



Connector Location A

Connector Location B

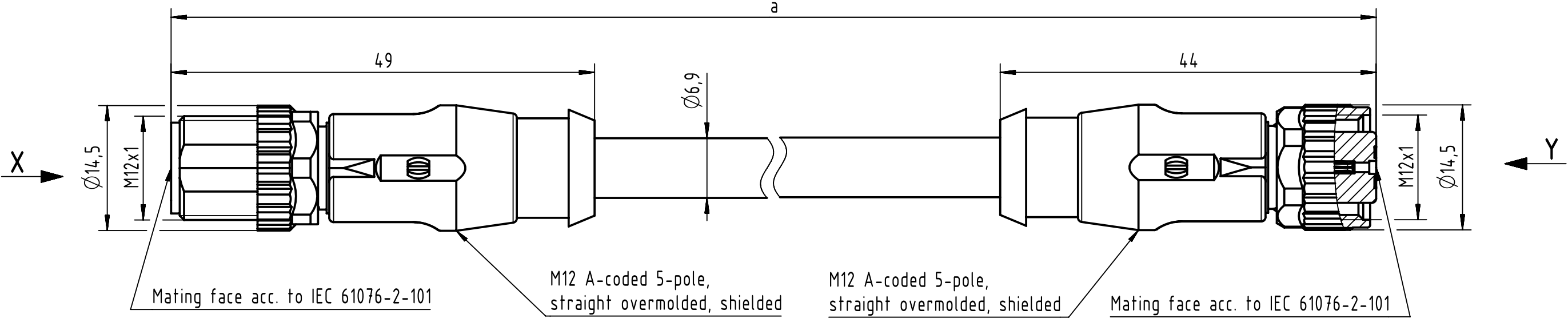


X
male

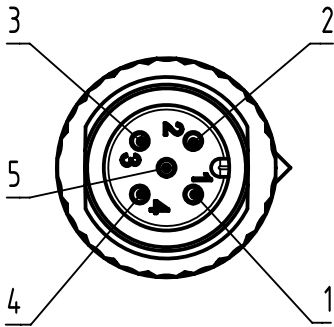


Loading Plan

- | | | |
|---|---------------|---|
| 1 | shield | 1 |
| 2 | red (+) | 2 |
| 3 | black (-) | 3 |
| 4 | white (CAN H) | 4 |
| 5 | blue (CAN L) | 5 |

Y
female

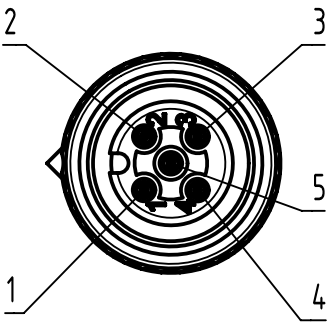

- Protection level: IP67
- Temperature range: -25°C ... +80°C

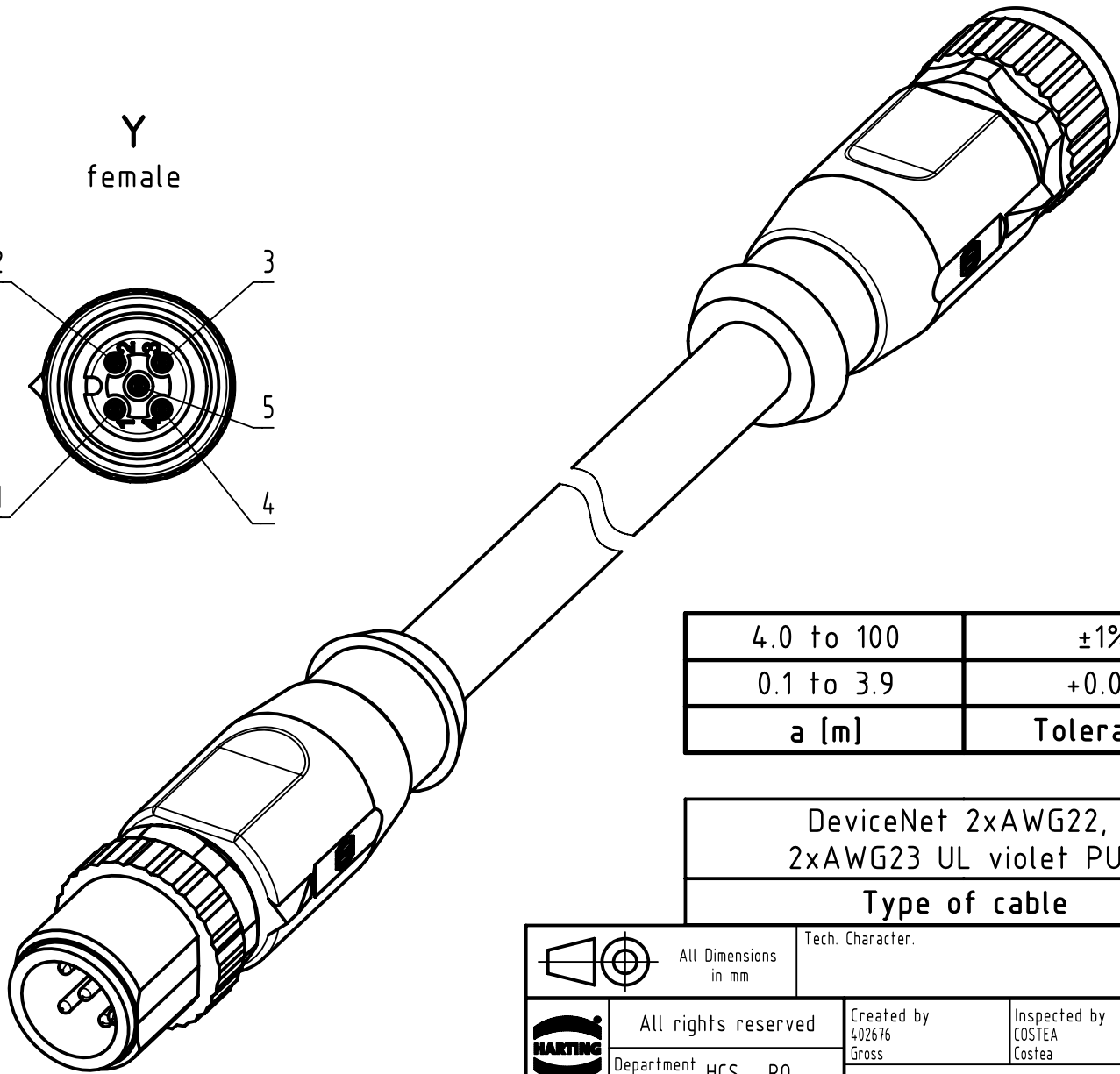

4.0 to 100	±1%
0.1 to 3.9	+0.04
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
	11	XXX=110
length in "0.1m" step	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001
Step	a [m]	XXX

DeviceNet 2xAWG22, 2xAWG23 UL violet PUR	21347875572XXX
Type of cable	Part no.

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
	All rights reserved	Created by 402676 Gross	Inspected by COSTEA Costea	Standardisation MUNTEANV Muntean	Date 2023-03-10	State Final Release	
	Department HCS - RO	Title M12 DeviceNet P+S A-cod st/st m/f				Doc-Key / ECM-Nr. 100644175/UGD/011/E 500000237467	
HARTING Customised Solutions D-32339 Espelkamp		Type TB	Number 21347875572XXX			Rev. E	Page 1/1