


Connector Location A

Connector Location B

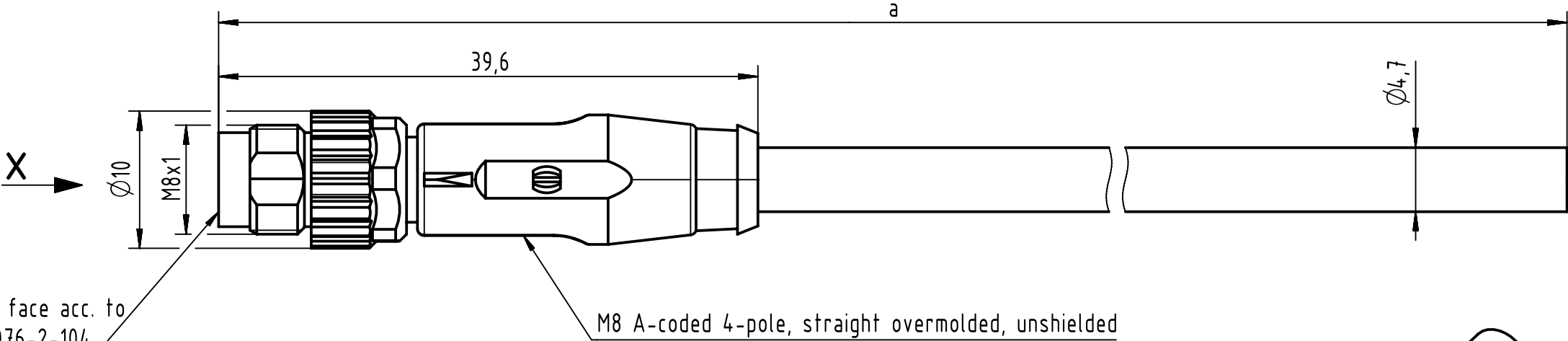

X

Ø10

M8x1

39,6

a


Ø4,7

Mating face acc. to IEC 61076-2-104

M8 A-coded 4-pole, straight overmolded, unshielded

X


male

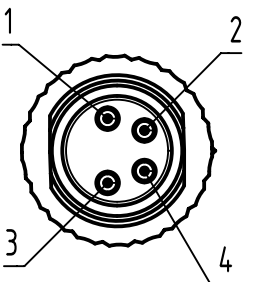

Loading Plan

- 1 brown
- 2 white
- 3 blue
- 4 black

- Protection level: IP67
- Temperature range: -25°C ... +80°C

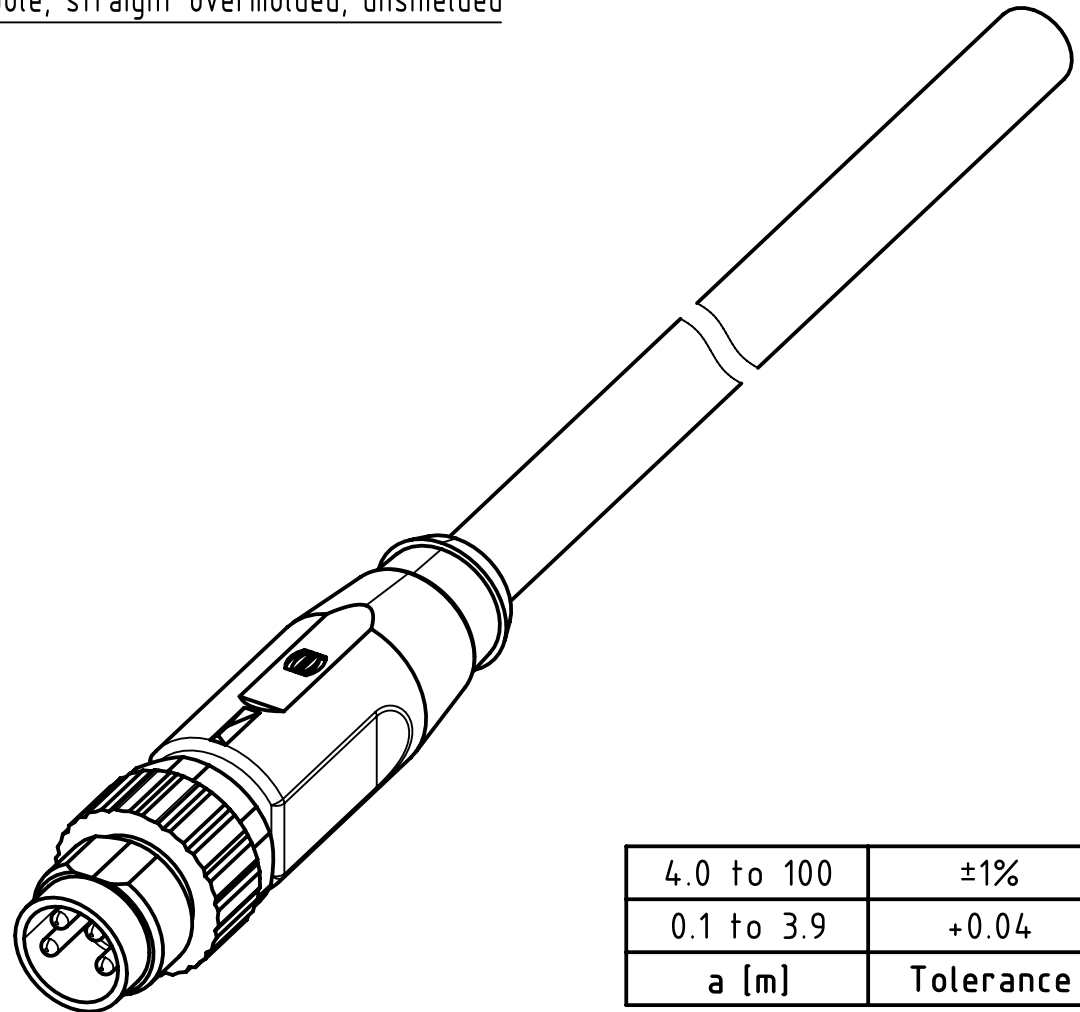

4.0 to 100	±1%
0.1 to 3.9	+0.04
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
	0.1	XXX=001
Step	a [m]	XXX

PVC grey, 4x0.25mm ²	21348000481XXX
Type of cable	Part no.

All Dimensions in mm		Tech. Character.		Free size tol.		According to production drawing	
	All rights reserved	Created by 407675 Lorinczi	Inspected by 402676 Gross	Standardisation MUNTEANV Muntean	Date 2023-06-09	State Final Release	
	Department HCS - RO	Title M8 Cable Assembly 4-poles st/- m/-				Doc-Key / ECM-Nr. 100577961/UGD/009/D 500000236006	
HARTING Customised Solutions D-32339 Espelkamp		Type TB	Number 21348000481XXX			Rev. D	Page 1/1