

## Han-Fast Lock 1,5-2,5mm<sup>2</sup> with pin, Ag

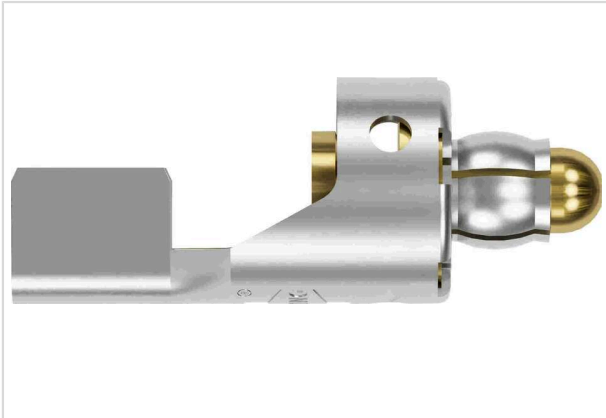


Image is for illustration purposes only. Please refer to product description.

Part number	09 08 000 7122
Specification	Han-Fast Lock 1,5-2,5mm <sup>2</sup> with pin, Ag
HARTING eCatalogue	<a href="https://harting.com/09080007122">https://harting.com/09080007122</a>

### Identification

Category	Contacts
Series	Han-Fast <sup>®</sup> Lock
Type of contact	PCB contact
Description of the contact	With pin

### Version

Pack contents	Single contact
---------------	----------------

### Technical characteristics

Conductor cross-section	1.5 ... 2.5 mm <sup>2</sup>
Rated current	≤60 A
Contact resistance	≤2 mΩ
Stripping length	7.5 mm

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated
Material (locking)	Copper alloy
Surface (locking)	Passivated
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50



**Pushing Performance**  
Since 1945

## Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel

## Commercial data

Packaging size	100
Net weight	2.04 g
Country of origin	Germany
European customs tariff number	85366990
GTIN	5713140014862
eCl@ss	27460201 PCB connector (board connector)
ETIM	EC002637
UNSPSC 24.0	39121415