

# SEK mezz Fe 26P THR 2.9mm PL3

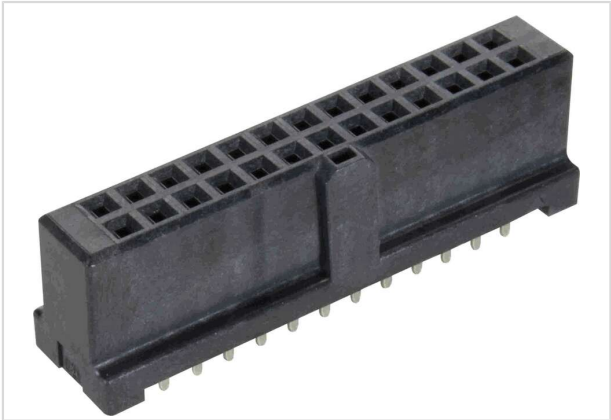


Image is for illustration purposes only. Please refer to product description.

|                    |                                                                                     |
|--------------------|-------------------------------------------------------------------------------------|
| Part number        | 09 19 526 7824 741                                                                  |
| Specification      | SEK mezz Fe 26P THR 2.9mm PL3                                                       |
| HARTING eCatalogue | <a href="https://harting.com/09195267824741">https://harting.com/09195267824741</a> |

## Identification

|                            |                  |
|----------------------------|------------------|
| Category                   | Connectors       |
| Series                     | SEK Mezzanine    |
| Element                    | Female connector |
| Description of the contact | Straight         |

## Version

|                    |                                           |
|--------------------|-------------------------------------------|
| Termination method | Reflow soldering termination (THR)        |
| Connection type    | PCB to PCB<br>Motherboard to daughtercard |
| Number of contacts | 26                                        |
| Termination length | 2.9 mm                                    |
| Pack contents      | Tape & reel                               |

## Technical characteristics

|                                    |                                                                 |
|------------------------------------|-----------------------------------------------------------------|
| Contact rows                       | 2                                                               |
| Contact spacing (termination side) | 2.54 mm                                                         |
| Rated current                      | 1 A                                                             |
| Insulation resistance              | $>10^9 \Omega$                                                  |
| Contact resistance                 | $\leq 20 \text{ m}\Omega$                                       |
| Limiting temperature               | -55 ... +125 °C (during reflow soldering max. +240 °C for 60 s) |
| Insertion force                    | $\leq 78 \text{ N}$                                             |
| Withdrawal force                   | $\leq 78 \text{ N}$                                             |
| Performance level                  | 3                                                               |



**Pushing Performance**  
Since 1945

## Technical characteristics

|                           |                               |
|---------------------------|-------------------------------|
| Mating cycles             | ≥50                           |
| Test voltage $U_{r.m.s.}$ | 1 kV                          |
| Isolation group           | IIIa ( $175 \leq CTI < 400$ ) |

## Material properties

|                                           |                                                          |
|-------------------------------------------|----------------------------------------------------------|
| Material (insert)                         | Liquid crystal polymer (LCP)                             |
| Colour (insert)                           | Black                                                    |
| Material (contacts)                       | Copper alloy                                             |
| Surface (contacts)                        | Sn over Ni Termination side<br>Au over Pd/Ni Mating side |
| Material flammability class acc. to UL 94 | V-0                                                      |
| RoHS                                      | compliant                                                |
| ELV status                                | compliant                                                |
| China RoHS                                | e                                                        |
| REACH Annex XVII substances               | Not contained                                            |
| REACH ANNEX XIV substances                | Not contained                                            |
| REACH SVHC substances                     | Not contained                                            |
| California Proposition 65 substances      | Not contained                                            |

## Specifications and approvals

|                |                                                            |
|----------------|------------------------------------------------------------|
| Specifications | IEC 60603-13                                               |
| UL / CSA       | UL 1977 ECBT2.E102079<br>CSA-C22.2 No. 182.3 ECBT8.E102079 |

## Commercial data

|                                |                                          |
|--------------------------------|------------------------------------------|
| Packaging size                 | 160                                      |
| Net weight                     | 6.9 g                                    |
| Country of origin              | China                                    |
| European customs tariff number | 85366990                                 |
| GTIN                           | 5713140212558                            |
| ETIM                           | EC002637                                 |
| eCl@ss                         | 27460201 PCB connector (board connector) |