

Han 16B-SCP-HBM-DL

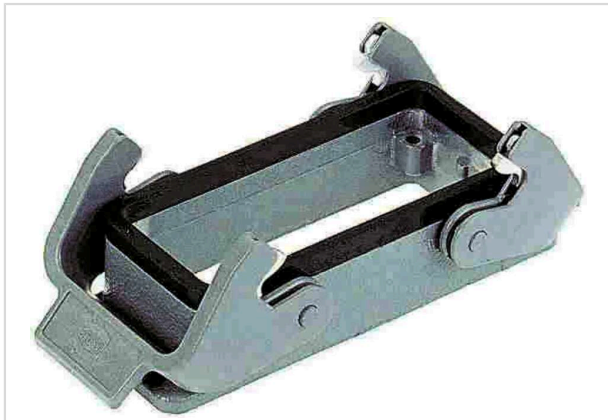


Image is for illustration purposes only. Please refer to product description.

Part number	09 30 916 0301
Specification	Han 16B-SCP-HBM-DL
HARTING eCatalogue	https://harting.com/09309160301

Identification

Category	Hoods / Housings
Series of hoods/housings	Han [®] B
Type of hood/housing	Bulkhead mounted housing
Description of hood/housing	Corrosion resistant
Type	Low construction

Version

Size	16 B
Locking type	Double locking lever
Han-Easy Lock [®]	Yes
Field of application	Standard hoods/housings for industrial connectors

Technical characteristics

Tightening torque	1 Nm Fixing screws M4
Limiting temperature	-40 ... +125 °C
Note on the limiting temperature	For use as a connector according to IEC 61984.
Mating cycles	≥500
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4
	4X
	12

Material properties

Material (hood/housing)	Aluminium die-cast
-------------------------	--------------------



Pushing Performance
Since 1945

Material properties

Surface (hood/housing)	Powder-coated
Colour (hood/housing)	RAL 7037 (dust grey)
Material (seal)	NBR
Material (locking)	Polycarbonate (PC) Stainless steel
Colour (locking)	RAL 7037 (dust grey)
Material flammability class acc. to UL 94 (locking levers)	V-0

Specifications and approvals

Approvals	CE DNV GL
-----------	--------------

Commercial data

Packaging size	1
Net weight	122.1 g
Country of origin	China
European customs tariff number	85366990
GTIN	5713140164819
eCl@ss	27440202 Shell for industrial connectors
ETIM	EC000437
UNSPSC 24.0	39121466