



Pushing Performance
Since 1945

Han 16M-Metal Cover-DL-Seal-for Hood

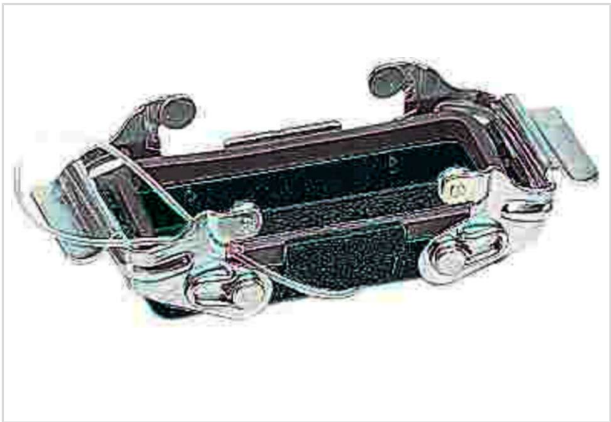


Image is for illustration purposes only. Please refer to product description.

Part number	09 37 016 5402
Specification	Han 16M-Metal Cover-DL-Seal-for Hood
HARTING eCatalogue	https://harting.com/09370165402

Identification

Category	Accessories
Series of hoods/housings	Han [®] M
Type of accessory	Protection cover
Description of the accessory	for hoods With fixing cord

Version

Size	16 B
Locking type	Double locking lever

Technical characteristics

Limiting temperature	-40 ... +125 °C
Degree of protection acc. to IEC 60529	IP65
Type rating acc. to UL 50 / UL 50E	4 4X 12

Material properties

Material (hood/housing)	Metal
Material (seal)	FPM
Material (locking)	Stainless steel
RoHS	compliant
ELV status	compliant
China RoHS	e



Pushing Performance
Since 1945

Material properties

REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead
	Nickel

Specifications and approvals

UL / CSA	UL 1977 ECBT2.E235076
	CSA-C22.2 No. 182.3 ECBT8.E235076
Approvals	DNV GL

Commercial data

Packaging size	1
Net weight	123.5 g
Country of origin	Germany
European customs tariff number	85389099
GTIN	5713140055766
eCl@ss	27440208 Cap for industrial connectors
ETIM	EC002314
UNSPSC 24.0	39121467