

## RJ45 RJ45 Keystone bulkhead jack IP20

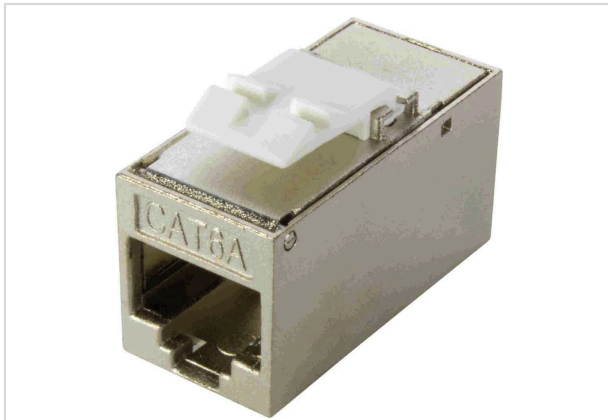


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 545 1568
Specification	RJ45 RJ45 Keystone bulkhead jack IP20
HARTING eCatalogue	<a href="https://harting.com/09455451568">https://harting.com/09455451568</a>

### Identification

Category	Connectors
Series	HARTING RJ Industrial®
Element	Coupler
Specification	RJ45

### Version

Size	Keystone version
Shielding	Fully shielded, 360° shielding contact
Number of contacts	8

### Technical characteristics

Transmission characteristics	Cat. 6 Class E up to 250 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s
Limiting temperature	-40 ... +70 °C
Mating cycles	≥750
Degree of protection acc. to IEC 60529	IP20

### Material properties

Material (hood/housing)	Zinc die-cast
Surface (hood/housing)	Nickel plated



**Pushing Performance**  
Since 1945

## Material properties

Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Specifications and approvals

Approvals	DNV GL
PROFINET	Yes

## Commercial data

Packaging size	1
Net weight	18 g
Country of origin	China
European customs tariff number	85366990
GTIN	5713140061415
eCl@ss	27440190 Industry connector (unspecified)
ETIM	EC001264
UNSPSC 24.0	39121409