


SD-WMS 10 (SY) - Wire marking tag



0826187

<https://www.phoenixcontact.com/us/products/0826187>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

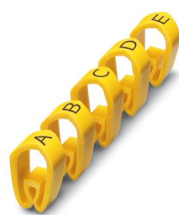

Wire marking tag, white, cable diameter range: 4 ... 10 mm, horizontal: Symbols, mounting type: thread on

Commercial data

Item number	0826187
Packing unit	1 pc
Sales key	BG17
Product key	BG222B
Weight per piece (including packing)	333 g
Weight per piece (excluding packing)	333 g
Customs tariff number	49119900
Country of origin	SE

SD-WMS 10 (SY) - Wire marking tag



0826187

<https://www.phoenixcontact.com/us/products/0826187>

Technical data

Notes

General	Please specify the required marking with order: Minimum order per imprint: 1 packing unit
---------	---

Product properties

Product type	Conductor marker
--------------	------------------

Marking

Printing direction	horizontal
Printing	Symbols

Dimensions

Width	4.2 mm
Height	9.5 mm
Length	6.6 mm

Material specifications

Color	white
Material	Polyvinyl chloride
Flammability rating according to UL 94	V0
Components	Free from silicone and cadmium

Cable/line

External cable diameter	4 mm ... 10 mm
-------------------------	----------------

Environmental and real-life conditions

Test for substances that would hinder coating with paint or varnish

Result	Test passed
--------	-------------

UV resistance

Specification	ISO 4892-2:2013-03 (following)
Result	Test passed
Test duration	96 h

Ambient conditions

Ambient temperature (operation)	-30 °C ... 60 °C
---------------------------------	------------------

Standards and regulations

Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

Mounting

Mounting type	thread on
---------------	-----------

SD-WMS 10 (SY) - Wire marking tag



0826187
<https://www.phoenixcontact.com/us/products/0826187>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com