

# HC-M-B24-MFH-H-CI - Module carrier frame




1721376

<https://www.phoenixcontact.com/us/products/1721376>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Module carrier frame, size: B24, type : for the sleeve side (A, B, C, ...), Push-in connection, 0.5 mm<sup>2</sup> ... 6 mm<sup>2</sup>, application: Module carrier frame

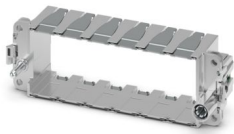

## Your advantages

- Significant time savings and improved handling: Consistent and easy tool-free installation and mounting with Push-in connection technology and innovative Click-in latching
- Tool-free installation and mounting of the PE connection with Push-in connection technology
- Shortest installation time compared to other connection technologies
- Quick and effortless wiring, in particular when space is tight
- Secure installation: Audible and tangible latching of the contact inserts in the connector housing
- Reliable connection: The Click-in contact insert latches into the housing creating a shock- and vibration-resistant connection in accordance with DIN EN 61373
- Easy integration: Click-in contact inserts fit in all plastic and metal housings of the HEAVYCON STANDARD and EVO series
- Safe wiring and operation with color-coded actuators
- Shock and vibration-resistant in accordance with DIN EN 61373

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1721376       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BF62          |
| Product key                          | AF7ACD        |
| GTIN                                 | 4067923274136 |
| Weight per piece (including packing) | 106.6 g       |
| Weight per piece (excluding packing) | 123.6 g       |
| Customs tariff number                | 85389099      |
| Country of origin                    | CN            |

# HC-M-B24-MFH-H-CI - Module carrier frame



1721376  
<https://www.phoenixcontact.com/us/products/1721376>

## Technical data

### Notes

|         |                                                                |
|---------|----------------------------------------------------------------|
| General | Connectors may be operated only when there is no load/voltage. |
|---------|----------------------------------------------------------------|

### Product properties

|                        |                      |
|------------------------|----------------------|
| Product type           | Module carrier frame |
| Series                 | HC-M-B               |
|                        | HC-M-02              |
|                        | HC-M-03              |
|                        | HC-M-03/04           |
|                        | HC-M-04              |
|                        | HC-M-05              |
|                        | HC-M-06              |
|                        | HC-M-08              |
|                        | HC-M-08-GBIT         |
|                        | HC-M-12              |
|                        | HC-M-17              |
|                        | HC-M-20              |
|                        | HC-M-25              |
|                        | HC-M-DSUB            |
|                        | HC-M-EMV             |
|                        | HC-M-HV              |
|                        | HC-M-HS              |
|                        | HC-M-00              |
| Application            | Module carrier frame |
| Type                   | B24                  |
| Number of module slots | 6                    |
| Frame type             | Module carrier frame |

### Connection data

|                         |                                      |
|-------------------------|--------------------------------------|
| Conductor connection    |                                      |
| Conductor cross section | 0.5 mm² ... 6 mm² (for PE conductor) |
| Stripping length        | 8 mm ... 10 mm (for PE conductor)    |

### Dimensions

|                     |         |
|---------------------|---------|
| Dimensional drawing |         |
| Width               | 34.9 mm |

# HC-M-B24-MFH-H-CI - Module carrier frame



1721376

<https://www.phoenixcontact.com/us/products/1721376>

|        |        |
|--------|--------|
| Height | 36 mm  |
| Length | 111 mm |

## Material specifications

|                          |                     |
|--------------------------|---------------------|
| Contact carrier material | Die-cast zinc alloy |
|--------------------------|---------------------|

## Mechanical properties

### Mechanical data

|                             |       |
|-----------------------------|-------|
| Insertion/withdrawal cycles | ≥ 500 |
|-----------------------------|-------|

## Environmental and real-life conditions

### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 125 °C |
|---------------------------------|-------------------|

## Mounting

|               |                                                                                                                                                        |
|---------------|--------------------------------------------------------------------------------------------------------------------------------------------------------|
| Assembly note | To ensure correct use, installation in housing with IP54 protection or better is required                                                              |
|               | tool-free snap-in into all plastic and metal housings of the HEAVYCON STANDARD and EVO series, and into metal housings of the HEAVYCON ADVANCED series |


# HC-M-B24-MFH-H-CI - Module carrier frame

1721376

<https://www.phoenixcontact.com/us/products/1721376>

## Drawings

Dimensional drawing

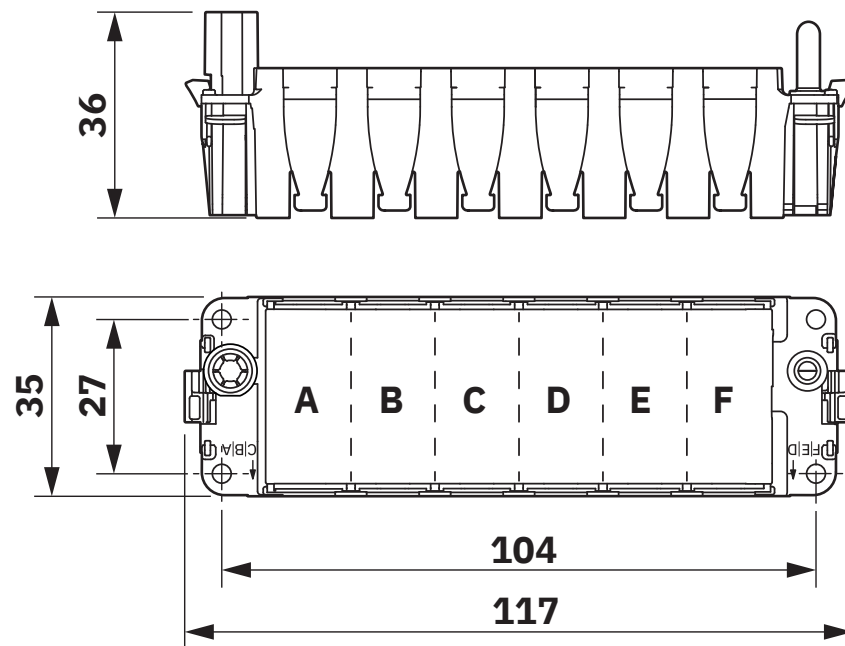

Dimensional drawing

# HC-M-B24-MFH-H-CI - Module carrier frame



1721376

<https://www.phoenixcontact.com/us/products/1721376>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440206 |
| ECLASS-15.0 | 27440206 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002312 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-M-B24-MFH-H-CI - Module carrier frame



1721376

<https://www.phoenixcontact.com/us/products/1721376>

## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)