

# HC-COM-BCFS-PLR-BK - Protective cover



1079397

<https://www.phoenixcontact.com/us/products/1079397>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover COM, for single locking latch, protective cover material: PA, height: 24.5 mm, seal: yes, Standard, for socket inserts

## Commercial data

Item number	1079397
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF66
Product key	AF7AZC
GTIN	4055626799230
Weight per piece (including packing)	17.7 g
Weight per piece (excluding packing)	17 g
Customs tariff number	39269097
Country of origin	CN

# HC-COM-BCFS-PLR-BK - Protective cover



1079397


<https://www.phoenixcontact.com/us/products/1079397>

## Technical data

### Product properties

Product type	Protective cover
Housing type	Protective cover
Series	HC-COM
Application	Standard
Type	COM
Retaining cord present	yes
Seal present	yes

### Dimensions

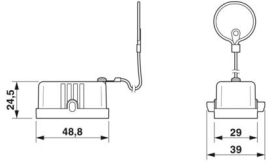Dimensional drawing	
Width	39 mm
Height	24.5 mm
Length	48.8 mm

### Material specifications

Material Protective cover	PA
Flammability rating according to UL 94	V0
Seal material	NBR
Material, protective cover	PA

### Mechanical properties

Mechanical data	
Locking type	Pin

### Environmental and real-life conditions

Ambient conditions	
Degree of protection	IP66
Ambient temperature (operation)	-40 °C ... 125 °C

# HC-COM-BCFS-PLR-BK - Protective cover



1079397

<https://www.phoenixcontact.com/us/products/1079397>



## Drawings

Dimensional drawing

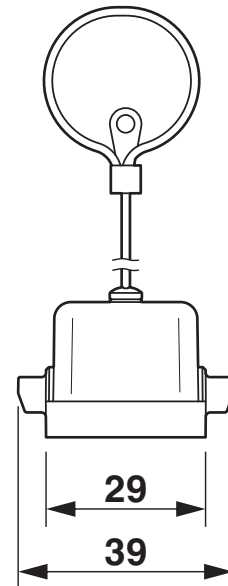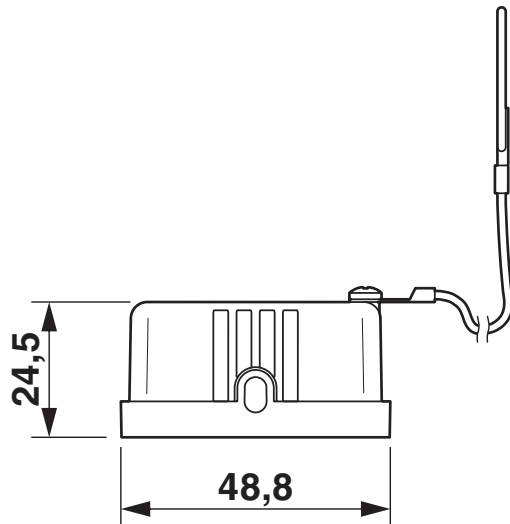

Dimensional drawing


# HC-COM-BCFS-PLR-BK - Protective cover



1079397

<https://www.phoenixcontact.com/us/products/1079397>

## Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1079397>



**UL Recognized**

Approval ID: E468743

1079397

<https://www.phoenixcontact.com/us/products/1079397>

Classifications

ECLASS

ECLASS-13.0	27440208
-------------	----------

ETIM

ETIM 9.0	EC002314
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)