

UM-BASIC 72 L5,50CM KMGY - Profile




1193573

<https://www.phoenixcontact.com/us/products/1193573>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, Basic profile, profile width (internal): 72 mm, length: 55 mm, depth: 19.8 mm

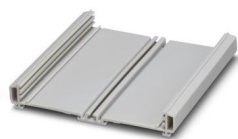

Commercial data

Item number	1193573
Packing unit	10 pc
Minimum order quantity	100 pc
Note	Made to order (non-returnable)
Product key	ACHDAD
GTIN	4063151248222
Weight per piece (including packing)	30.06 g
Weight per piece (excluding packing)	26.45 g
Country of origin	DE

UM-BASIC 72 L5,50CM KMGY - Profile



1193573

<https://www.phoenixcontact.com/us/products/1193573>

Technical data

Product properties

Product type	Component housing lower part
Housing type	Press-drawn section housings
Housing series	UM-BASIC
Type	Basic profile

Dimensions

Depth	19.8 mm
Length	55 mm

Internal dimensions

Profile width (internal)	72 mm
--------------------------	-------

Material specifications

Color (Housing)	light gray (RAL 7035)
Flammability rating according to UL 94	V0
Housing material	PVC

Environmental and real-life conditions

Ambient conditions

Max. IP code to attain	IP20
------------------------	------

UM-BASIC 72 L5,50CM KMGY - Profile



1193573

<https://www.phoenixcontact.com/us/products/1193573>

Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1193573>



UL Recognized

Approval ID: E240868

UM-BASIC 72 L5,50CM KMGY - Profile



1193573

<https://www.phoenixcontact.com/us/products/1193573>

Classifications

ECLASS

ECLASS-13.0	27190601
-------------	----------

ETIM

ETIM 9.0	EC002779
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

UM-BASIC 72 L5,50CM KMGY - Profile



1193573

<https://www.phoenixcontact.com/us/products/1193573>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com