

# HC-STA-B10-HLWD-1STM25-EL-AL - Housing



1412634

<https://www.phoenixcontact.com/us/products/1412634>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B10, with double locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, lateral, 1x M25, height: 57 mm, cable gland: none, Standard

## Your advantages

- Good shielding in the event of electromagnetic interference

## Commercial data

Item number	1412634
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF56
Product key	AF7APB
GTIN	4055626059600
Weight per piece (including packing)	177.6 g
Weight per piece (excluding packing)	175 g
Customs tariff number	85389099
Country of origin	CN

## Technical data

 
### Notes

General	for contact inserts HC-B10, BB18, DD42, M, K8/24, HV03
General	also available as a powder-coated or color version: 1372759 HC-STA-B10-HLWD-1STM25-EL/...

### Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Application	Standard
Type	B10
No. of cable outlets	1
Type of the screw connection	1x M25
Type	Low design
Cable outlet	lateral
Pg screw connection	none

### Dimensions

Dimensional drawing	
Width	44 mm
Height	57 mm
Length	73 mm

### Material specifications

Flammability rating according to UL 94	V0 (Interlock)
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated
Locking latch material	PA

### Mechanical properties

#### Mechanical data

Type of the screw connection	1x M25
Locking type	Latch

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP66
	IP67

# HC-STA-B10-HLWD-1STM25-EL-AL - Housing



1412634

<https://www.phoenixcontact.com/us/products/1412634>

Enclosure rating (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Impact strength	IK09
Ambient temperature (operation)	-40 °C ... 125 °C

# HC-STA-B10-HLWD-1STM25-EL-AL - Housing


1412634

<https://www.phoenixcontact.com/us/products/1412634>



## Drawings

Dimensional drawing

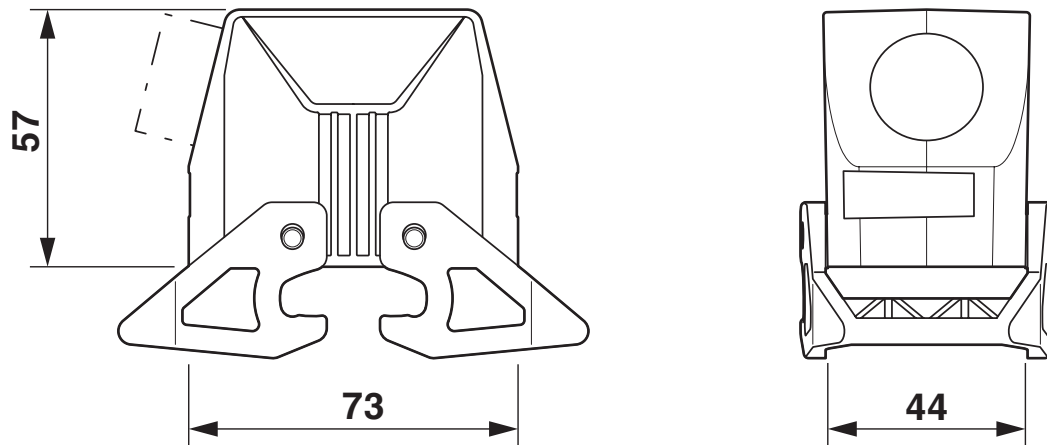

Dimensional drawing

# HC-STA-B10-HLWD-1STM25-EL-AL - Housing



1412634

<https://www.phoenixcontact.com/us/products/1412634>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1412634>

### DNV

Approval ID: TAE000037S



### EAC

Approval ID: RU C-DE.AI30.B.01102

# HC-STA-B10-HLWD-1STM25-EL-AL - Housing



1412634

<https://www.phoenixcontact.com/us/products/1412634>

## Classifications

### ECLASS

ECLASS-13.0	27440202
-------------	----------

### ETIM

ETIM 9.0	EC000437
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%
EF3.0 Climate Change	
CO2e kg	3.002 kg CO2e