

RC-12P1N12QDEP - Crimp contact



1613094

<https://www.phoenixcontact.com/us/products/1613094>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



M23, Crimp contact, series: RC, straight, shielded: yes, Screw locking mechanism, No. of pos.: 12, Direction of rotation: Standard, contact connection type: Pin, Solder cup, Axial O-ring, Panel thickness min.: 0.8 mm, Panel thickness max.: 6.5 mm, cable diameter range: 2 mm ... 10.5 mm, coding: N

Commercial data

Item number	1613094
Packing unit	10 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Product key	ABRAFJ
GTIN	4046356397698
Weight per piece (including packing)	242.2 g
Weight per piece (excluding packing)	176 g
Country of origin	DE

RC-12P1N12QDEP - Crimp contact



1613094

<https://www.phoenixcontact.com/us/products/1613094>

Technical data

Product properties

Product type	Circular connector (cable-side)
--------------	---------------------------------

Connector

Insulating body

Coding	N
Contact material	CuZn
Contact surface material	Ni/Au
Insertion/withdrawal cycles	100
Connection method	Solder cup
Contact switching type	Pin
Application	Signal
Number of positions	12
Direction of rotation	Standard
Connection profile	12
Number Contact (Contact group 1)	12
Diameter Contact (Contact group 1)	1 mm
Litz wire cross-section min. Contact (Contact group 1)	0.08 mm ²
Litz wire cross-section max. Contact (Contact group 1)	1 mm ²
Rated current Contact (Contact group 1)	8 A (for max. connection cross section)
Rated voltage Contact (Contact group 1)	48 V AC
	74 V DC
Rated surge voltage	1.5 kV
Overvoltage category	III
Degree of pollution	3

Housing

Order information:	Order contact inserts and cable clamping/shield accessories separately
Thread type	M23
Type of locking	Screw locking mechanism
Pg screw connection	none
Degree of protection (plugged in)	IP67

Seal

External cable diameter	2 mm ... 10.5 mm
-------------------------	------------------

RC-12P1N12QDEP - Crimp contact


1613094

<https://www.phoenixcontact.com/us/products/1613094>




Drawings

Dimensional drawing

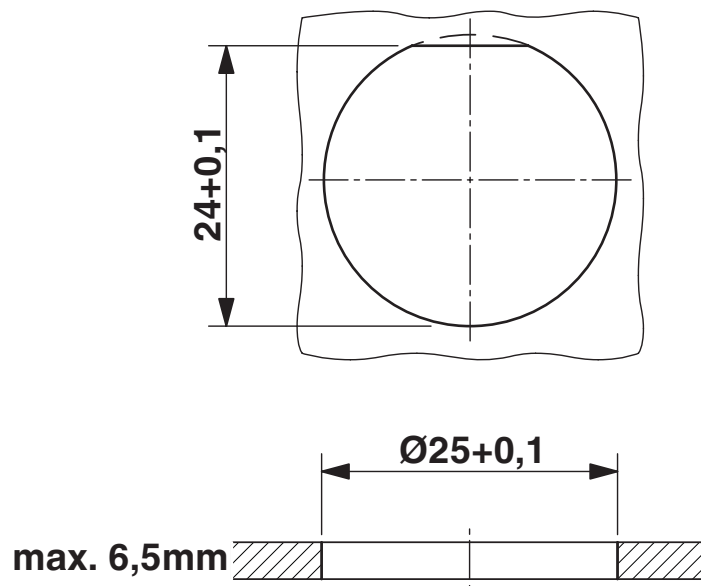

Installation dimensions

Dimensional drawing

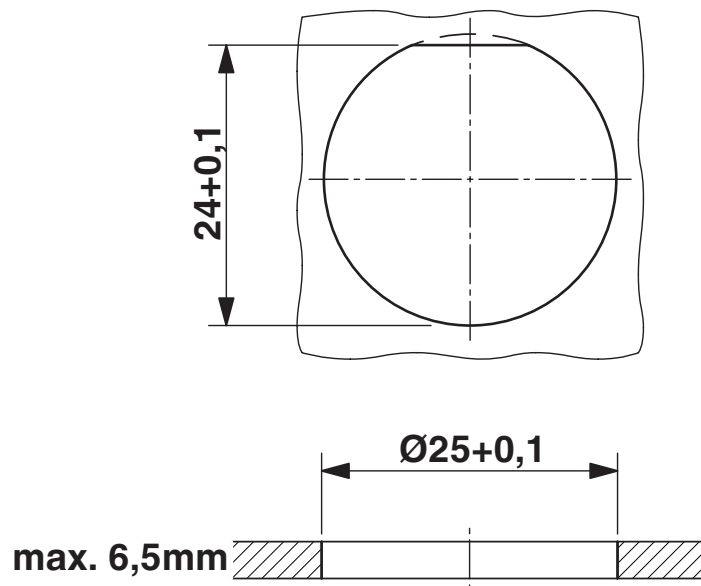

Installation dimensions


RC-12P1N12QDEP - Crimp contact

1613094

<https://www.phoenixcontact.com/us/products/1613094>



Schematic diagram

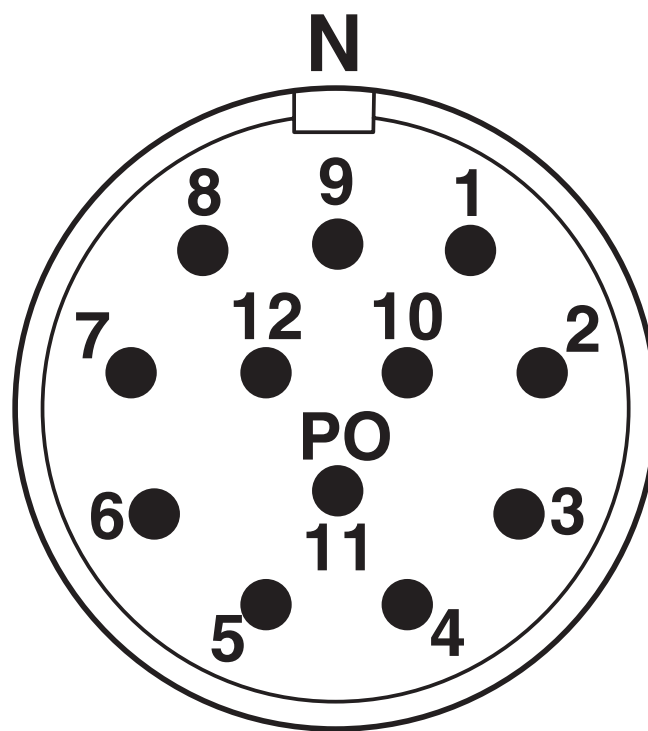

Connector pin assignment


RC-12P1N12QDEP - Crimp contact

1613094

<https://www.phoenixcontact.com/us/products/1613094>



Schematic diagram

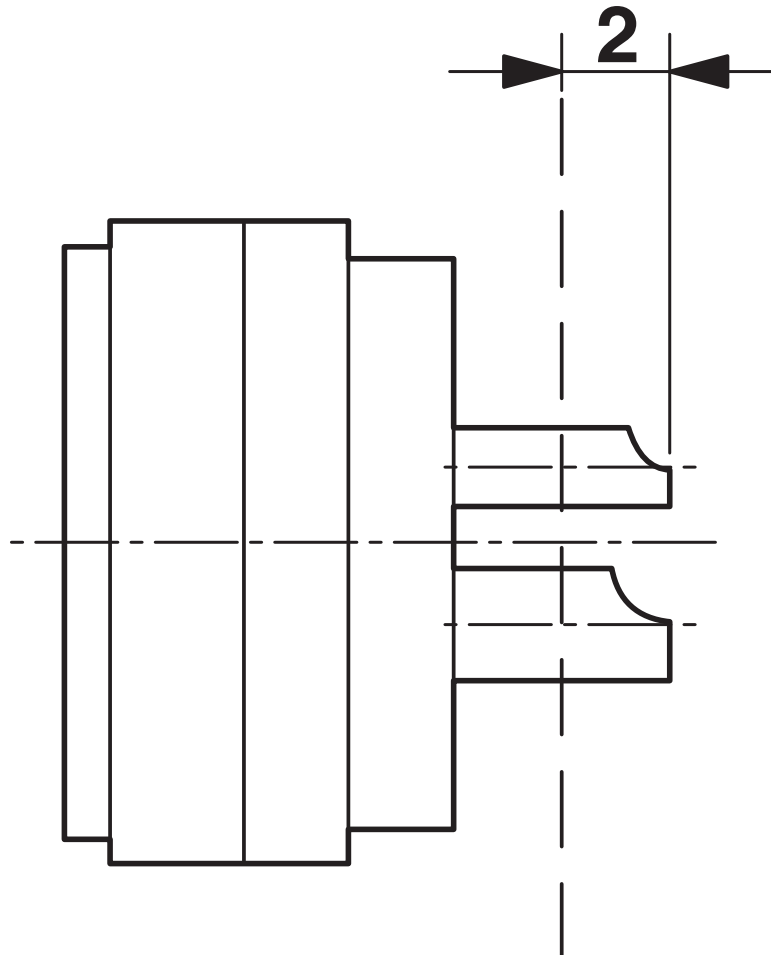

Dimensional drawing

RC-12P1N12QDEP - Crimp contact



1613094

<https://www.phoenixcontact.com/us/products/1613094>

Classifications

UNSPSC

UNSPSC 21.0	39121413
-------------	----------

RC-12P1N12QDEP - Crimp contact



1613094

<https://www.phoenixcontact.com/us/products/1613094>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes
Exemption	6(c)
China RoHS	
Environment friendly use period (EFUP)	EFUP-50
	An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required.
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com