

# UM100-PROFIL 100CM - Profile

2914563

<https://www.phoenixcontact.com/us/products/2914563>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, Basic profile, profile width (internal): 100 mm, profile width (external): 122.6 mm, length: 1000 mm, depth: 21.5 mm, Note: required profile length = PCB length - 3.6 mm



## Your advantages

- Easy installation
- Flexible size and shape
- Inexpensive as a result of reducing the number of separate housing parts

## Commercial data

Item number	2914563
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	AC13
Product key	ACHDBA
GTIN	4017918959159
Weight per piece (including packing)	400 g
Weight per piece (excluding packing)	606 g
Customs tariff number	39162000
Country of origin	DE

# UM100-PROFIL 100CM - Profile

2914563

<https://www.phoenixcontact.com/us/products/2914563>




## Technical data

### Product properties

Product type	Component housing lower part
Housing type	Press-drawn section housings
Housing series	UM
Product family	UM100
Type	Basic profile
Ventilation openings present	no

### Dimensions

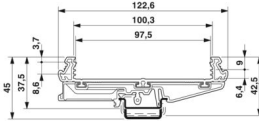Dimensional drawing	
Depth	21.5 mm
Length	100 cm

#### External dimensions

Profile width (external)	122.6 mm
--------------------------	----------

#### Internal dimensions

Profile width (internal)	100 mm
--------------------------	--------

#### PCB design

PCB thickness	1.4 mm ... 1.8 mm
---------------	-------------------

### Material specifications

Color (Housing)	green (RAL 6021)
Flammability rating according to UL 94	V0
Housing material	PVC

### Environmental and real-life conditions

#### Ambient conditions

Max. IP code to attain	IP20
Ambient temperature (operation)	-15 °C ... 50 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 50 °C
Ambient temperature (assembly)	-5 °C ... 50 °C
Relative humidity (storage/transport)	95 %

### PCB data

Number of PCB holders	2
Thickness of the PCB	1.4 mm ... 1.8 mm

# UM100-PROFIL 100CM - Profile

2914563

<https://www.phoenixcontact.com/us/products/2914563>



## Mounting

Mounting position	parallel to the DIN rail
-------------------	--------------------------

## Packaging specifications

Type of packaging	packed in cardboard
Outer packaging type	Carton


# UM100-PROFIL 100CM - Profile

2914563

<https://www.phoenixcontact.com/us/products/2914563>



## Drawings

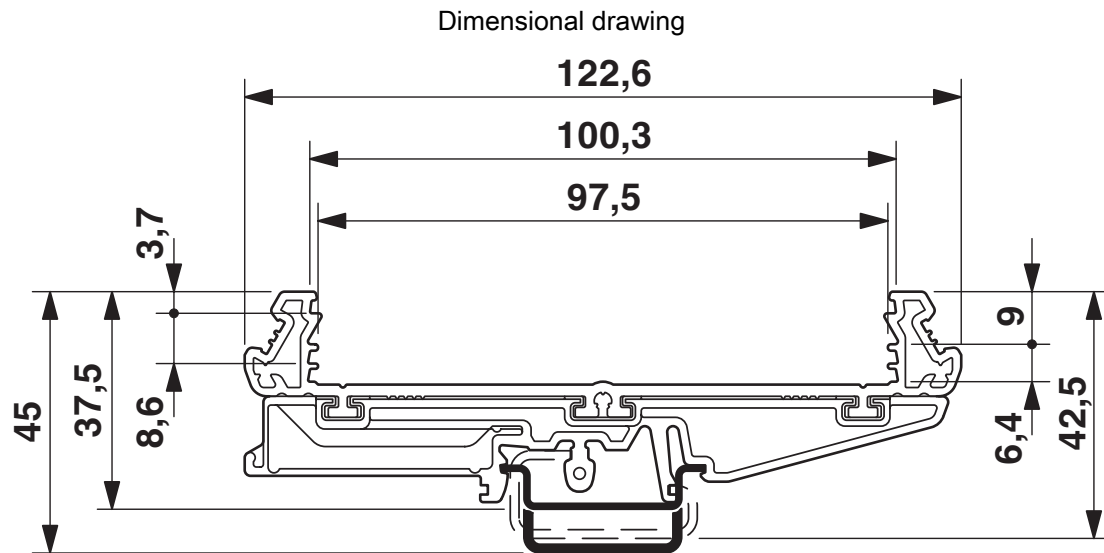

# UM100-PROFIL 100CM - Profile

2914563

<https://www.phoenixcontact.com/us/products/2914563>



## Classifications

### ECLASS

ECLASS-13.0	27190601
-------------	----------

### ETIM

ETIM 9.0	EC002779
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------

# UM100-PROFIL 100CM - Profile

2914563

<https://www.phoenixcontact.com/us/products/2914563>



## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)