

# SK 3,8 REEL P5,08 WH CUS - Marker card



0825125

<https://www.phoenixcontact.com/us/products/0825125>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Marker card, can be ordered: by card, white, labeled according to customer specifications, mounting type: adhesive, for terminal block width: 5.08 mm

## Your advantages

- Labeling service: Phoenix Contact can custom-label all SK ... markers in accordance with your requirements
- The SK labeling range offers self-adhesive marker strips for labeling products that do not have a marker groove

## Commercial data

Item number	0825125
Packing unit	1 pc
Minimum order quantity	50 pc
Note	Made to order (non-returnable)
Sales key	BG24
Product key	BG8113
GTIN	4046356355087
Weight per piece (including packing)	0.89 g
Weight per piece (excluding packing)	0.535 g
Customs tariff number	49119900
Country of origin	DE

# SK 3,8 REEL P5,08 WH CUS - Marker card



0825125

<https://www.phoenixcontact.com/us/products/0825125>

## Technical data

### Product properties

Product type	Klemmenmarker
Pitch	5.08 mm

### Marking

Number of marker strips	12
-------------------------	----

### Mounting

Mounting type	adhesive
---------------	----------

### Material specifications

Foil strength	53 µm
Adhesive strength	20 µm
Adhesive	Acrylic
Color	white (RAL 9010)
Material	Polyester
Components	free from silicone and halogen

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 150 °C
Ambient temperature (assembly)	> 15 °C
Recommended storage conditions	23 °C / 50% relative humidity. Storage in the original packaging is recommended prior to processing.
Recommended ambient temperature (storage/transport)	23 °C
Recommended humidity (storage/transport)	50 %
Shelf life	12 months

### Dimensions

Width	50.00 mm
Height	3.80 mm
Depth	0.07 mm
Pitch	5.08 mm

### Standards and regulations


Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
-----------------	-----------------------------

### Notes

Order information:	Marking up to max. 25-pos.
--------------------	----------------------------

## Drawings

Schematic diagram

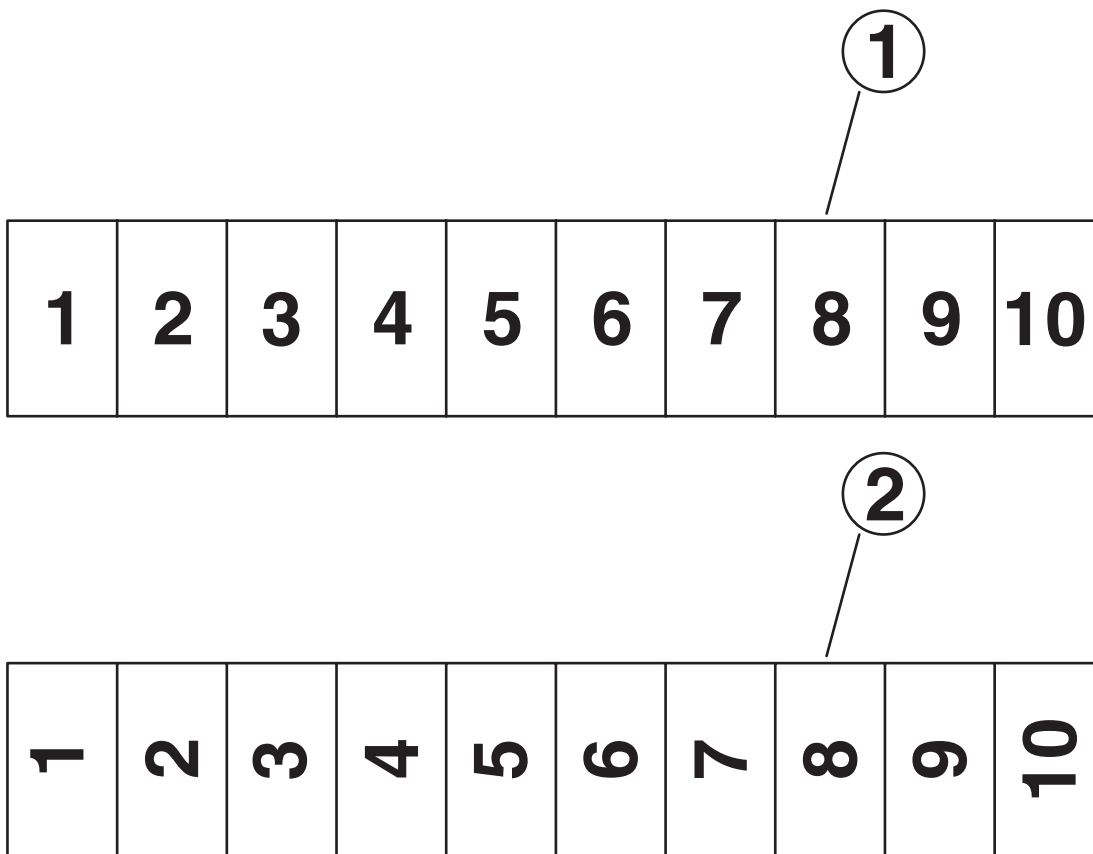

① Horizontal

② Vertical

# SK 3,8 REEL P5,08 WH CUS - Marker card



0825125

<https://www.phoenixcontact.com/us/products/0825125>

## Classifications

### ECLASS

ECLASS-13.0	27281101
ECLASS-15.0	27281101

### ETIM

ETIM 9.0	EC000761
----------	----------

### UNSPSC

UNSPSC 21.0	39131500
-------------	----------

# SK 3,8 REEL P5,08 WH CUS - Marker card



0825125

<https://www.phoenixcontact.com/us/products/0825125>

## Environmental product compliance

### EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

### EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)