


Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

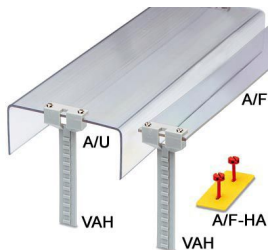

Flat-ribbon cover, for covering terminal strips, 2 mm thick, 10 cm wide, an additional requirement are 2 E/UK end brackets and 2 adjustable VAH cover holders. The max. supply length is 100 cm

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1004898       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BH84          |
| Product key                          | BH8412        |
| GTIN                                 | 4017918012274 |
| Weight per piece (including packing) | 270 g         |
| Weight per piece (excluding packing) | 270 g         |
| Customs tariff number                | 39205100      |
| Country of origin                    | DE            |

## Technical data

### Product properties

|              |               |
|--------------|---------------|
| Product type | Cover profile |
|--------------|---------------|

### Dimensions

|        |        |
|--------|--------|
| Width  | 100 mm |
| Length | 1 m    |

### Material specifications

|                                        |                  |
|----------------------------------------|------------------|
| Color                                  | transparent      |
| Material                               | Polycarbonate PC |
| Flammability rating according to UL 94 | V2               |

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-15.0 | 27141192 |
| ECLASS-13.0 | 27141192 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC004592 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121400 |
|-------------|----------|

Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |