

# A-EXSH-M20-68L-N-S - Screw plug



1411104

<https://www.phoenixcontact.com/us/products/1411104>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Screw plug, material for screw connection: Brass, nickel-plated, application: Ex, connecting thread: M20 x 1.5, color: silver-colored

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1411104       |
| Packing unit                         | 20 pc         |
| Minimum order quantity               | 1 pc          |
| Sales key                            | BF68          |
| Product key                          | AF7DDX        |
| GTIN                                 | 4046356922197 |
| Weight per piece (including packing) | 36.85 g       |
| Weight per piece (excluding packing) | 35.045 g      |
| Customs tariff number                | 74198090      |
| Country of origin                    | GB            |

# A-EXSH-M20-68L-N-S - Screw plug



1411104

<https://www.phoenixcontact.com/us/products/1411104>

## Technical data

### Notes

|                       |                                                                                                     |
|-----------------------|-----------------------------------------------------------------------------------------------------|
| Note on Ex protection | This item must only be used with counter nut 1411242 A-INL-M20-N-S for the Ex e type of protection. |
|-----------------------|-----------------------------------------------------------------------------------------------------|

 
### Product properties

|                             |                                         |
|-----------------------------|-----------------------------------------|
| Product type                | Plug for cable screw gland              |
| Application                 | Ex                                      |
| Manufacturer                | CMP                                     |
| Manufacturer Designation    | 757 M20 Exd/Exe N.PLTD HEX HD STOP PLUG |
| Manufacturer product number | 757DM25                                 |

### Ex data

|                            |     |
|----------------------------|-----|
| Suited for EX-applications | yes |
|----------------------------|-----|

### Dimensions

|                                 |                                                                                      |
|---------------------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing             |  |
| Length                          | 20.3 mm                                                                              |
| Length of the connecting thread | 15.3 mm                                                                              |
| Diameter                        | 20 mm                                                                                |
| Connecting thread diameter      | 20 mm                                                                                |
| Wrench size, union nut          | 24 mm                                                                                |
| Hexagon angular dimension       | 26.4 mm                                                                              |
| Thread type connection side     | M20 x 1.5                                                                            |
| Thread pitch                    | 1.5 mm                                                                               |

### Material specifications

|                               |                      |
|-------------------------------|----------------------|
| Housing surface material      | Ni                   |
| Material for screw connection | Brass, nickel-plated |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                                                                                                                    |
|---------------------------------|--------------------------------------------------------------------------------------------------------------------|
| Degree of protection            | IP66 (using the corresponding A-SEW-...P-W flat gasket)<br>IP68 (using the corresponding A-SEW-...P-W flat gasket) |
| Ambient temperature (operation) | -60 °C ... 130 °C                                                                                                  |

### Approvals

Sira 01ATEX1284U

# A-EXSH-M20-68L-N-S - Screw plug



1411104

<https://www.phoenixcontact.com/us/products/1411104>

|       |                                                      |
|-------|------------------------------------------------------|
| ATEX  | Sira 02ATEX1003X                                     |
|       | Ex II 2 GD Ex d IIC & Ex e II, Ex IM2 Ex d I, Ex e I |
| IECEX | IECEX SIR 07.0056X                                   |
|       | Ex d I / Ex e I / Ex d IIC / Ex e II, Ex tD A21 IP6X |

## Standards and regulations

### EN Ex

|                          |                    |
|--------------------------|--------------------|
| Standards/specifications | EN 60079-0, -1, -7 |
|--------------------------|--------------------|

### IEC Ex

|                          |                     |
|--------------------------|---------------------|
| Standards/specifications | IEC 60079-0, -1, -7 |
|--------------------------|---------------------|

### EN Ex

|                          |                |
|--------------------------|----------------|
| Standards/specifications | EN 61241-0, -1 |
|--------------------------|----------------|

### IEC Ex

|                          |                 |
|--------------------------|-----------------|
| Standards/specifications | IEC 61241-0, -1 |
|--------------------------|-----------------|

## Mounting

|               |                                                                                      |
|---------------|--------------------------------------------------------------------------------------|
| Assembly note | Sealed to IP66/IP68 thanks to the use of the A-SEW-20-P-W flat gasket (item 1411283) |
|---------------|--------------------------------------------------------------------------------------|

# A-EXSH-M20-68L-N-S - Screw plug


1411104

<https://www.phoenixcontact.com/us/products/1411104>



## Drawings

Dimensional drawing

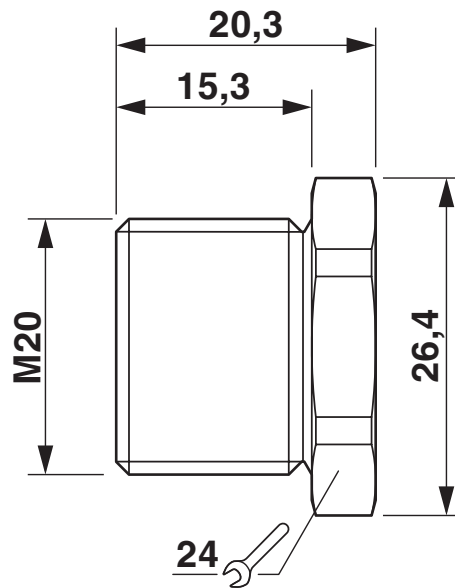

# A-EXSH-M20-68L-N-S - Screw plug



1411104

<https://www.phoenixcontact.com/us/products/1411104>

## Approvals

 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1411104>



**CSA**

Approval ID: 113642



**UL Listed**

Approval ID: E214221



**ATEX**

Approval ID: CML 18ATEX1320X

# A-EXSH-M20-68L-N-S - Screw plug



1411104

<https://www.phoenixcontact.com/us/products/1411104>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 23111190 |
| ECLASS-15.0 | 23111190 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000032 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# A-EXSH-M20-68L-N-S - Screw plug



1411104

<https://www.phoenixcontact.com/us/products/1411104>

## Environmental product compliance

### EU RoHS

|                                         |      |
|-----------------------------------------|------|
| Fulfills EU RoHS substance requirements | Yes  |
| Exemption                               | 6(c) |

### China RoHS

|                                        |                                                                                                                                                                                                                                   |
|----------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-50                                                                                                                                                                                                                           |
|                                        | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

### EU REACH SVHC

|                                     |                                      |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: n/a)                       |
| SCIP                                | b5c2a053-1146-4c31-89a1-c45da3e1e2d1 |

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)