

SAC-12P-MS 4B SCO D-B - Short-circuit connector



1446841

<https://www.phoenixcontact.com/us/products/1446841>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Short-circuit connector, Plug straight M12, coding: A, Customer version

Commercial data

Item number	1446841
Packing unit	10 pc
Minimum order quantity	100 pc
Sales key	BF03
Product key	AF1CGA
GTIN	4046356691345
Weight per piece (including packing)	16.32 g
Weight per piece (excluding packing)	16.01 g
Customs tariff number	85366990
Country of origin	DE

SAC-12P-MS 4B SCO D-B - Short-circuit connector



1446841

<https://www.phoenixcontact.com/us/products/1446841>

Technical data

Product properties

Product type	Sensor/actuator cable
Coding	A

Insulation characteristics

Overvoltage category	II
Degree of pollution	3

Material specifications

Seal material	FKM
Material of grip body	TPU, hardly inflammable, self-extinguishing
Contact material	CuZn
Contact surface material	Ni/Au
Contact carrier material	PA 6.6
Material for screw connection	Zinc die-cast, nickel-plated

Electrical properties

Nominal voltage U_N	30 V AC
	30 V DC
Nominal current I_N	1.5 A

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	------------

Connection data

Connection technology

Connection method	Piercecon® fast connection
-------------------	----------------------------

Conductor connection

Connection method	Piercecon® fast connection
Tightening torque	0.4 Nm

Connection assignment

Contact Color (signal designation) Contact (optional)	1 (Plug) 5 (Plug)
	2 (Plug) 7 (Plug)
	3 (Plug) 11 (Plug)
	6 (Plug) 10 (Plug)

Connector

Connection 1

Type	Plug straight M12
------	-------------------

SAC-12P-MS 4B SCO D-B - Short-circuit connector



1446841

<https://www.phoenixcontact.com/us/products/1446841>

Number of positions	12
Coding type	A

Cable/line

Cable cross section	0.14 mm ²
---------------------	----------------------

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP68
Ambient temperature (operation)	-25 °C ... 85 °C (Plug)

SAC-12P-MS 4B SCO D-B - Short-circuit connector




1446841

<https://www.phoenixcontact.com/us/products/1446841>

Drawings

Schematic diagram

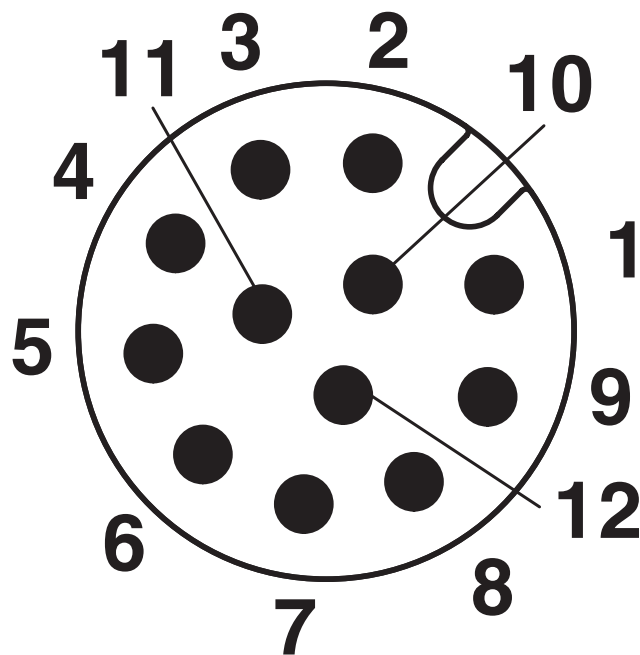

Pin assignment M12 male connector, 12-pos., male side view

SAC-12P-MS 4B SCO D-B - Short-circuit connector



1446841

<https://www.phoenixcontact.com/us/products/1446841>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1446841>

UL Listed Approval ID: E221474				
	Nominal voltage U_N	Nominal current I_N	Cross section AWG	Cross section mm^2
keine				
	30 V	1 A	-	-

SAC-12P-MS 4B SCO D-B - Short-circuit connector



1446841

<https://www.phoenixcontact.com/us/products/1446841>

Classifications

ECLASS

ECLASS-13.0	27060311
ECLASS-15.0	27060311

ETIM

ETIM 9.0	EC001855
----------	----------

UNSPSC

UNSPSC 21.0	26121600
-------------	----------

SAC-12P-MS 4B SCO D-B - Short-circuit connector



1446841

<https://www.phoenixcontact.com/us/products/1446841>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com