

# HC-B 6-ADP/2 DSUB 9 - Adapter plate



1775460

<https://www.phoenixcontact.com/us/products/1775460>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

D-SUB adapter plate, for two D-SUB connectors, no. of positions 9, housing series HC-B 6...



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1775460       |
| Packing unit                         | 2 pc          |
| Minimum order quantity               | 2 pc          |
| Sales key                            | BF66          |
| Product key                          | AF7AZD        |
| GTIN                                 | 4017918038069 |
| Weight per piece (including packing) | 14.9 g        |
| Weight per piece (excluding packing) | 14 g          |
| Customs tariff number                | 39269097      |
| Country of origin                    | DE            |

# HC-B 6-ADP/2 DSUB 9 - Adapter plate

1775460

<https://www.phoenixcontact.com/us/products/1775460>

## Technical data


### Notes

|         |                   |
|---------|-------------------|
| General | For housing HC-B6 |
|---------|-------------------|

### Product properties

|                     |               |
|---------------------|---------------|
| Product type        | Adapter plate |
| Type                | B6            |
| Number of positions | 9             |
| Seal present        | no            |

### Dimensions
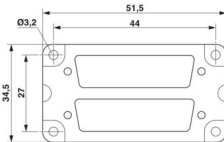
|                     |                                                                                     |
|---------------------|-------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 34.5 mm                                                                             |
| Height              | 10 mm                                                                               |
| Length              | 51.5 mm                                                                             |

### Material specifications

|                                        |    |
|----------------------------------------|----|
| Material                               | PA |
| Flammability rating according to UL 94 | HB |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -20 °C ... 100 °C |
|---------------------------------|-------------------|

### Mounting

|               |                                                                                                                                                                                                                                                                                                                                                                                                      |
|---------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Assembly note | <p>Mounting position of the adapter plate in the sleeve housing: <b>T</b> is visible after mounting in the housing. Mounting position of the adapter plate in the panel mounting base/socket</p> <p>housing/coupling housing: <b>A</b> is visible after mounting in the housing. Mounting position of the D-SUB (after mounting in the housing): in front of the mounting panel (front mounting)</p> |
|---------------|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|


# HC-B 6-ADP/2 DSUB 9 - Adapter plate



1775460

<https://www.phoenixcontact.com/us/products/1775460>

## Drawings

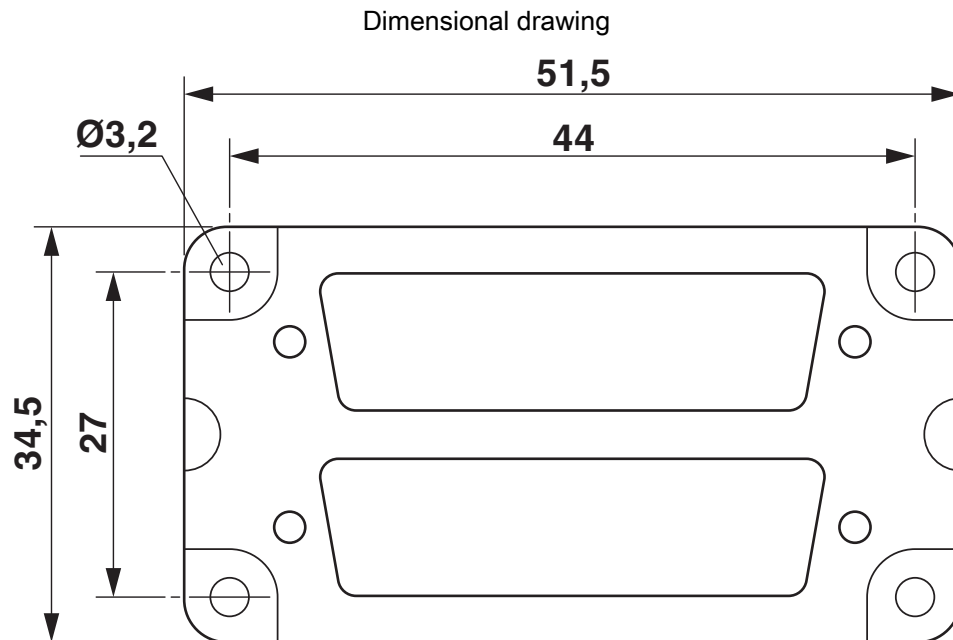

See assembly instruction

# HC-B 6-ADP/2 DSUB 9 - Adapter plate

1775460

<https://www.phoenixcontact.com/us/products/1775460>



## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1775460>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-B 6-ADP/2 DSUB 9 - Adapter plate



1775460

<https://www.phoenixcontact.com/us/products/1775460>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002309 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-B 6-ADP/2 DSUB 9 - Adapter plate



1775460

<https://www.phoenixcontact.com/us/products/1775460>

## Environmental product compliance

### EU RoHS

|                                         |              |
|-----------------------------------------|--------------|
| Fulfills EU RoHS substance requirements | Yes          |
| Exemption                               | 6(a), 6(a)-I |

### China RoHS

|                                        |                                                                                                                                                                                                                                   |
|----------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-50                                                                                                                                                                                                                           |
|                                        | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

### EU REACH SVHC

|                                     |                                      |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: n/a)                       |
| SCIP                                | 8ac80385-eded-4122-812b-ad05dabef550 |

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)