

# HC-B 10-ADP/1 DSUB 25 - Adapter plate



1775499

<https://www.phoenixcontact.com/us/products/1775499>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

D-SUB adapter plate, for one D-SUB connector, no. of positions 25, housing series HC-B 10...



## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 1775499       |
| Packing unit                         | 2 pc          |
| Minimum order quantity               | 2 pc          |
| Sales key                            | BF66          |
| Product key                          | AF7AZD        |
| GTIN                                 | 4017918038090 |
| Weight per piece (including packing) | 15.62 g       |
| Weight per piece (excluding packing) | 15 g          |
| Customs tariff number                | 39269097      |
| Country of origin                    | DE            |

# HC-B 10-ADP/1 DSUB 25 - Adapter plate



1775499

<https://www.phoenixcontact.com/us/products/1775499>

## Technical data


### Notes

|         |                    |
|---------|--------------------|
| General | For housing HC-B10 |
|---------|--------------------|

### Product properties

|                     |               |
|---------------------|---------------|
| Product type        | Adapter plate |
| Type                | B10           |
| Number of positions | 25            |
| Seal present        | no            |

### Dimensions
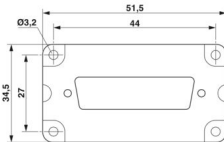
|                     |                                                                                     |
|---------------------|-------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Width               | 34.5 mm                                                                             |
| Height              | 10 mm                                                                               |
| Length              | 64.5 mm                                                                             |

### Material specifications

|                                        |    |
|----------------------------------------|----|
| Material                               | PA |
| Flammability rating according to UL 94 | HB |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -20 °C ... 100 °C |
|---------------------------------|-------------------|

### Mounting

|               |                                                                                                                                                                                                                                                                                                                                                                                               |
|---------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Assembly note | <p>Mounting position of the adapter plate in the sleeve housing: <b>T</b> is visible after mounting in the housing. Mounting position of the adapter plate in the panel mounting base/socket housing/coupling housing: <b>A</b> is visible after mounting in the housing. Mounting position of the D-SUB (after mounting in the housing): in front of the mounting panel (front mounting)</p> |
|---------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|


# HC-B 10-ADP/1 DSUB 25 - Adapter plate



1775499

<https://www.phoenixcontact.com/us/products/1775499>

## Drawings

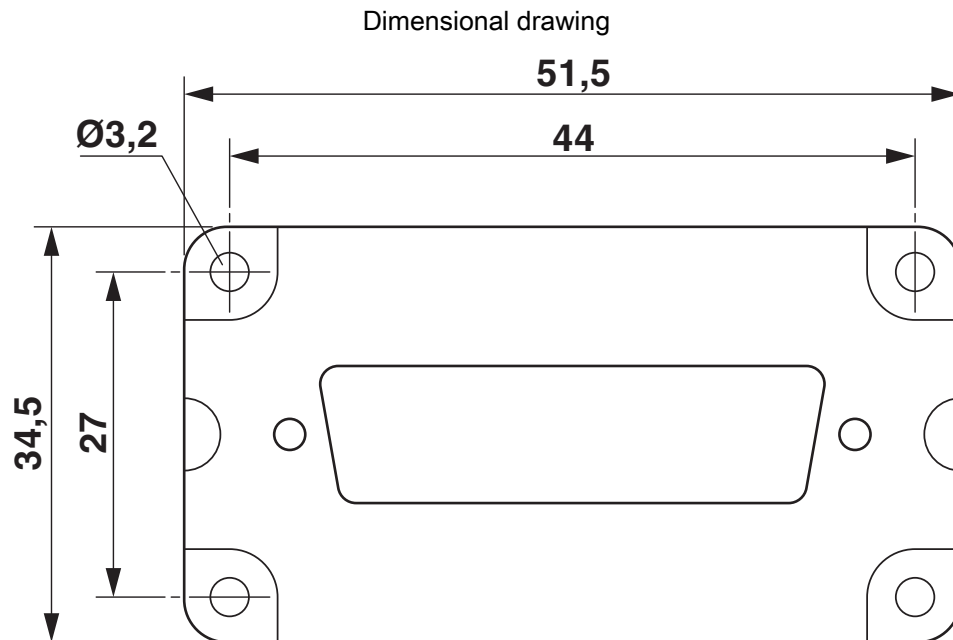

See assembly instruction

# HC-B 10-ADP/1 DSUB 25 - Adapter plate



1775499

<https://www.phoenixcontact.com/us/products/1775499>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1775499>



**EAC**

Approval ID: RU C-DE.AI30.B.01102

# HC-B 10-ADP/1 DSUB 25 - Adapter plate



1775499

<https://www.phoenixcontact.com/us/products/1775499>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27440201 |
| ECLASS-15.0 | 27440201 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002309 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

# HC-B 10-ADP/1 DSUB 25 - Adapter plate



1775499

<https://www.phoenixcontact.com/us/products/1775499>

## Environmental product compliance

### EU RoHS

|                                         |              |
|-----------------------------------------|--------------|
| Fulfills EU RoHS substance requirements | Yes          |
| Exemption                               | 6(a), 6(a)-I |

### China RoHS

|                                        |                                                                                                                                                                                                                                   |
|----------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-50                                                                                                                                                                                                                           |
|                                        | An article-related China RoHS declaration table can be found in the download area for the respective article under "Manufacturer declaration". For all articles with EFUP-E, no China RoHS declaration table issued and required. |

### EU REACH SVHC

|                                     |                                      |
|-------------------------------------|--------------------------------------|
| REACH candidate substance (CAS No.) | Lead(CAS: n/a)                       |
| SCIP                                | 8f49962a-64ff-45bb-8f8f-c5273c1f24e4 |

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)