

IL BK DIO-PLSET/SCN 12 - Connector set




2701004

<https://www.phoenixcontact.com/us/products/2701004>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Connector set for Inline bus coupler with integrated I/Os (IL ... BK DI8 DO4-PAC)

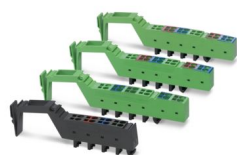

Commercial data

Item number	2701004
Packing unit	1 pc
Minimum order quantity	1 pc
Product key	DRI1Z1
GTIN	4046356679015
Weight per piece (including packing)	86.6 g
Weight per piece (excluding packing)	85.5 g
Country of origin	DE

IL BK DIO-PLSET/SCN 12 - Connector set



2701004

<https://www.phoenixcontact.com/us/products/2701004>

Technical data

Product properties

Product type	Connector set
Application	Inline bus coupler

Connection data

Connection method	Spring-cage connection
Conductor cross-section, rigid	0.08 mm ² ... 1.5 mm ²
Conductor cross-section, flexible	0.08 mm ² ... 1.5 mm ²
Conductor cross-section AWG	28 ... 16
Stripping length	8 mm

IL BK DIO-PLSET/SCN 12 - Connector set



2701004

<https://www.phoenixcontact.com/us/products/2701004>

Classifications

ECLASS

ECLASS-13.0	27242692
-------------	----------

ETIM

ETIM 9.0	EC002584
----------	----------

UNSPSC

UNSPSC 21.0	32151600
-------------	----------

IL BK DIO-PLSET/SCN 12 - Connector set



2701004

<https://www.phoenixcontact.com/us/products/2701004>

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com