

UM 108-PROFIL 100CM - Profile

2907525

<https://www.phoenixcontact.com/us/products/2907525>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, Basic profile, open, profile width (internal): 122.6 mm, profile width (external): 107.5 mm, length: 1000 mm, depth: 21.5 mm, Note: required profile length = PCB length - 3.6 mm



Your advantages

- Easy installation
- Flexible size and shape
- Inexpensive as a result of reducing the number of separate housing parts

Commercial data

Item number	2907525
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	AC13
Product key	ACHDBA
GTIN	4017918336653
Weight per piece (including packing)	605 g
Weight per piece (excluding packing)	605 g
Customs tariff number	39162000
Country of origin	DE

UM 108-PROFIL 100CM - Profile

2907525

<https://www.phoenixcontact.com/us/products/2907525>




Technical data

Product properties

Product type	Component housing lower part
Housing type	Press-drawn section housings
Housing series	UM
Product family	UM108
Ventilation openings present	no

Dimensions

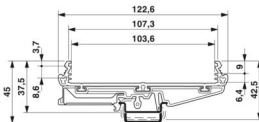Dimensional drawing	
Depth	21.5 mm
Length	100 cm

External dimensions

Profile width (external)	107.5 mm
--------------------------	----------

Internal dimensions

Profile width (internal)	122.6 mm
--------------------------	----------

PCB design

PCB thickness	1.4 mm ... 1.8 mm
---------------	-------------------

Material specifications

Color (Housing)	green (RAL 6021)
Flammability rating according to UL 94	V0
Housing material	PVC

Environmental and real-life conditions

Ambient conditions

Max. IP code to attain	IP20
Ambient temperature (operation)	-15 °C ... 50 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 50 °C
Ambient temperature (assembly)	-5 °C ... 50 °C
Relative humidity (storage/transport)	95 %

PCB data

Number of PCB holders	2
Thickness of the PCB	1.4 mm ... 1.8 mm

Mounting

UM 108-PROFIL 100CM - Profile

2907525

<https://www.phoenixcontact.com/us/products/2907525>



Mounting position	parallel to the DIN rail
-------------------	--------------------------

Packaging specifications

Type of packaging	packed in cardboard
Outer packaging type	Carton


UM 108-PROFIL 100CM - Profile

2907525

<https://www.phoenixcontact.com/us/products/2907525>



Drawings

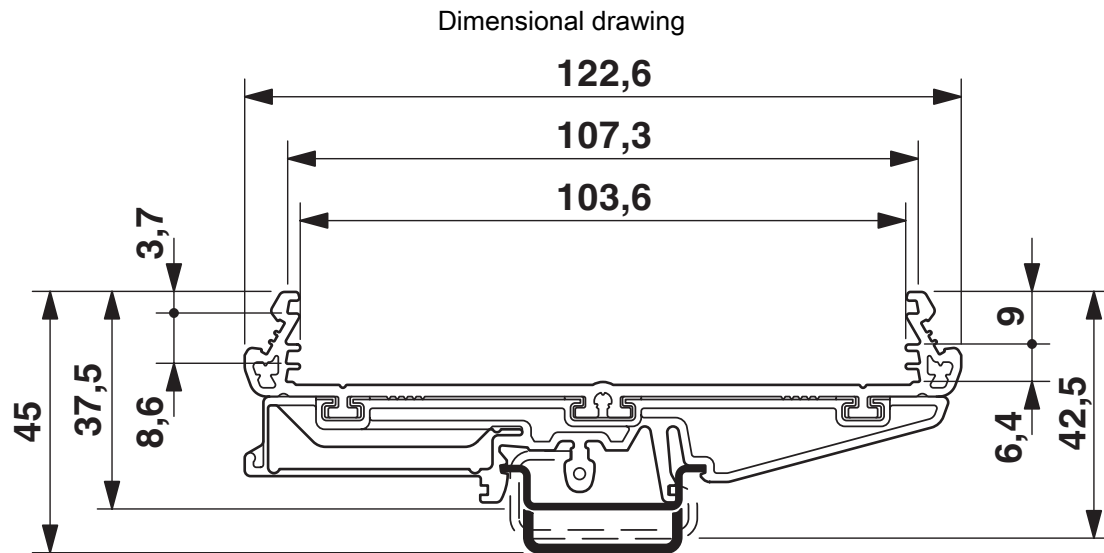

UM 108-PROFIL 100CM - Profile

2907525

<https://www.phoenixcontact.com/us/products/2907525>



Classifications

ECLASS

ECLASS-13.0	27190601
ECLASS-15.0	27190601

ETIM

ETIM 9.0	EC002779
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

UM 108-PROFIL 100CM - Profile

2907525

<https://www.phoenixcontact.com/us/products/2907525>



Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

China RoHS

Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com