

# HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/us/products/1346553>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover D50, with double locking latch, protective cover material: PC, height: 29 mm, seal: yes

## Commercial data

Item number	1346553
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	BF66
Product key	AF7AZC
GTIN	4063151660918
Weight per piece (including packing)	59.4 g
Weight per piece (excluding packing)	82.3 g
Customs tariff number	85389099
Country of origin	CN

# HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/us/products/1346553>

## Technical data

 
### Notes

General	Protective cover for sleeve housings for double locking latch
---------	---

### Product properties

Product type	Protective cover
Housing type	Protective cover
Type	D50
Retaining cord present	yes
Seal present	yes

### Dimensions

Dimensional drawing	
Width	69.2 mm
Height	29 mm
Length	86.5 mm
Diameter	40 mm

### Material specifications

Material Protective cover	PC
Flammability rating according to UL 94	V0
Seal material	NBR
Material, protective cover	PC

### Environmental and real-life conditions

#### Ambient conditions

Degree of protection	IP66
Ambient temperature (operation)	-40 °C ... 125 °C
Resistance to UV radiation	yes

### Mounting

Assembly note	Double eyelet for mounting on a cable / below screw head
	Plastic protective cover for short-term protection


# HC-D50-HCWD-PLR-BK - Protective cover

1346553

<https://www.phoenixcontact.com/us/products/1346553>

## Drawings

Dimensional drawing

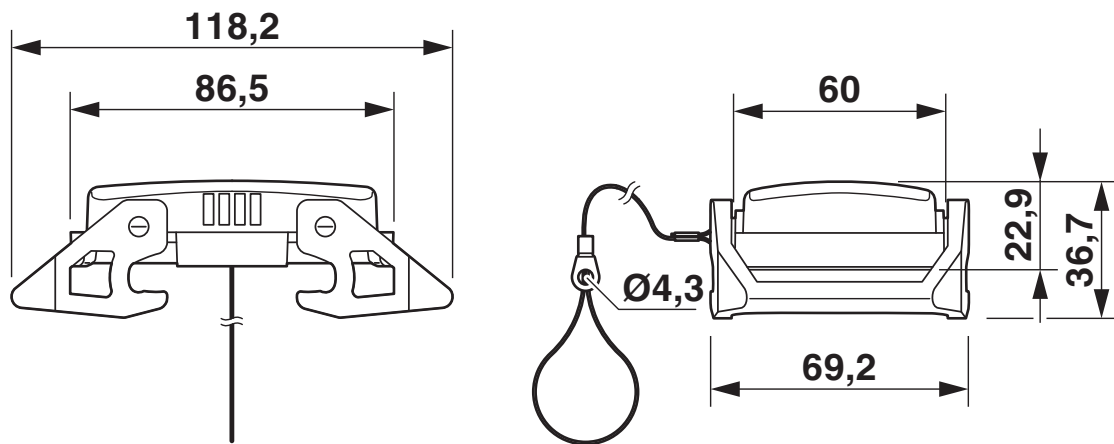

Dimensional drawing

# HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/us/products/1346553>

## Approvals

🔗 To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1346553>

### DNV

Approval ID: TAE000037S

# HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/us/products/1346553>

## Classifications

### ECLASS

ECLASS-13.0	27440208
ECLASS-15.0	27440208

### ETIM

ETIM 9.0	EC002314
----------	----------

### UNSPSC

UNSPSC 21.0	39121400
-------------	----------

# HC-D50-HCWD-PLR-BK - Protective cover



1346553

<https://www.phoenixcontact.com/us/products/1346553>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)