

# SEALING PLUG 10X16 RD - Sealing plug



1400284

<https://www.phoenixcontact.com/us/products/1400284>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sealing plug, for threads pluggable, color: red

## Commercial data

Item number	1400284
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BF68
Product key	AF7DZX
GTIN	4046356482004
Weight per piece (including packing)	1.38 g
Weight per piece (excluding packing)	1.062 g
Customs tariff number	39235090
Country of origin	DE

# SEALING PLUG 10X16 RD - Sealing plug



1400284


<https://www.phoenixcontact.com/us/products/1400284>

## Technical data

### Product properties

Product type	Sealing plugs
Thread type	pluggable

### Dimensions

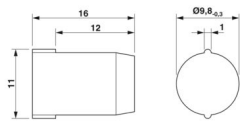Dimensional drawing		
Width	9.80 mm	
Length	16 mm	
Diameter	9.8 mm	
	9.8 mm	
Thread type connection side	pluggable	

### Material specifications

Material	PA
----------	----

### Environmental and real-life conditions

#### Ambient conditions

Ambient temperature (operation)	-60 °C ... 100 °C
---------------------------------	-------------------

### Mounting

Assembly note	The head of the sealing plug must still be visible after mounting in the screw connection (see "after mounting" photo).
---------------	-------------------------------------------------------------------------------------------------------------------------

# SEALING PLUG 10X16 RD - Sealing plug


1400284

<https://www.phoenixcontact.com/us/products/1400284>



## Drawings

Dimensional drawing

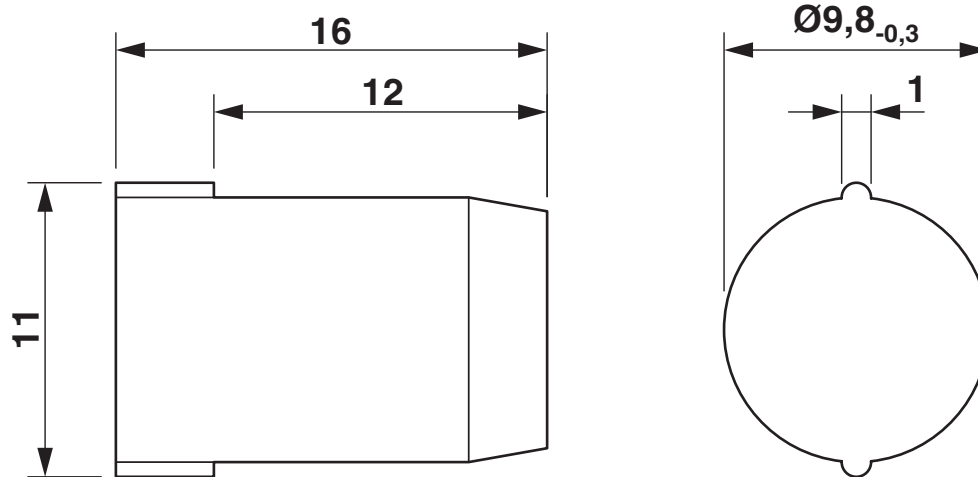

Dimensional drawing

# SEALING PLUG 10X16 RD - Sealing plug



1400284

<https://www.phoenixcontact.com/us/products/1400284>

## Classifications

### ECLASS

ECLASS-13.0	23111190
ECLASS-15.0	23111190

### ETIM

ETIM 9.0	EC000032
----------	----------

### UNSPSC

UNSPSC 21.0	39121300
-------------	----------

# SEALING PLUG 10X16 RD - Sealing plug



1400284  
<https://www.phoenixcontact.com/us/products/1400284>

## Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%
EF3.0 Climate Change	
CO2e kg	0.017 kg CO2e

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)