

HC-COM-K-SD-FLU-BU/FS - Protective cover



1408397

<https://www.phoenixcontact.com/us/products/1408397>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Protective cover for HC-COM-K housing... for female contact inserts



Commercial data

Item number	1408397
Packing unit	1 pc
Note	Made to order (non-returnable)
Sales key	BF66
Product key	AF7AZC
GTIN	4046356618137
Weight per piece (including packing)	13 g
Weight per piece (excluding packing)	13 g
Customs tariff number	39269097
Country of origin	CN

HC-COM-K-SD-FLU-BU/FS - Protective cover



1408397

 
<https://www.phoenixcontact.com/us/products/1408397>

Technical data

Product properties

Product type	Protective cover
Housing type	Protective cover
Type	COM

Dimensions

Dimensional drawing	
Width	29 mm
Height	23.5 mm
Length	48.5 mm

Material specifications

Material Protective cover	PC
Flammability rating according to UL 94	V0
Material, protective cover	PC

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP54
Ambient temperature (operation)	-40 °C ... 100 °C

HC-COM-K-SD-FLU-BU/FS - Protective cover


1408397

<https://www.phoenixcontact.com/us/products/1408397>



Drawings

Dimensional drawing

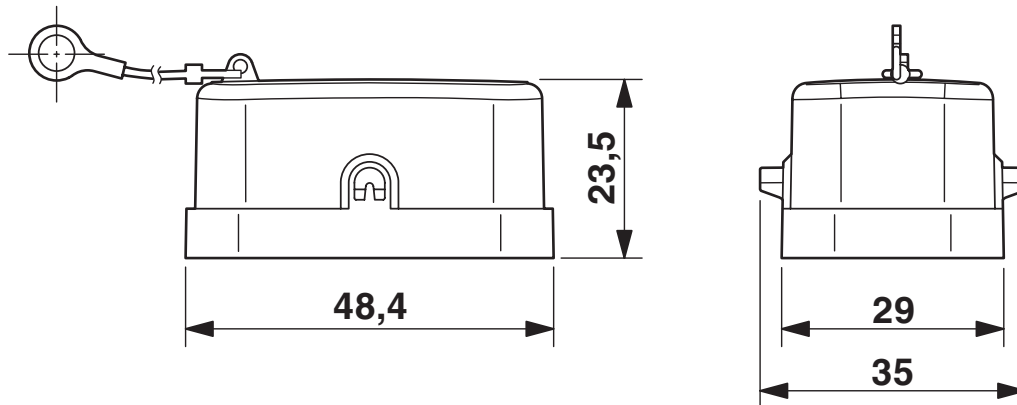

Dimensional drawing

HC-COM-K-SD-FLU-BU/FS - Protective cover



1408397

<https://www.phoenixcontact.com/us/products/1408397>

Classifications

ECLASS

ECLASS-13.0	27440208
ECLASS-15.0	27440208

ETIM

ETIM 8.0	EC002314
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%