

HC-B 24-TMS-SD-IP50-OLOGO - Protective cover

1690846

<https://www.phoenixcontact.com/us/products/1690846>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Protective cover B24, Clip locking, protective cover material: PA, height: 31.2 mm, seal: no, with lanyard

Commercial data

Item number	1690846
Packing unit	10 pc
Minimum order quantity	1 pc
Product key	AF7AZC
GTIN	4017918890735
Weight per piece (including packing)	46.2 g
Weight per piece (excluding packing)	39.6 g
Country of origin	DE

HC-B 24-TMS-SD-IP50-OLOGO - Protective cover

1690846

<https://www.phoenixcontact.com/us/products/1690846>

 


Technical data

Product properties

Product type	Protective cover
Housing type	Protective cover
Type	B24
Seal present	no

Dimensions

Dimensional drawing	
	
Width	55 mm
Height	31.2 mm
Length	150 mm

Material specifications

Flammability rating according to UL 94	V0
Material, protective cover	PA

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP50
Ambient temperature (operation)	-20 °C ... 100 °C

HC-B 24-TMS-SD-IP50-OLOGO - Protective cover


1690846

<https://www.phoenixcontact.com/us/products/1690846>



Drawings

Dimensional drawing

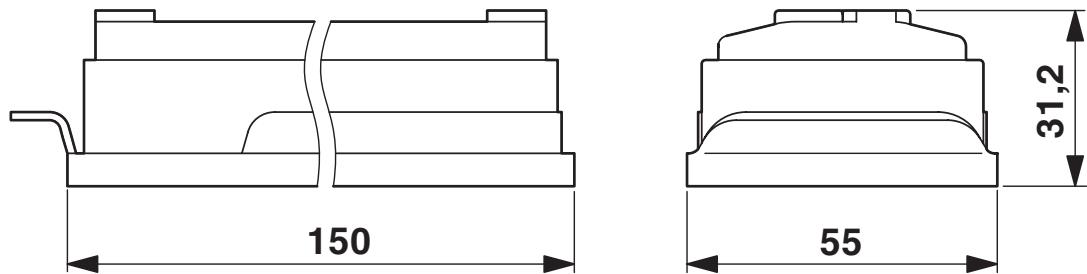

Dimensional drawing

HC-B 24-TMS-SD-IP50-OLOGO - Protective cover

1690846

<https://www.phoenixcontact.com/us/products/1690846>



Classifications

ECLASS

ECLASS-13.0

27440208

Environmental product compliance

EU RoHS

Fulfills EU RoHS substance requirements	Yes, No exemptions
---	--------------------

EU REACH SVHC

REACH candidate substance (CAS No.)	No substance above 0.1 wt%
-------------------------------------	----------------------------

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA

586 Fulling Mill Road

Middletown, PA 17057, United States

(+717) 944-1300

info@phoenixcon.com