

# IPCC 16- 4-MT - Crimp contact

1733385

<https://www.phoenixcontact.com/us/products/1733385>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Single crimp pin contact for flexible cable with 4 mm<sup>2</sup> cross section.

## Commercial data

|                                      |                                |
|--------------------------------------|--------------------------------|
| Item number                          | 1733385                        |
| Packing unit                         | 100 pc                         |
| Minimum order quantity               | 100 pc                         |
| Note                                 | Made to order (non-returnable) |
| Sales key                            | AA08                           |
| Product key                          | AAHZAF                         |
| GTIN                                 | 4046356282796                  |
| Weight per piece (including packing) | 1.93 g                         |
| Weight per piece (excluding packing) | 1.891 g                        |
| Customs tariff number                | 85366990                       |
| Country of origin                    | DE                             |

# IPCC 16- 4-MT - Crimp contact

1733385

<https://www.phoenixcontact.com/us/products/1733385>



## Technical data

### Product properties

|                       |               |
|-----------------------|---------------|
| Product type          | Crimp contact |
| Product family        | IPCC 16-MT    |
| Series                | VC-D          |
| Pitch                 | 0 mm          |
| Contact material type | rolled        |

 
### Connection data

|                                         |                   |
|-----------------------------------------|-------------------|
| Connection method                       | Crimp connection  |
| Contact connection type                 | Pin               |
| Connection technology                   | Crimp connection  |
| Conductor cross section                 | 4 mm <sup>2</sup> |
| Stripping length of the individual wire | 8 mm              |

### Material specifications

|                                        |         |
|----------------------------------------|---------|
| Contact surface                        | Tin Sn  |
| Contact surface material               | Tin     |
| Metal surface contact area (top layer) | Tin Sn) |

### Dimensions

|                     |                                                                                      |
|---------------------|--------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Pitch               | -                                                                                    |

### Mechanical characteristics

|                  |        |
|------------------|--------|
| Contact diameter | 3.4 mm |
|------------------|--------|

### Electrical properties

|                      |      |
|----------------------|------|
| Maximum load current | 32 A |
| Rated current        | 32 A |

### Mechanical properties

#### Mechanical data

|                             |       |
|-----------------------------|-------|
| Insertion/withdrawal cycles | >= 25 |
|-----------------------------|-------|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -40 °C ... 100 °C |
|---------------------------------|-------------------|

# IPCC 16- 4-MT - Crimp contact


1733385

<https://www.phoenixcontact.com/us/products/1733385>



## Drawings

Dimensional drawing

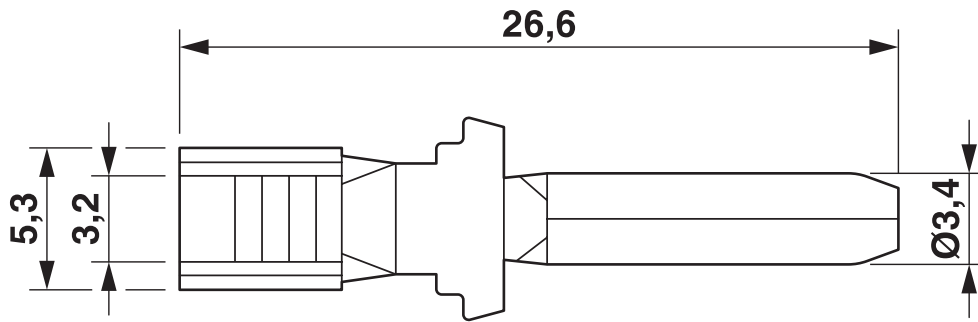

# IPCC 16- 4-MT - Crimp contact

1733385

<https://www.phoenixcontact.com/us/products/1733385>



## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27460403 |
| ECLASS-15.0 | 27460403 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000796 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121500 |
|-------------|----------|

# IPCC 16- 4-MT - Crimp contact

1733385

<https://www.phoenixcontact.com/us/products/1733385>



## Environmental product compliance

|                                         |                                          |
|-----------------------------------------|------------------------------------------|
| EU RoHS                                 |                                          |
| Fulfills EU RoHS substance requirements | Yes, No exemptions                       |
| China RoHS                              |                                          |
| Environment friendly use period (EFUP)  | EFUP-E                                   |
|                                         | No hazardous substances above the limits |
| EU REACH SVHC                           |                                          |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt%               |
| EF3.0 Climate Change                    |                                          |
| CO2e kg                                 | 0.005 kg CO2e                            |

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)