

2906225

<https://www.phoenixcontact.com/us/products/2906225>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Drawn section panel mounting base, with a constructional width of 72 mm and a fixed length of 200 cm



Commercial data


|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 2906225       |
| Packing unit                         | 1 pc          |
| Minimum order quantity               | 1 pc          |
| Sales key                            | AC13          |
| Product key                          | ACHDBA        |
| GTIN                                 | 4017918277437 |
| Weight per piece (including packing) | 890.63 g      |
| Weight per piece (excluding packing) | 890.63 g      |
| Customs tariff number                | 39162000      |
| Country of origin                    | DE            |

## Technical data

### Product properties

|                              |                              |
|------------------------------|------------------------------|
| Product type                 | Component housing lower part |
| Housing type                 | Press-drawn section housings |
| Housing series               | UM                           |
| Product family               | UM72                         |
| Ventilation openings present | no                           |

### Dimensions
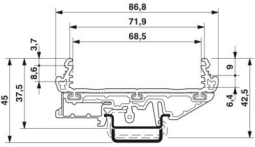
|                     |                                                                                    |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Depth               | 21.5 mm                                                                            |
| Length              | 2 m                                                                                |

#### External dimensions

|                          |         |
|--------------------------|---------|
| Profile width (external) | 86.8 mm |
|--------------------------|---------|

#### Internal dimensions

|                          |         |
|--------------------------|---------|
| Profile width (internal) | 71.9 mm |
|--------------------------|---------|

### Material specifications


|                         |                  |
|-------------------------|------------------|
| Color (Housing)         | green (RAL 6021) |
| Material Housing        | PVC              |
| Surface characteristics | untreated        |

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                  |
|---------------------------------|------------------|
| Ambient temperature (operation) | -15 °C ... 50 °C |
|---------------------------------|------------------|

## Drawings

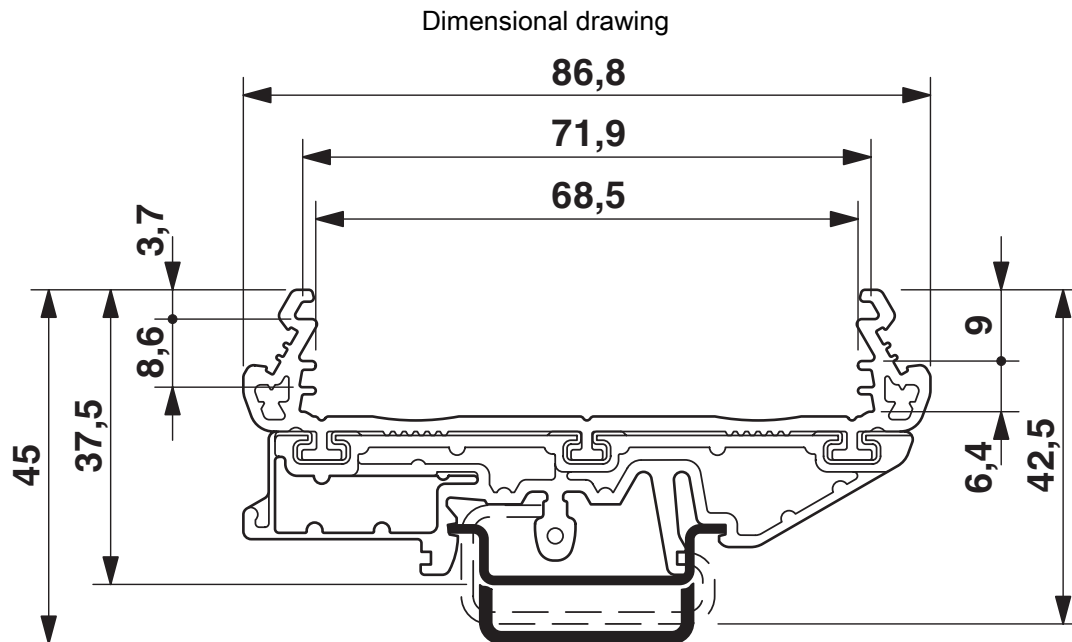

2906225

<https://www.phoenixcontact.com/us/products/2906225>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27190601 |
| ECLASS-15.0 | 27190601 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC002779 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 31261500 |
|-------------|----------|

## Environmental product compliance

## EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

## China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

## EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|