

APK-TU - Cover

5022805

<https://www.phoenixcontact.com/us/products/5022805>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Cover profile holder, 10 mm wide, for mounting on NS 32 or NS 35/7.5, for fixing the holding profile APK-HP, labeling with Zack strip ZB 10



Your advantages

- Can be labeled
- Protection against accidental actuation of terminal points or disconnect terminal blocks
- Covering of live parts

Commercial data

Item number	5022805
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BE07
Product key	BE61ZX
GTIN	4017918095307
Weight per piece (including packing)	8.5 g
Weight per piece (excluding packing)	8.35 g
Customs tariff number	39269097
Country of origin	DE

APK-TU - Cover



5022805


<https://www.phoenixcontact.com/us/products/5022805>

Technical data

Product properties

Product type	Cover profile
--------------	---------------

Dimensions

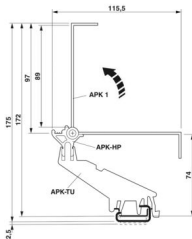Dimensional drawing	
Width	10 mm

Material specifications


Color	gray (RAL 7042)
Material	PA
Flammability rating according to UL 94	V2
Components	free from silicone and halogen

Environmental and real-life conditions

Ambient conditions	
Ambient temperature (operation)	-60 °C ... 105 °C (max. short-term operating temperature RTI Elec.)
Ambient temperature (storage/transport)	-25 °C ... 60 °C (for a short time, not exceeding 24 h, -60 °C to +70 °C)
Ambient temperature (assembly)	-5 °C ... 70 °C
Ambient temperature (actuation)	-5 °C ... 70 °C
Permissible humidity (storage/transport)	30 % ... 70 %

Drawings

Dimensional drawing

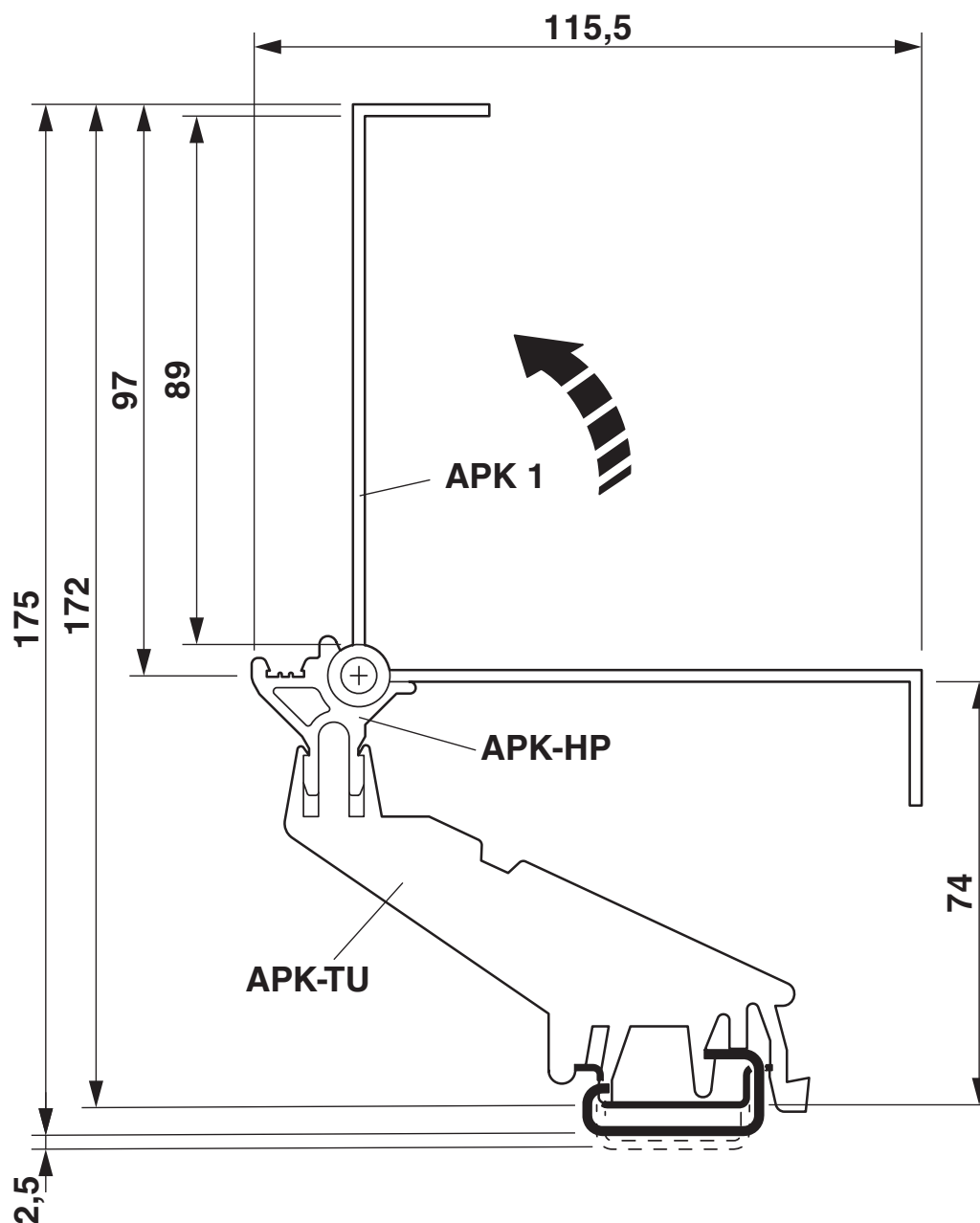

5022805

<https://www.phoenixcontact.com/us/products/5022805>

Classifications

ECLASS

ECLASS-13.0	27371392
ECLASS-15.0	27371392

ETIM

ETIM 9.0	EC002498
----------	----------

UNSPSC

UNSPSC 21.0	39121100
-------------	----------

APK-TU - Cover



5022805
<https://www.phoenixcontact.com/us/products/5022805>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com