

UM-ALU 4-100,5 COVER PA BK - Lateral element



2200952

<https://www.phoenixcontact.com/in/products/2200952>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Press-drawn section housings, Screw mounting, Side elements (left and right) incl. snap-on foot and screws for basic profile, width: 105.4 mm



Your advantages

- Aluminum extruded profile
- Variety of connection technology
- Can be mounted on the DIN rail
- Available in lengths from 42.5 mm ... 990 mm, can be cut to any length
- Available in overall widths of 75 mm and 105 mm
- EMC protection

Commercial data

Item number	2200952
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	ACH
Product key	ACHDFA
GTIN	4046356716543
Weight per piece (including packing)	25.68 g
Weight per piece (excluding packing)	25.68 g
Customs tariff number	39269097
Country of origin	HU

UM-ALU 4-100,5 COVER PA BK - Lateral element



2200952

<https://www.phoenixcontact.com/in/products/2200952>

Technical data

Product properties

Product type	Panel mounting base side part
Housing type	Press-drawn section housings
Housing series	UM-ALU
Product family	UM-ALU 4-100,5
Ventilation openings present	no

Dimensions

Width	105.4 mm
-------	----------

Material specifications

Color (Housing)	black (RAL 9005)
Material	PA
Flammability rating according to UL 94	V0
Surface characteristics	untreated

Environmental and real-life conditions

Ambient conditions

Max. IP code to attain	IP40
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	80 %

Mounting

Mounting type	Screw mounting
Tightening torque / speed	Screw connection with the basic profile: 0.8 Nm-1 Nm / rpm- rpm

Packaging specifications

Type of packaging	packed in cardboard
Outer packaging type	Carton

UM-ALU 4-100,5 COVER PA BK - Lateral element



2200952

<https://www.phoenixcontact.com/in/products/2200952>

Classifications

ECLASS

ECLASS-13.0	27190602
ECLASS-15.0	27190602

ETIM

ETIM 9.0	EC002779
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

UM-ALU 4-100,5 COVER PA BK - Lateral element



2200952

<https://www.phoenixcontact.com/in/products/2200952>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

UM-ALU 4-100,5 COVER PA BK - Lateral element



2200952


<https://www.phoenixcontact.com/in/products/2200952>

Accessories

UM-ALU 4-100,5 PROFILE 42,5 - Profile

2200935

<https://www.phoenixcontact.com/in/products/2200935>

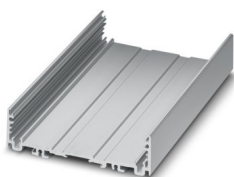


Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 42.5 mm, depth: 29.4 mm

UM-ALU 4-100,5 PROFILE 60 - Profile

2200936

<https://www.phoenixcontact.com/in/products/2200936>

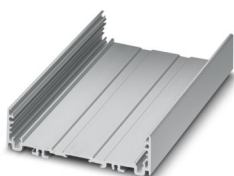

Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 60 mm, depth: 29.4 mm

UM-ALU 4-100,5 COVER PA BK - Lateral element



2200952

<https://www.phoenixcontact.com/in/products/2200952>

UM-ALU 4-100,5 PROFILE 95 - Profile

2200937

<https://www.phoenixcontact.com/in/products/2200937>



Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 95 mm, depth: 29.4 mm

UM-ALU 4-100,5 PROFILE 130 - Profile

2200938

<https://www.phoenixcontact.com/in/products/2200938>



Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 130 mm, depth: 29.4 mm

UM-ALU 4-100,5 COVER PA BK - Lateral element




2200952

<https://www.phoenixcontact.com/in/products/2200952>

UM-ALU 4-100,5 PROFILE 165 - Profile

2200939

<https://www.phoenixcontact.com/in/products/2200939>

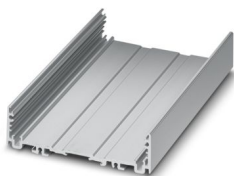


Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 165 mm, depth: 29.4 mm

UM-ALU 4-100,5 PROFILE 200 - Profile

2200940

<https://www.phoenixcontact.com/in/products/2200940>

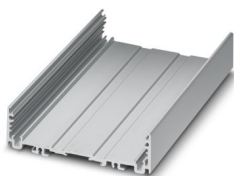

Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 200 mm, depth: 29.4 mm

UM-ALU 4-100,5 COVER PA BK - Lateral element



2200952

<https://www.phoenixcontact.com/in/products/2200952>

UM-ALU 4-100,5 PROFILE 235 - Profile

2200941

<https://www.phoenixcontact.com/in/products/2200941>



Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 235 mm, depth: 29.4 mm

UM-ALU 4-100,5 PROFILE 990 - Profile

2200942

<https://www.phoenixcontact.com/in/products/2200942>



Press-drawn section housings, Screw mounting, Basic profile, profile width (internal): 100.5 mm, profile width (external): 105 mm, length: 990 mm, depth: 29.4 mm

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in