

# ME MAX 45 F-MT G 3-3 KMGY - Intermediate element



2201169

<https://www.phoenixcontact.com/us/products/2201169>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



DIN rail housing, Intermediate element, flat design, without vents, width: 22.6 mm, height: 85 mm, depth: 90 mm, color: light gray (similar RAL 7035), cross connection: without bus connector

## Your advantages

- Easy installation
- Variety of connection technology
- Can be mounted on the DIN rail

## Commercial data


Item number	2201169
Packing unit	10 pc
Minimum order quantity	10 pc
Note	Made to order (non-returnable)
Sales key	NULL
Product key	ACHABA
GTIN	4046356736077
Weight per piece (including packing)	23.73 g
Weight per piece (excluding packing)	23.5 g
Customs tariff number	85389099
Country of origin	DE

## Technical data

### Product properties

Product type	Complete housing center part
Housing type	DIN rail housing
Housing series	ME-MAX
Product family	ME MAX 45..
Number of positions	24
Number of rows	3
Number (Connection openings)	6
Ventilation openings present	no

### Dimensions

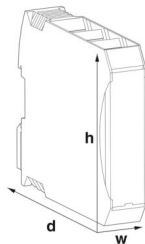Dimensional drawing	
Width	22.6 mm
Height	85 mm
Depth	90 mm
Depth from top edge of DIN rail	84.5 mm

### Material specifications

Color (Housing)	light gray (RAL 7035)
Material Housing	PA
Flammability rating according to UL 94	V0
CTI according to IEC 60112	600
Surface characteristics	untreated

### Environmental and real-life conditions

#### Ambient conditions

Max. IP code to attain	IP20
Ambient temperature (operation)	-40 °C ... 105 °C (depending on power dissipation)
Ambient temperature (storage/transport)	-40 °C ... 55 °C
Ambient temperature (assembly)	-5 °C ... 100 °C
Relative humidity (storage/transport)	80 %

### PCB data

Type of PCB mount	Latching
-------------------	----------

# ME MAX 45 F-MT G 3-3 KMGY - Intermediate element



2201169


<https://www.phoenixcontact.com/us/products/2201169>

## Packaging specifications

Type of packaging	packed in cardboard
Outer packaging type	Carton

## Drawings

Dimensional drawing

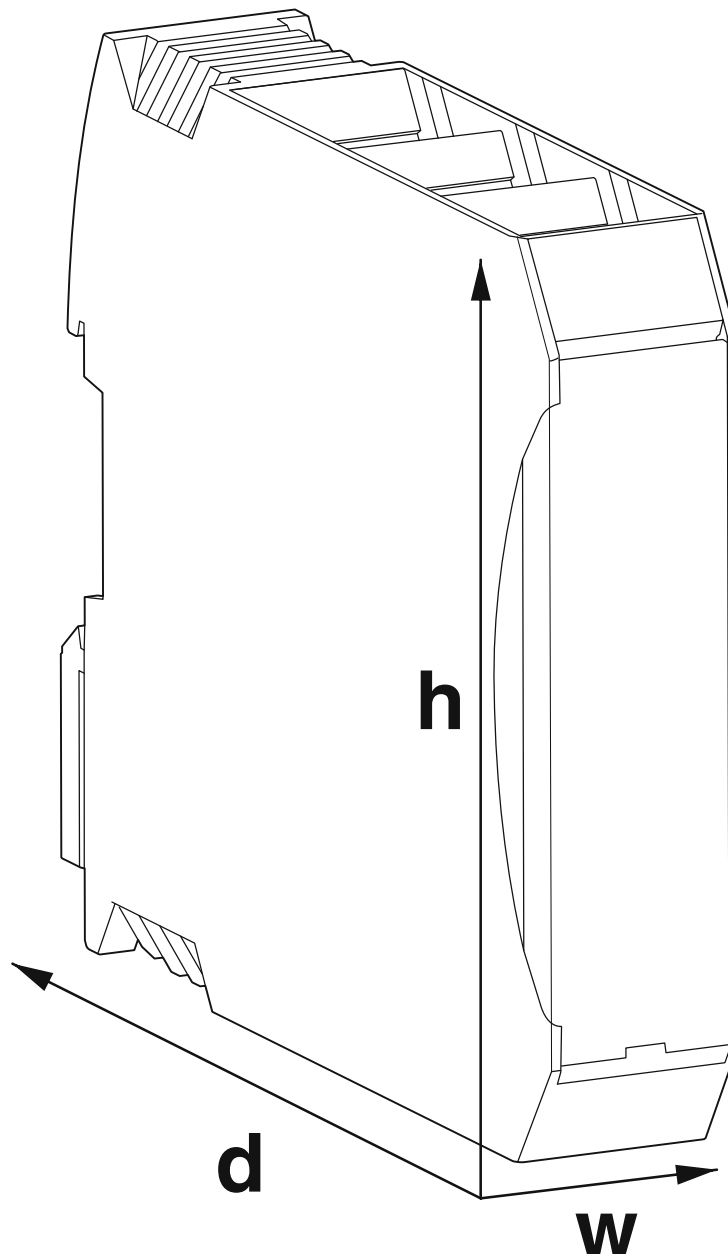

Schematic figure for illustrating the item dimensions. The figure is not of the desired product. For further details, refer to the product drawings in the "Downloads" tab.

# ME MAX 45 F-MT G 3-3 KMGY - Intermediate element



2201169

<https://www.phoenixcontact.com/us/products/2201169>

## Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/2201169>



**UL Recognized**

Approval ID: E240868

# ME MAX 45 F-MT G 3-3 KMGY - Intermediate element



2201169

<https://www.phoenixcontact.com/us/products/2201169>

## Classifications

### ECLASS

ECLASS-13.0	27190604
ECLASS-15.0	27190604

### ETIM

ETIM 9.0	EC002779
----------	----------

### UNSPSC

UNSPSC 21.0	31261500
-------------	----------



2201169

<https://www.phoenixcontact.com/us/products/2201169>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)