

APK 1 - Cover

5022795

<https://www.phoenixcontact.com/us/products/5022795>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.

Hinged cover profile, permits hinged covering of terminal strips when used with cover holder APK-TU and holding profile APK-HP; snaps into the holding profile APK-HP, dimensions: 95 x 50 mm



Your advantages

- Can be labeled
- Protection against environmental influences
- Covering of live parts

Commercial data

Item number	5022795
Packing unit	10 pc
Minimum order quantity	10 pc
Sales key	BE07
Product key	BE61ZX
GTIN	4017918095291
Weight per piece (including packing)	19.2 g
Weight per piece (excluding packing)	16.2 g
Customs tariff number	39162000
Country of origin	DE

APK 1 - Cover

5022795

<https://www.phoenixcontact.com/us/products/5022795>



Technical data

Product properties

Product type	Cover profile
--------------	---------------

Dimensions

Dimensional drawing	
Width	95 mm
Height	50 mm
Length	50 mm

Material specifications

Color	transparent
Material	Polycarbonate PC
Flammability rating according to UL 94	V2
Components	free from silicone and halogen

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 115 °C
---------------------------------	-------------------

APK 1 - Cover


5022795

<https://www.phoenixcontact.com/us/products/5022795>



Drawings

Dimensional drawing

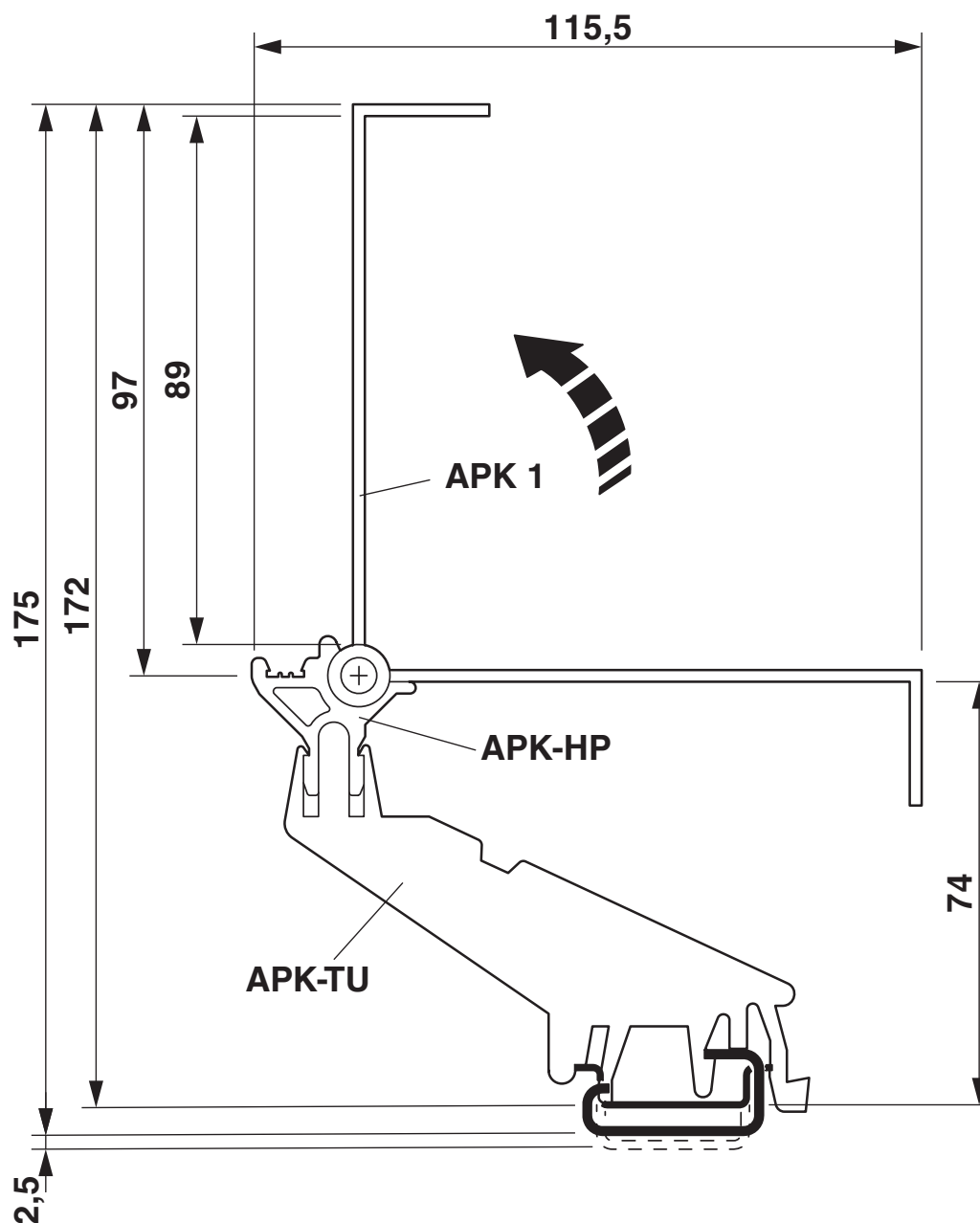

5022795

<https://www.phoenixcontact.com/us/products/5022795>

Classifications

ECLASS

ECLASS-13.0	27371392
ECLASS-15.0	27371392

ETIM

ETIM 9.0	EC002498
----------	----------

UNSPSC

UNSPSC 21.0	39121100
-------------	----------

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com