

HC-STA-B10-HHWD-1TTM25-EL/... - Housing



1372734

<https://www.phoenixcontact.com/us/products/1372734>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sleeve housing B10, with double locking latch, material: Die-cast aluminum, salt water resistant, cable outlets: 1, straight, 1x M25, height: 72 mm, cable gland: none, with choice of powder coating color

Commercial data

Item number	1372734
Packing unit	1 pc
Minimum order quantity	1 pc
Note	Made to order (non-returnable)
Sales key	BF71
Product key	AF7APB
Weight per piece (including packing)	212 g
Weight per piece (excluding packing)	212 g
Customs tariff number	85389099
Country of origin	PL

HC-STA-B10-HHWD-1TTM25-EL/... - Housing



1372734

<https://www.phoenixcontact.com/us/products/1372734>

Technical data


Notes

General	powder-coated and color version of item 1412612 HC-STA-B10-HHWD-1TTM25-EL-AL
General	for contact inserts HC-B10, BB18, DD42, M, K8/24, HV03

Product properties

Product type	Housing with locking latch
Housing type	Sleeve housing
Application	Standard
Design	B10
Type of locking	with double locking latch
No. of cable outlets	1
Type of the screw connection	1x M25
Cable outlet	straight

Dimensions

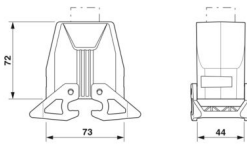Dimensional drawing	
Width	44 mm
Height	72 mm
Length	73 mm

Material specifications

Color	black (RAL 9005)
Flammability rating according to UL 94	V0 (Interlock)
Housing material	Die-cast aluminum, salt water resistant
Housing surface material	uncoated
Locking latch material	PA


Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
	IP67
Enclosure rating (NEMA)	4 (UL 50e)
	4X (UL 50e)
	12 (UL 50e)
Impact strength	IK09
Ambient temperature (operation)	-40 °C ... 125 °C

Drawings

Dimensional drawing

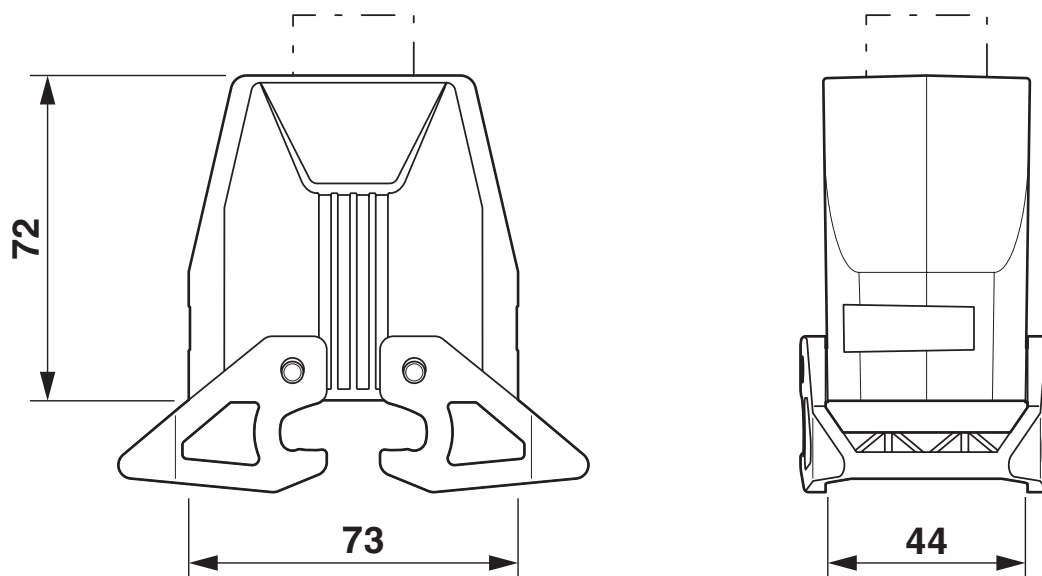

Dimensional drawing

Application drawing



YE – RAL 1021



WH – RAL 9016



RD – RAL 3020



VT – RAL 4004



GY – RAL 7045



GN – RAL 6005



PL – RAL 4006



BN – RAL 8017



BK – RAL 9005



OG – RAL 2004



BU – RAL 5005

HC-STA-B10-HHWD-1TTM25-EL/... - Housing



1372734

<https://www.phoenixcontact.com/us/products/1372734>

Approvals

To download certificates, visit the product detail page: <https://www.phoenixcontact.com/us/products/1372734>



cUL Recognized
Approval ID: E255026



UL Recognized
Approval ID: E255026

HC-STA-B10-HHWD-1TTM25-EL/... - Housing



1372734

<https://www.phoenixcontact.com/us/products/1372734>

Classifications

ECLASS

ECLASS-13.0	27440202
ECLASS-15.0	27440202

ETIM

ETIM 9.0	EC000437
----------	----------

UNSPSC

UNSPSC 21.0	31261500
-------------	----------

1372734

<https://www.phoenixcontact.com/us/products/1372734>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com