

HC-M-08-GBIT-LK10 - Strain relief clamp



1587755

<https://www.phoenixcontact.com/us/products/1587755>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Cable clamp for cable diameter of 7 - 10 mm

Commercial data

Item number	1587755
Packing unit	2 pc
Minimum order quantity	2 pc
Product key	AF7ACZ
GTIN	4046356527903
Weight per piece (including packing)	11.53 g
Weight per piece (excluding packing)	11.53 g
Country of origin	DE

HC-M-08-GBIT-LK10 - Strain relief clamp



1587755

<https://www.phoenixcontact.com/us/products/1587755>

Technical data

Product properties

Product type	Mounting material
--------------	-------------------

Material specifications

Material	Zinc alloy
----------	------------

Cable/line

External cable diameter	7 mm ... 10 mm
-------------------------	----------------

Environmental and real-life conditions

Ambient conditions

Ambient temperature (operation)	-40 °C ... 125 °C
---------------------------------	-------------------

HC-M-08-GBIT-LK10 - Strain relief clamp




1587755

<https://www.phoenixcontact.com/us/products/1587755>

Drawings

Dimensional drawing

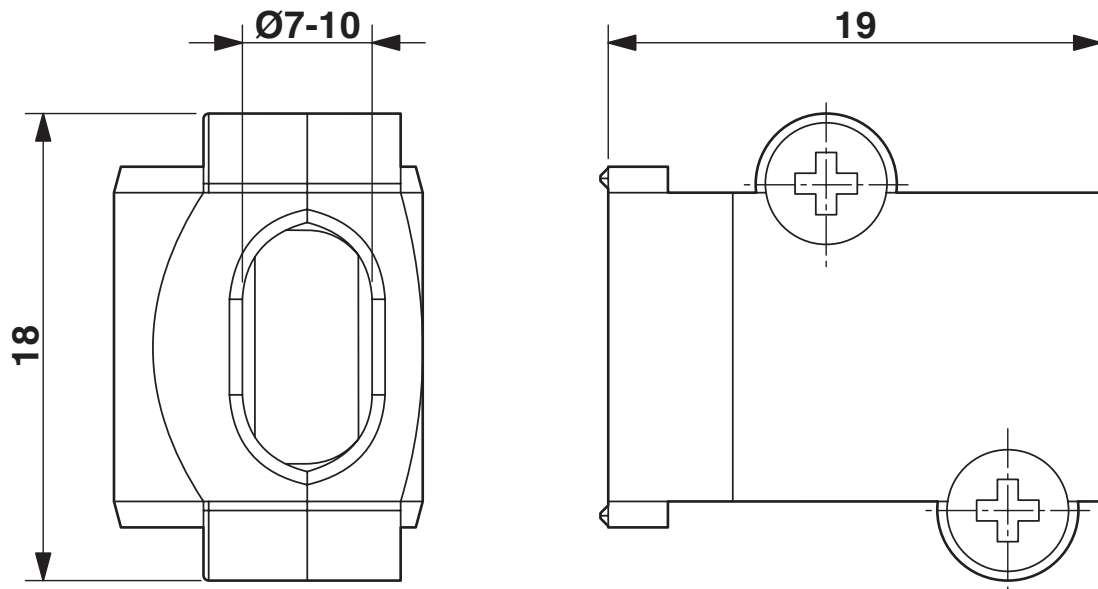

HC-M-08-GBIT-LK10 - Strain relief clamp



1587755

<https://www.phoenixcontact.com/us/products/1587755>

Environmental product compliance

China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com