

EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>



Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Electronics housing ,Component housing, length: 75 mm, without vents, Lower housing part, with snap-on foot and test opening with side cover, cross connection: without bus connector, color: green, width: 67.5 mm, height: 107.5 mm, number of positions cross connector: not relevant

Commercial data

| | |
|--------------------------------------|---------------|
| Item number | 2764302 |
| Packing unit | 5 pc |
| Sales key | AC11 |
| Product key | ACHCGA |
| GTIN | 4017918065935 |
| Weight per piece (including packing) | 79.67 g |
| Weight per piece (excluding packing) | 52.12 g |
| Customs tariff number | 85389099 |
| Country of origin | DE |

EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>



Technical data

Product properties

| | |
|---------------------|---|
| Housing type | Component housing |
| Type | Lower housing parts with test opening with side cover, housing cover necessary to complete the module |
| Number of positions | 26 |

Dimensions

| Dimensional drawing | |
|---------------------|----------|
| | |
| Width | 67.5 mm |
| Installed height | 107.5 mm |
| Height NS 35/7,5 | 107.5 mm |
| Depth | 75 mm |
| Length | 75 mm |

Material specifications

| | |
|--|-------------------------------|
| Color | green |
| Flammability rating according to UL 94 | HB |
| Housing material | Acryl butadiene styrene (ABS) |

Environmental and real-life conditions

Ambient conditions

| | |
|---------------------------------|------------------|
| Ambient temperature (operation) | -40 °C ... 80 °C |
|---------------------------------|------------------|

Mounting

| | |
|---------------|-------------------|
| Mounting type | DIN rail mounting |
|---------------|-------------------|

EG 67,5-GP/ABS GN - Electronics housing


2764302

<https://www.phoenixcontact.com/us/products/2764302>



Drawings

Dimensional drawing

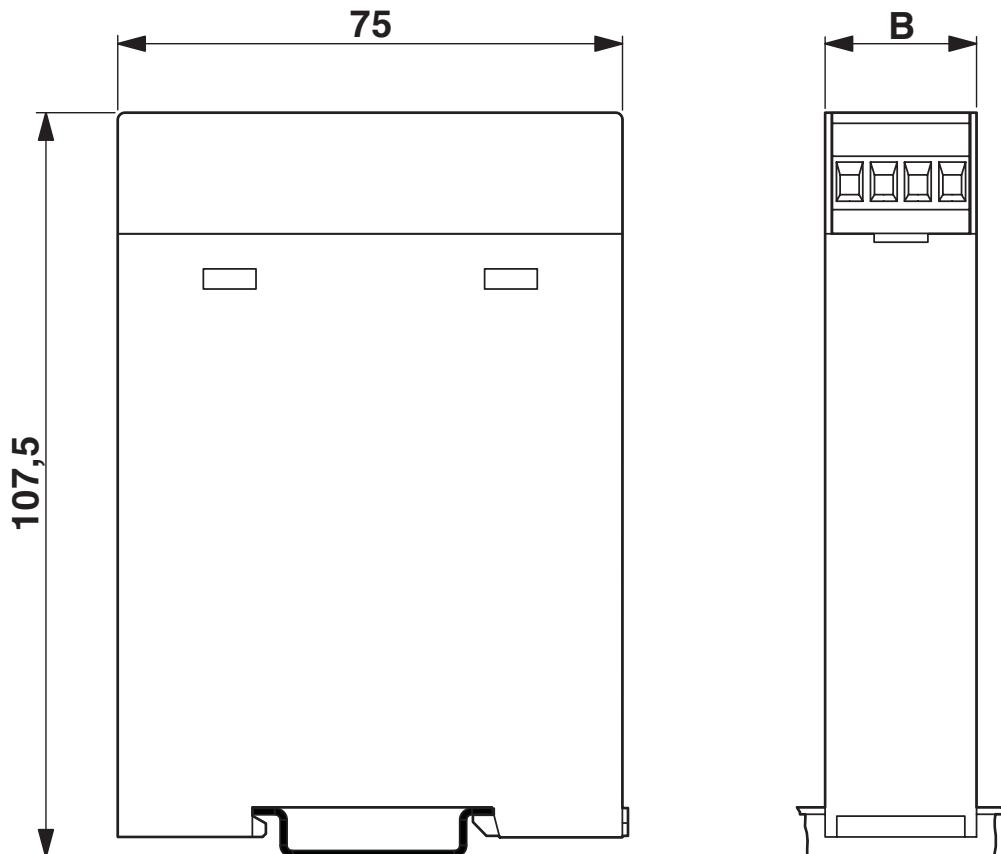


EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>



Dimensional drawing

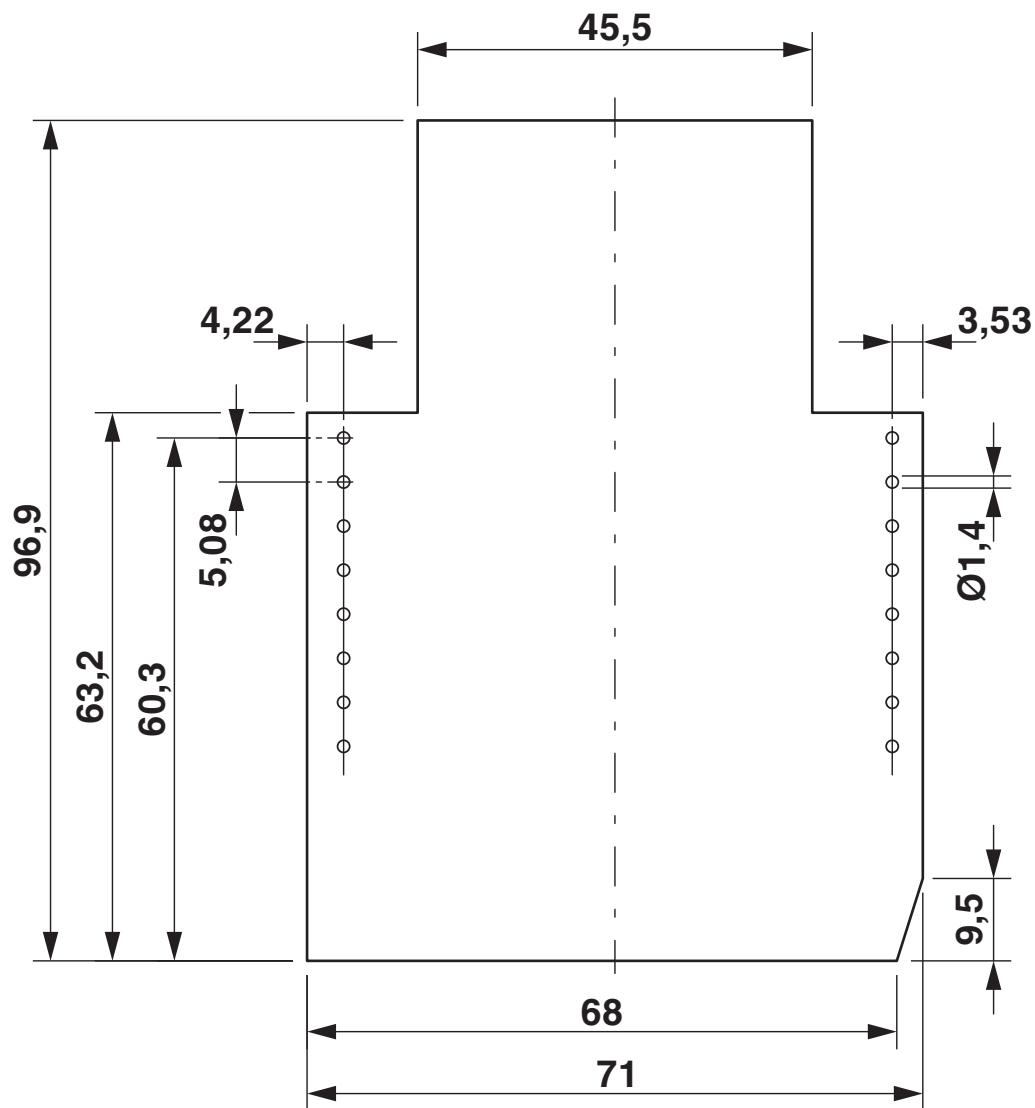

Component mounting side, if the double-level upper part is used


EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>




Dimensional drawing

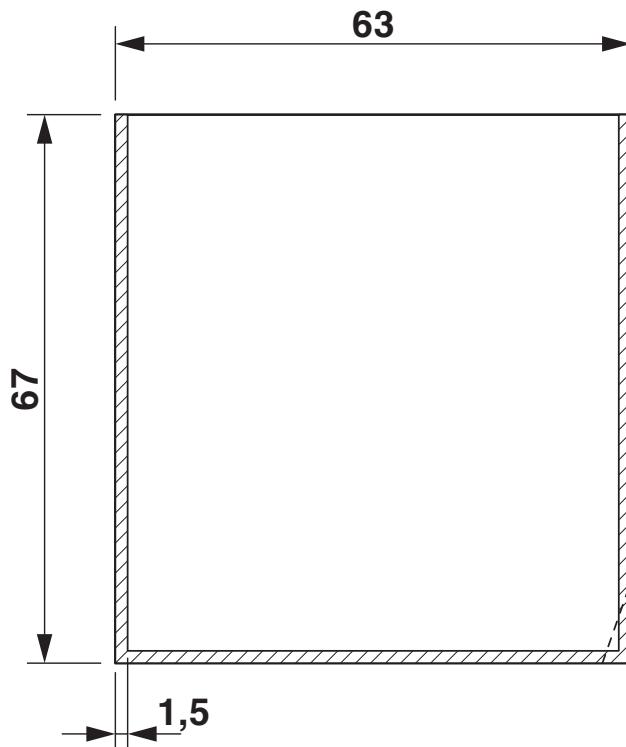

valid for PCB 1; 2; 3; 4; 5 und 6, see explosion drawing

Dimensional drawing

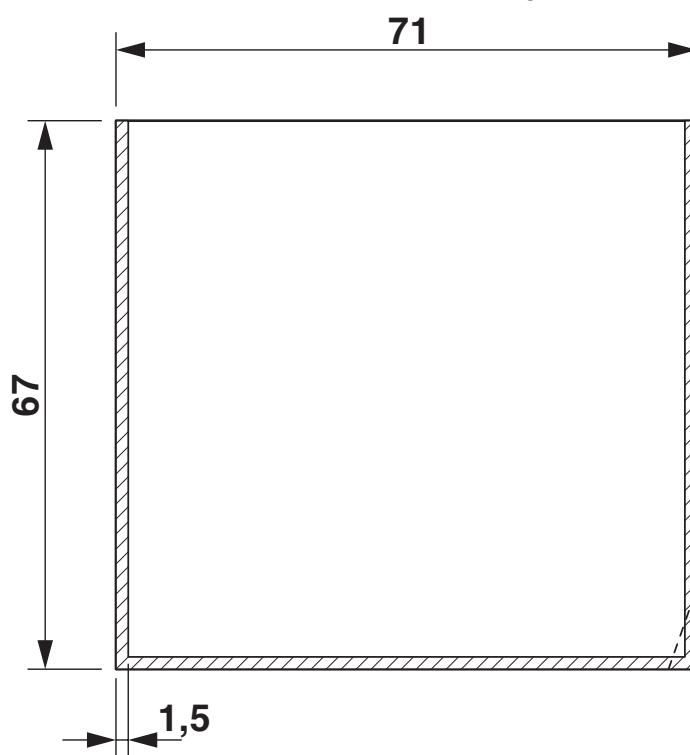

valid for PCB 7; 8; 11 and 12, see explosion drawing


EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>



Dimensional drawing

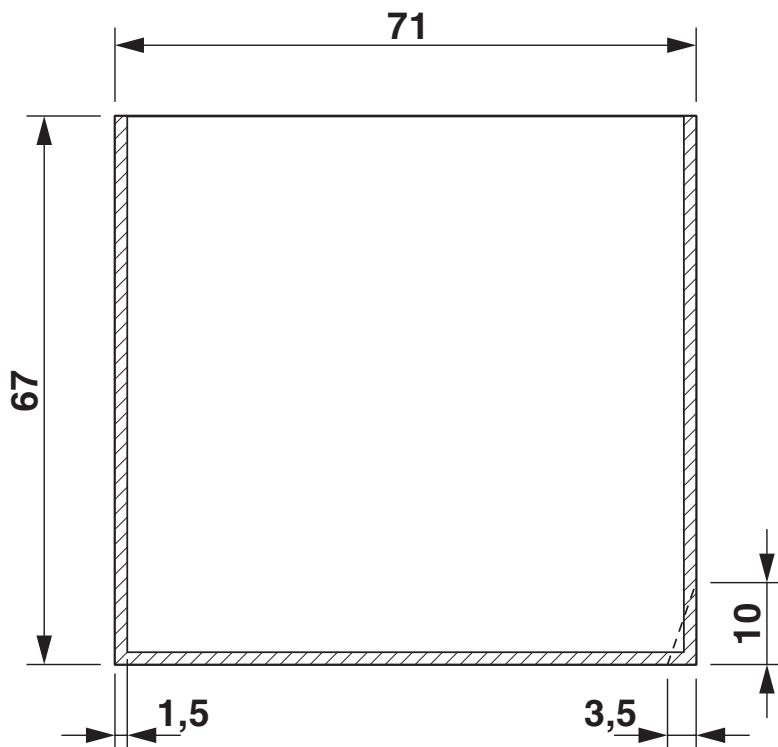


valid for PCB 9, see explosion drawing

EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>

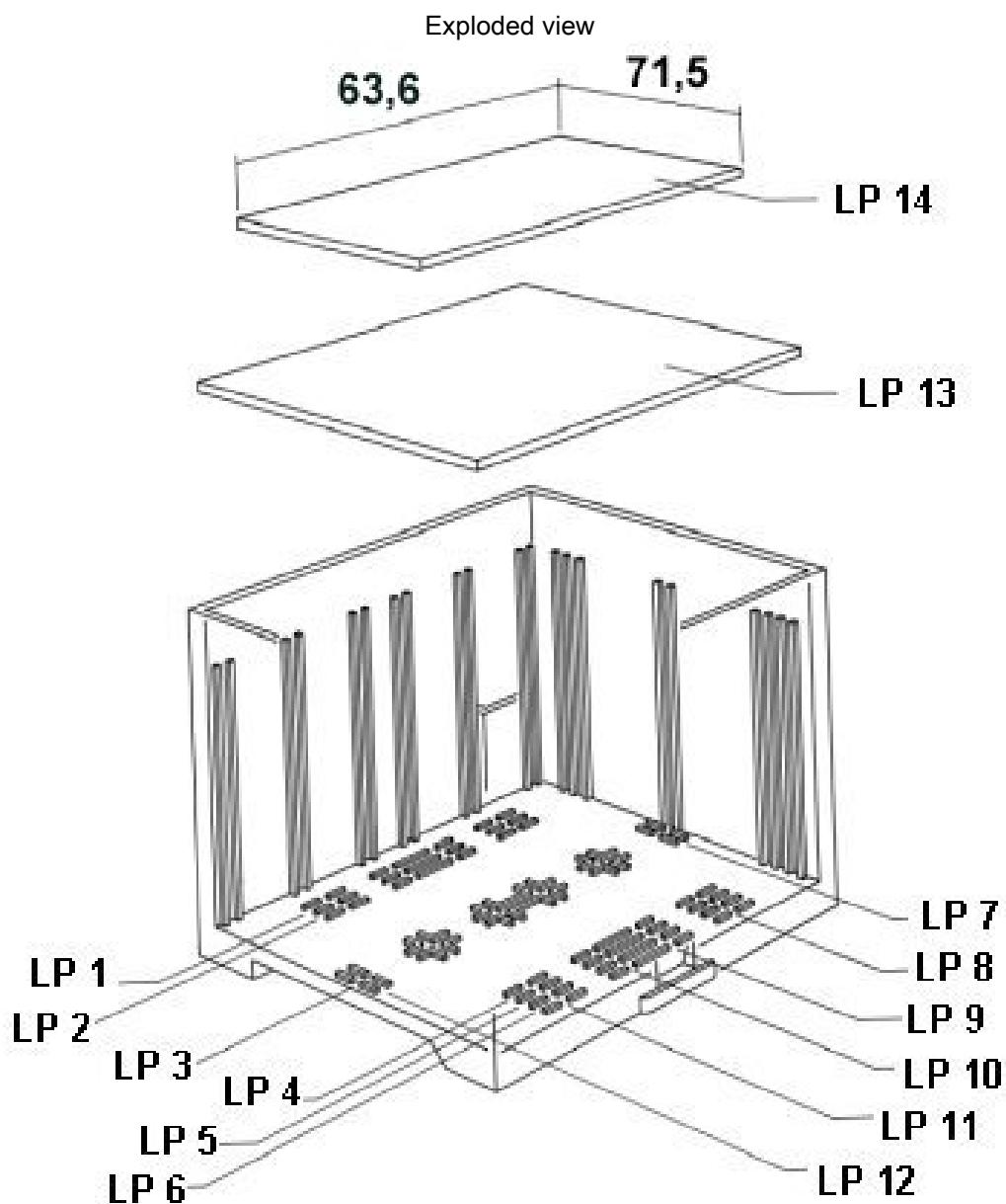


valid for PCB 13

EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>

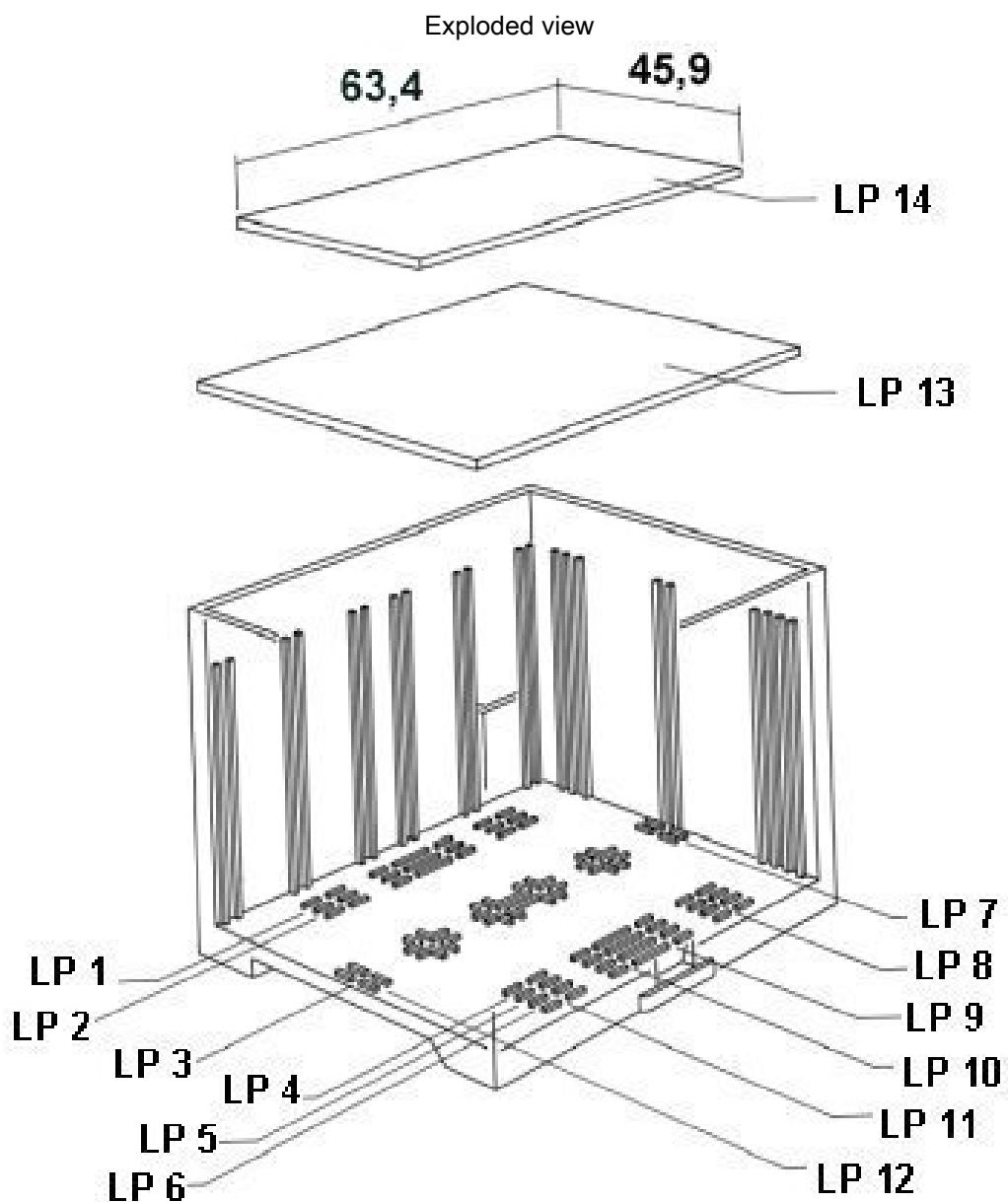

valid for PCB 14

EG 67,5-GP/ABS GN - Electronics housing

2764302

<https://www.phoenixcontact.com/us/products/2764302>



Environmental product compliance

EU RoHS

| | |
|---|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|---|--------------------|

China RoHS

| | |
|--|--|
| Environment friendly use period (EFUP) | EFUP-E |
| | No hazardous substances above the limits |

EU REACH SVHC

| | |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

Phoenix Contact USA
586 Fulling Mill Road
Middletown, PA 17057, United States
(+717) 944-1300
info@phoenixcon.com