

# ZB 6/WH-100:UNBEDRUCKT - Zack marker strip



5060935

<https://www.phoenixcontact.com/us/products/5060935>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Zack marker strip, Strip, white, unmarked, can be labeled with: PLOTMARK, CMS-P1-PLOTTER, mounting type: latching, for terminal block width: 6.2 mm, Number of individual labels: 1000, text field height: 10.5 mm, text field width: 6.15 mm

## Commercial data

|                                      |               |
|--------------------------------------|---------------|
| Item number                          | 5060935       |
| Packing unit                         | 100 pc        |
| Minimum order quantity               | 100 pc        |
| Sales key                            | BG05          |
| Product key                          | BG2112        |
| GTIN                                 | 4017918096168 |
| Weight per piece (including packing) | 1.357 g       |
| Weight per piece (excluding packing) | 1.357 g       |
| Customs tariff number                | 39269097      |
| Country of origin                    | DE            |

## Technical data

### Notes

|         |                         |
|---------|-------------------------|
| General | Can be labeled with CMS |
|---------|-------------------------|

### Product properties

|              |               |
|--------------|---------------|
| Product type | Klemmenmarker |
| Pitch        | 6.2 mm        |

### Marking

|                                     |      |
|-------------------------------------|------|
| Number of individual labels         | 1000 |
| Number of individual labels per row | 10   |
| Number of marker strips             | 100  |

### Dimensions

|        |          |
|--------|----------|
| Width  | 6.15 mm  |
| Height | 10.50 mm |
| Depth  | 4.20 mm  |
| Pitch  | 6.2 mm   |

### Material specifications

|                                        |                                |
|----------------------------------------|--------------------------------|
| Color                                  | white (RAL 9010)               |
| Material                               | PA                             |
| Flammability rating according to UL 94 | V2                             |
| Components                             | free from silicone and halogen |

### Environmental and real-life conditions

#### UV resistance

|               |                                |
|---------------|--------------------------------|
| Specification | ISO 4892-2:2013-03 (following) |
|---------------|--------------------------------|

#### Wipe resistance of inscriptions

|               |                                                |
|---------------|------------------------------------------------|
| Specification | DIN EN 61010-1 (VDE 0411-1):2011-07            |
|               | DIN EN 62208 (VDE 0660-511):2012-06 (in parts) |

#### Ambient conditions

|                                                     |                   |
|-----------------------------------------------------|-------------------|
| Ambient temperature (operation)                     | -40 °C ... 100 °C |
| Recommended ambient temperature (storage/transport) | 23 °C             |
| Recommended humidity (storage/transport)            | 50 %              |

### Standards and regulations

|                 |                             |
|-----------------|-----------------------------|
| Wipe resistance | DIN EN 61010-1 (VDE 0411-1) |
|-----------------|-----------------------------|

### Mounting

|               |          |
|---------------|----------|
| Mounting type | latching |
|---------------|----------|


# ZB 6/WH-100:UNBEDRUCKT - Zack marker strip

5060935

<https://www.phoenixcontact.com/us/products/5060935>

## Drawings

Schematic diagram

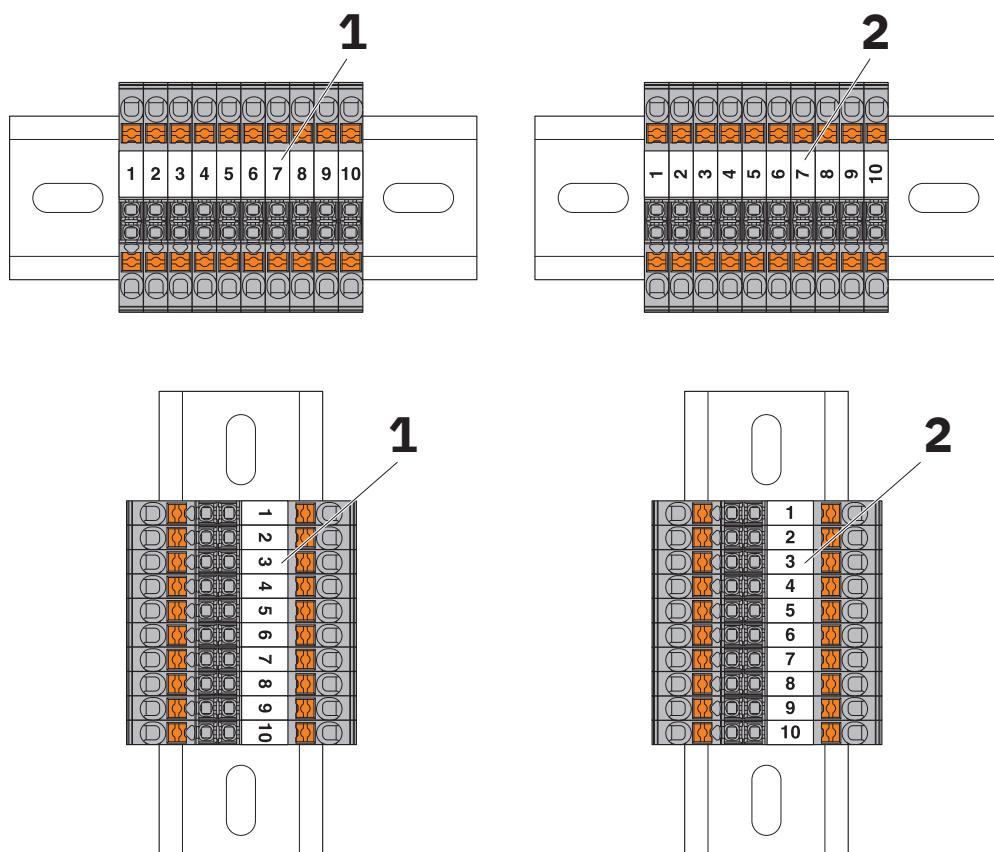

5060935

<https://www.phoenixcontact.com/us/products/5060935>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-13.0 | 27281101 |
| ECLASS-15.0 | 27281101 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000761 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39131500 |
|-------------|----------|

# ZB 6/WH-100:UNBEDRUCKT - Zack marker strip



5060935

<https://www.phoenixcontact.com/us/products/5060935>

## Environmental product compliance

|                                         |                            |
|-----------------------------------------|----------------------------|
| EU RoHS                                 |                            |
| Fulfills EU RoHS substance requirements | Yes, No exemptions         |
| EU REACH SVHC                           |                            |
| REACH candidate substance (CAS No.)     | No substance above 0.1 wt% |
| EF3.0 Climate Change                    |                            |
| CO2e kg                                 | 0.012 kg CO2e              |

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

Phoenix Contact USA  
586 Fulling Mill Road  
Middletown, PA 17057, United States  
(+717) 944-1300  
[info@phoenixcon.com](mailto:info@phoenixcon.com)