


Height-Adjustable TV Wall Mount for 50" to 70" Flat-Panel Interactive Displays

MODEL NUMBER: DWM5070HD

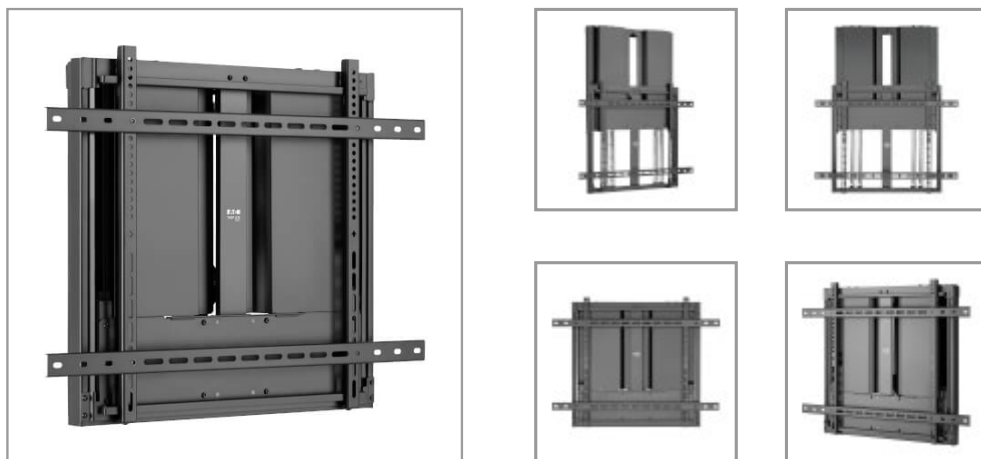

Mounts your 50 to 70 in. television, whiteboard or interactive display to a wall and adjusts vertically to provide optimal viewing angles.

Features

TV Wall Mount Secures Your Interactive Touchscreen Display at Arm's Length

The VESA-compliant DWM5070HD mounts your television, monitor, whiteboard or interactive display to a wood stud, brick or concrete wall with the included hardware. Recommended for conference rooms, boardrooms and classrooms, this wall mount supports most popular brands of interactive touchscreen displays.

Glides Up and Down with Just a Touch for Perfect Viewing

Intricately designed counterbalanced springs allow the connected display to glide up and down the wall, allowing users of all sizes to adjust and work at the interactive touchscreen. With 15.7 inches (40 centimeters) of vertical movement, the DWM5070HD provides easy fingertip control for everyone.

Durable All-Metal Construction Built to Last

This height-adjustable TV wall mount is made from heavy-duty steel with a powder-coated black finish that resists scratches and blends smoothly into any room décor. It is compatible with most flat-screen televisions, monitors and interactive digital whiteboards between 50 and 70 inches and supports 88 to 132 pounds (60 kilograms).

VESA-Compliant Mounting Ensures Display Compatibility

VESA (Video Electronics Standards Association) promotes uniformity in the video electronics industry by developing standards for TVs and monitors. For hassle-free display compatibility, this TV wall mount supports the following VESA mounting hole patterns: 200 x 200, 200 x 300, 200 x 400, 300 x 200, 300 x 300, 300 x 400, 400 x 200, 400 x 300, 400 x 400, 400 x 500, 400 x 600, 600 x 300, 600 x 400, 600 x 500, 600 x 600, 700 x 400, 700 x 500, 700 x 600, 800 x 500 and 800 x 600.

Highlights

- Supports most 50-70 in. interactive touchpanel displays 88 to 132 lbs.
- Innovative weight-balancing design allows smooth height adjustment up to 15.7 in.
- Compact steel mount hides out of sight behind the display for a professional look
- VESA compliance ensures compatibility with most popular mounting hole patterns
- Hardware included for mounting on wood, brick or concrete wall surface

System Requirements

Flat-screen television, monitor whiteboard or interactive display from 50 to 70 in.

Package Includes

- DWM5070HD Height-Adjustable TV Wall Mount
- Mounting hardware
- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332268822
Device Compatibility	Monitor/HDTV



Powering Business Worldwide

TRIPP LITE
SERIES

PHYSICAL	
Color	Black
Material of Construction	Steel
VESA Pattern (mm)	200x200; 200x300; 200x400; 300x200; 300x300; 300x400; 400x200; 400x300; 400x400; 400x500; 400x600; 600x300; 600x400; 600x500; 600x600; 700x400; 700x500; 700x600; 800x400; 800x500; 800x600
Motion	Full
Mounting Location	Wall
Distance from Wall (in.)	5
Distance from Wall (cm)	13
Distance from Wall (mm)	127
Minimum Screen Size (in.)	50
Minimum Screen Size (cm)	127
Maximum Screen Size (in.)	70
Maximum Screen Size (cm)	177.8
Maximum Weight Capacity (lbs.)	132
Maximum Weight Capacity (kg)	60
Number of Displays	1
Unit Dimensions (hwd / in.)	40.940 x 33.070 x 5.000
Unit Dimensions (hwd / cm)	103.99 x 84 x 12.70
Unit Weight (lbs.)	53.9
Unit Weight (kg)	24.45
Assembly Required	Yes
FEATURES & SPECIFICATIONS	
Antimicrobial	No
Cord Management	No
Tools Necessary	Yes
Security Lock	No
STANDARDS & COMPLIANCE	
Product Compliance	RoHS; RoHS3; REACH
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	5-year limited warranty



Powering Business Worldwide

TRIPP LITE
SERIES

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.