


DisplayPort 1.2 to VGA Active Compact Adapter Video Converter (M/F)

MODEL NUMBER: P134-000-VGA-V2

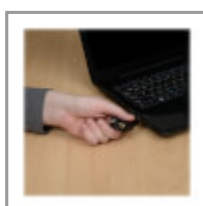

Highlights

- Connect a VGA monitor to a computer with a DisplayPort output
- DisplayPort v1.2 to VGA Active Adapter Converter (DisplayPort-Male to VGA-Female)
- Plug-and-play convenience; no drivers or software needed
- Ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals
- Converts both Single-Mode and Dual Mode (DP++) Displayport output

Package Includes

- DisplayPort 1.2 to VGA Active Compact Adapter (DP-Male to VGA-Female)

Description

The P134-000-VGA-V2 DisplayPort 1.2 to VGA Active Compact Adapter allows you to connect a computer with a DisplayPort connection to a VGA monitor. DisplayPort v1.2 doubles the previous version bandwidth of 8.64 Gbps to 17.28 Gbps in High Bit Rate (HBR2) mode, which allows increased resolutions, higher refresh rates and greater color depth. Fully molded one-piece design ensures longer life. Unlike passive adapters, active adapters convert both Single-Mode and Dual Mode (DP++) DisplayPort output. It is ideal for use with graphics cards, such as AMD Eyefinity, that do not output Dual Mode (DP++) signals.

Features

- Connect a VGA monitor to a computer with a DisplayPort output
- DisplayPort 1.2 to VGA Active Adapter (DisplayPort-Male to VGA-Female)
- Supports computer video resolutions up to 1920 x 1200 and HD resolutions up to 1080p
- 17.28 Gbps bandwidth
- Fully molded one piece design
- Plug and Play; no drivers or software required
- Converts both Single-Mode and Dual-Mode DisplayPort output
- Works with graphics cards that don't output DP++ signals, such as AMD Eyefinity

Specifications

OVERVIEW	
UPC Code	037332187567
Product Type	Video Adapter
Device Compatibility	Computer; Monitor/HDTV
Technology	VGA/SVGA; DisplayPort
CONNECTIONS	



Powering Business Worldwide

TRIPP LITE
SERIES

Side A - Connector 1	DISPLAYPORT (MALE)
Side B - Connector 1	HD15 (FEMALE)
PHYSICAL	
Color	Black
Shipping Dimensions (hwd / in.)	5.90 x 3.90 x 0.50
Shipping Dimensions (hwd / cm)	14.99 x 9.91 x 1.27
Shipping Weight (lbs.)	0.05
Shipping Weight (kg)	0.02
Unit Dimensions (hwd / in.)	5.900 x 3.900 x 0.500
Unit Dimensions (hwd / cm)	14.99 x 9.91 x 1.27
Unit Weight (lbs.)	0.05
Unit Weight (kg)	0.02
STANDARDS & COMPLIANCE	
Product Certifications	EN 55024; EN 55032
Product Compliance	RoHS
WARRANTY & SUPPORT	
Product Warranty Period (Worldwide)	3-year limited warranty

1000 Eaton Boulevard
Cleveland, OH 44122
United States
<https://tripplite.eaton.com>

© 2025 Eaton. All Rights Reserved.
Eaton is a registered trademark. All other trademarks
are the property of their respective owners.