


PRODUCT DATA DRAWING

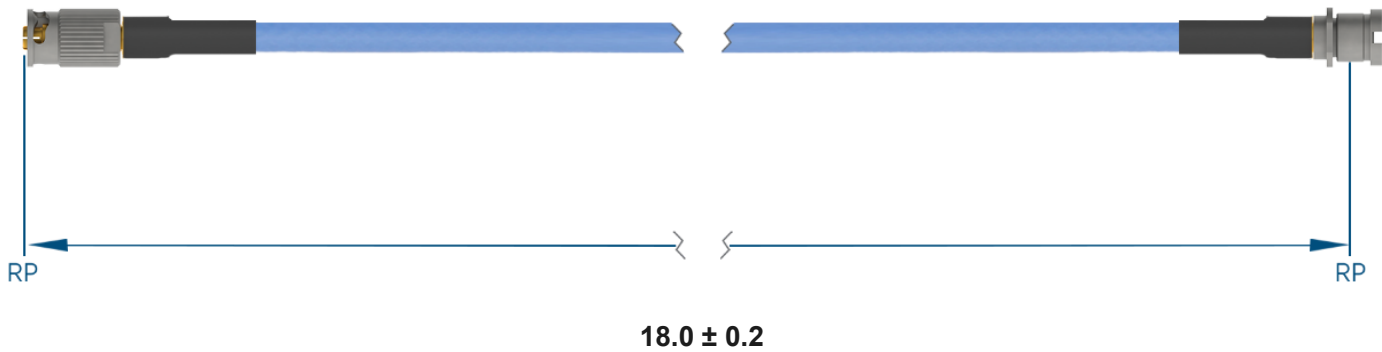

MATERIAL

- CONNECTORS: SMPM Female QB (3221-60004)
SMP Male Bulkhead (SF1211-6061)
- CABLE: Ø.085 Flexible Coax
- SHRINK TUBING: M23053/5

PERFORMANCE

- IMPEDANCE: 50 Ohms
- FREQ. RANGE: DC to 26.5 GHz
- VSWR: 1.3:1 Max, DC to 18.0 GHz
1.5:1 Max, 18.0 + GHz
- INSERTION LOSS: 2.21 dB Max

NOTES

1. See individual data drawings for connector specifications
2. Dimensions shown are in inches



TITLE:	SMPM Female QB to SMP Male Bulkhead 18" Cable Assembly for Ø.085 Flexible Coax
DWG. NO.	FQSMPM-085-MBSMP-180
DRAWN	2022-10-18 11:30:14