

MOTOR SUPPRESSOR

RC, 3x690VAC/10kW

Art.No.: 23017

Weight: 0.14

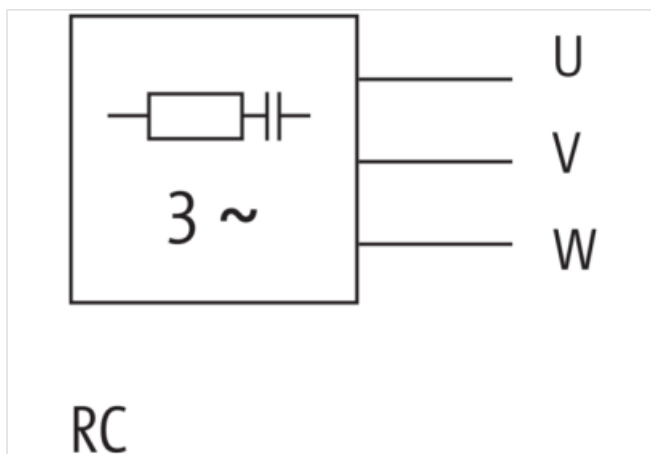
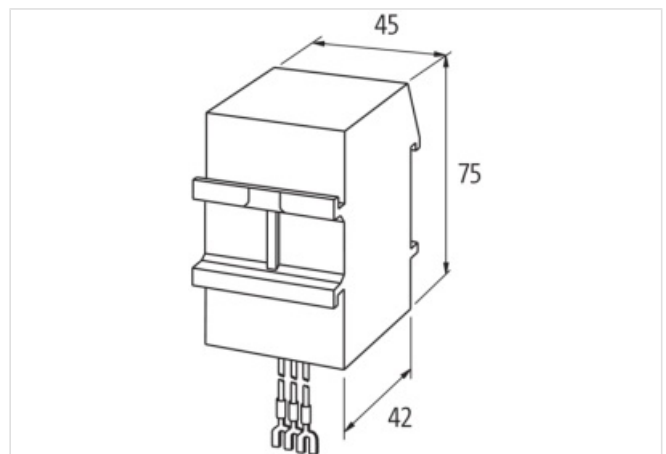
Country of origin: CZ

Model designation: HRC 3/690-10

3× 690 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

HRC 3/690-10

Commercial data

URL Webshop	https://shop.murrelektronik.com/23017
GTIN	4048879019538
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019538
Packaging unit	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	690 V
------------------	-------

Installation

Connection cross-section stranded/fine-stranded min.	0.5 mm ²
--	---------------------

Installation | Connection

Length single strands	250 mm
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	75 mm
Width	45 mm
Depth	42 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C