

MOTOR SUPPRESSOR

RC, 3x400VAC/4kW

Art.No.: 23020

Weight: 0.114

Country of origin: CZ

Model designation: RC 3/022-400 U - PG 9

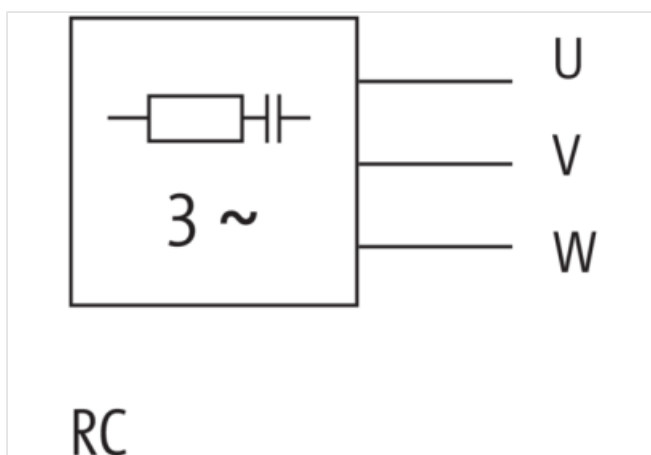
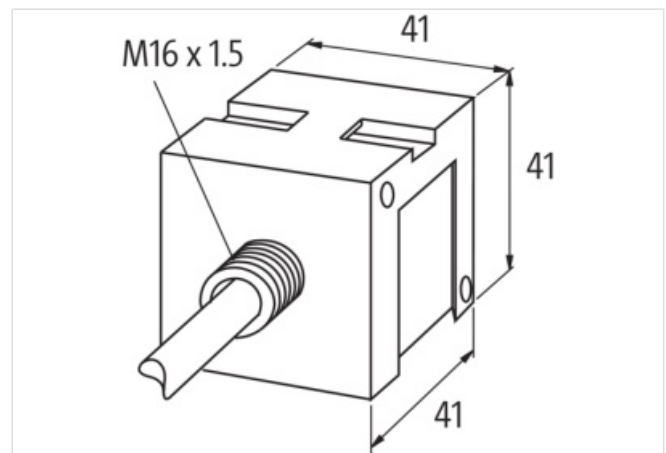
3 × 400 V AC

RC

PG9

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

For DIN-rail mounting use 2×Art.-No. 20900 adapter feet
approx. 500 mm, PVC cable 3 × 0.75 mm²

[Link to Product](#)**Illustration**

Product may differ from Image



EAC

Commercial data

URL Webshop	https://shop.murrelektronik.com/23020
GTIN	4048879019514
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
EAN	4048879019514

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	400 V
------------------	-------

Installation

Connection cross section max.	0.75 mm²
-------------------------------	----------

Installation | Connection

Family construction form	free cable end
--------------------------	----------------

Installation | Pin assignment

No. of poles	3
--------------	---

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	41 mm
Width	41 mm
Depth	41 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C