

MOTOR SUPPRESSOR

RC, 3x400VAC/4kW

Art.No.: 23020

Weight: 0.114

Country of origin: CZ

Model designation: RC 3/022-400 U - PG 9

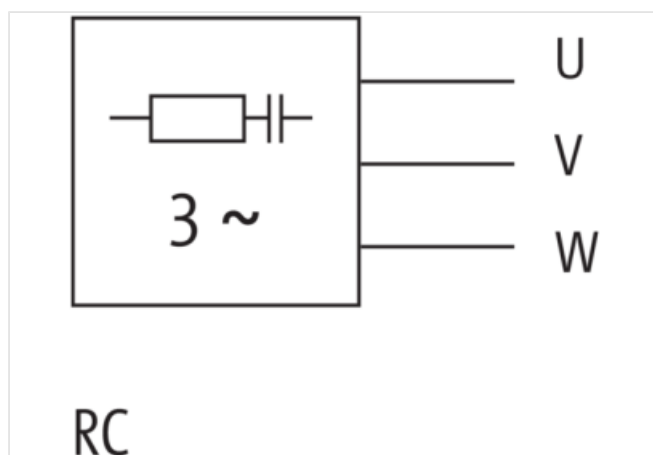
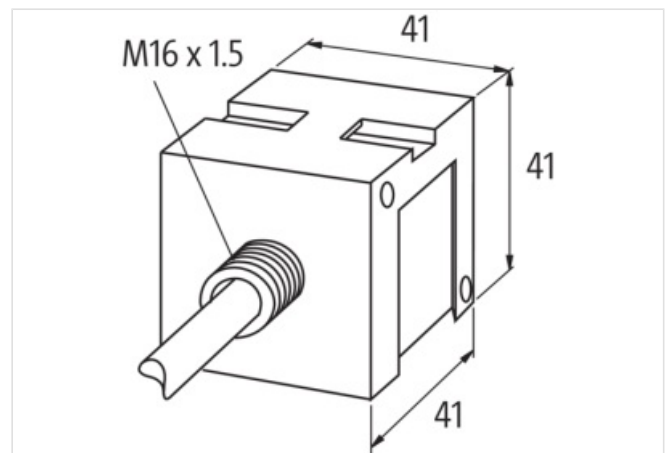
3 × 400 V AC

RC

PG9

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

For DIN-rail mounting use 2×Art.-No. 20900 adapter feet
approx. 500 mm, PVC cable 3 × 0.75 mm²

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

RC 3/022-400 U - PG 9

Commercial data	
URL Webshop	https://shop.murrelektronik.com/23020
GTIN	4048879019514
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019514
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	400 V
Installation	
Connection cross section max.	0.75 mm ²
Installation Connection	
Family construction form	Free cable end
Installation Pin assignment	
No. of poles	3
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Height	41 mm
Width	41 mm
Depth	41 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C

Operating temperature max. 60 °C