

MOTOR SUPPRESSOR

Varistor, 3x400VAC/7,5kW

Art.No.: 23111

Weight: 0.03

Country of origin: CZ

Model designation: RC 3 R-400/7,5-PG9

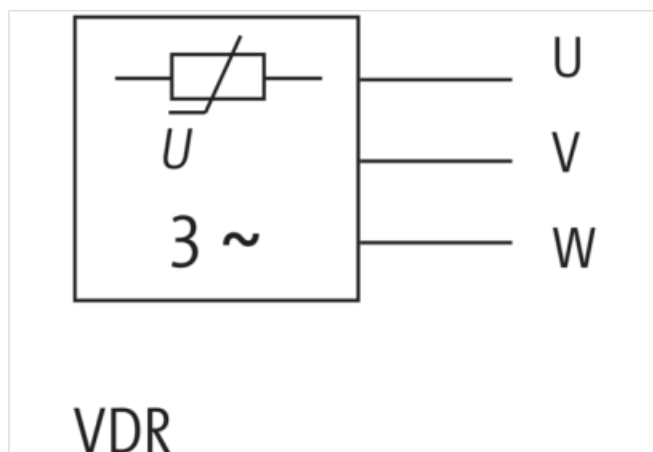
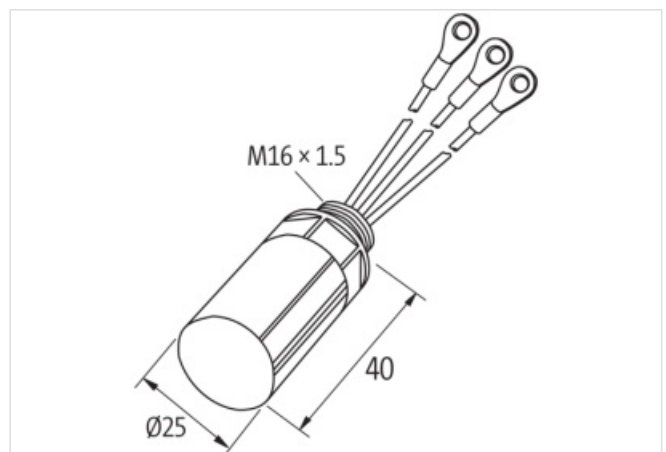
3× 400 V AC

VDR

isolated M6

PG9

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

RC 3 R-400/7,5-PG9

Commercial data	
URL Webshop	https://shop.murrelektronik.com/23111
GTIN	4048879019309
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019309
Packaging unit	1
Electrical data Supply	
Power frequency	10 ... 400 Hz
Electrical data Input	
Input voltage AC	400 V
Installation	
Connection cross section max.	0.5 mm ²
Installation Connection	
Ring terminals	M6, isolated
Length single strands	100 mm
Connection information	Single strands
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Height	25 mm
Width	25 mm
Depth	40 mm
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C