

## MOTOR SUPPRESSOR

Varistor, 3x575VAC/10kW

Art.No.: 23145

Weight: 0.075

Country of origin: CZ

Model designation: RC 3 RG-575/10-M20 X 1,5 M6

3× 575 V AC



VDR

with (M20×1.5 mm) gland

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

### Link to Product

#### Illustration

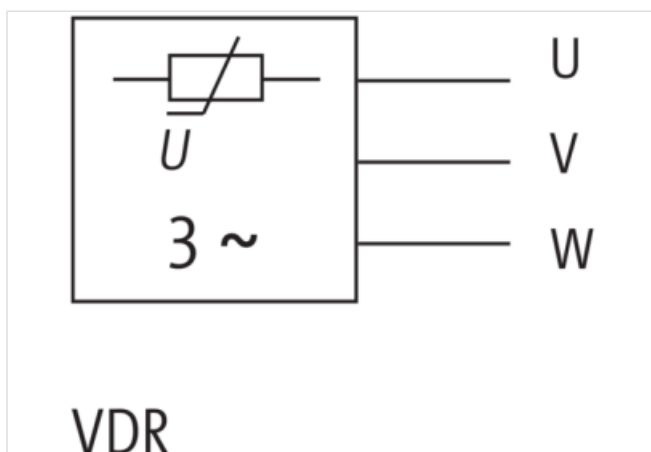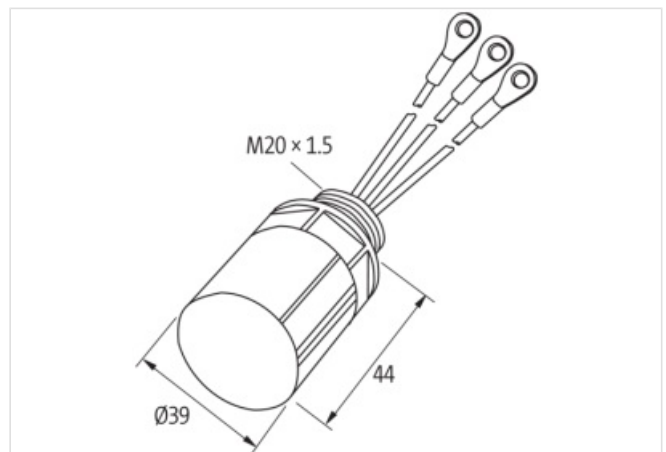

Product may differ from Image



#### Commercial data

URL Webshop

<https://shop.murrelektronik.com/23145>

GTIN

4048879019101

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
EAN	4048879019101

**Electrical data | Input**

Input voltage AC	575 V
------------------	-------

**Installation**

Connection cross section max.	1 mm <sup>2</sup>
-------------------------------	-------------------

**Installation | Connection**

Ring terminals	M6, isolated
Length single strands	150 mm
Connection information	Single strands

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

**Mechanical data | Mounting data**

Height	39 mm
Width	39 mm
Depth	44 mm
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C