

**MOTOR SUPPRESSOR**

Varistor, 3x575VAC/4kW

Art.No.: 23172

Weight: 0.04

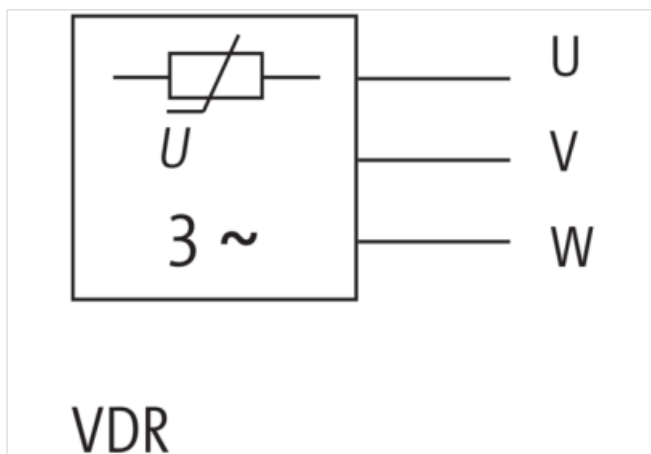
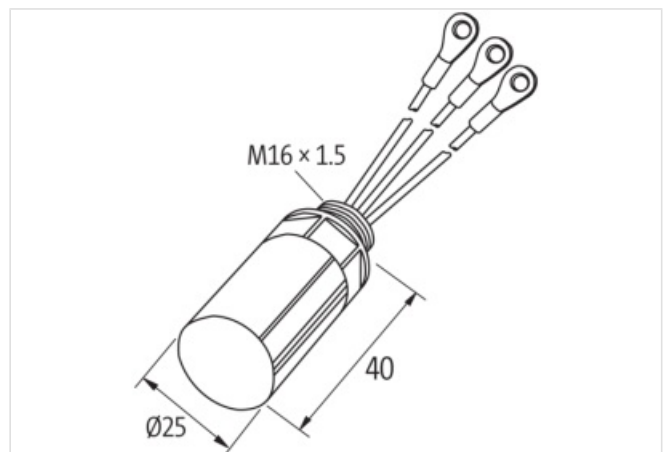
Country of origin: CZ

Model designation: RC 3 R-575/4-M16 X 1,5

3× 575 V AC

VDR

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

**Link to Product****Illustration**

Product may differ from Image

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/23172>

GTIN

4048879018913

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
EAN	4048879018913

#### Electrical data | Input

Input voltage AC	575 V
------------------	-------

#### Installation

Connection cross section max.	0.5 mm <sup>2</sup>
-------------------------------	---------------------

#### Installation | Connection

Ring terminals	M6, isolated
Length single strands	100 mm
Connection information	Single strands

#### Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

#### Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

#### Mechanical data | Mounting data

Height	25 mm
Width	25 mm
Depth	40 mm
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C