

EMC SUPPRESSOR FOR MOTOR

RC 3 BU/022-575VAC, star, AWG 20

Art.No.: 236116

Weight: 0.04

Country of origin: CZ

Model designation: RC 3 BU/022-575/4

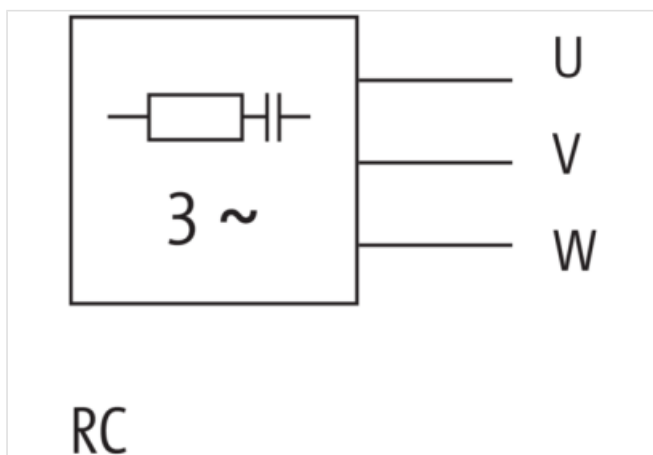
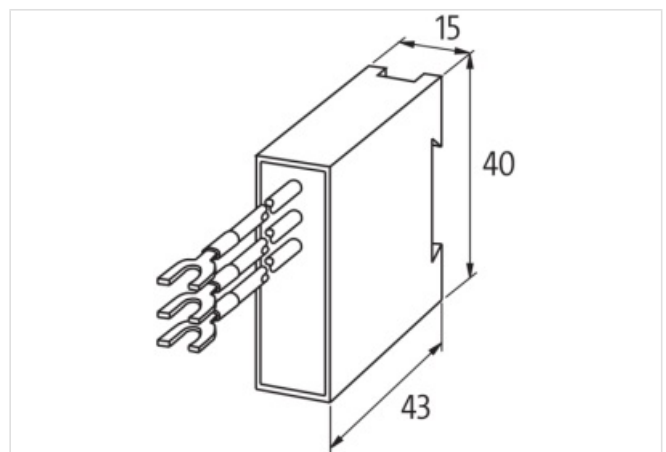
3× 400 V AC

3× 575 V AC

RC

For DIN-rail mounting use Art.-No. 20900 adapter feet

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product**Illustration**

Product may differ from Image



EAC

Commercial data

URL Webshop

<https://shop.murrelektronik.com/236116>

GTIN	4048879015295
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
EAN	4048879015295

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	575 V
------------------	-------

Installation

Connection cross-section solid max.	0.5 mm ²
-------------------------------------	---------------------

Installation | Connection

Length single strands	70 mm
Connection information	Single strands

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	43 mm
Width	15 mm
Depth	40 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C