

MOELLER CONTACTOR SUPPRESSOR

Zener diode, 24VDC

Art.No.: 26081

Weight: 0.018

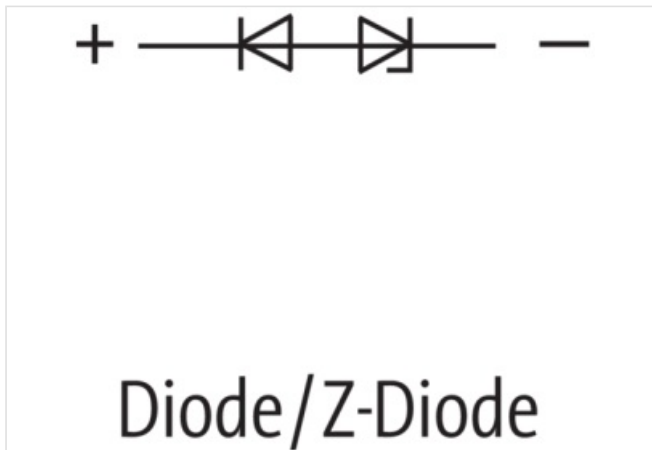
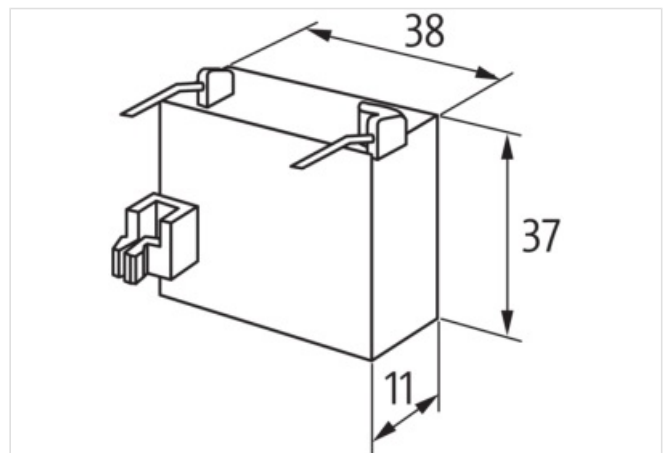
Country of origin: CZ

Model designation: LG-BDIL/Z 24(ME)

24 V DC

Diode/Z-Diode

For other configurations and voltages, please inquire.

[Link to Product](#)**Illustration**

Product may differ from Image

**Commercial data**

URL Webshop	https://shop.murrelektronik.com/26081
GTIN	4048879018401
ECLASS-6.0	27371013
ECLASS-6.1	27371013

ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
EAN	4048879018401

Electrical data | Input

Input voltage DC min.	12 V
Input voltage DC max.	30 V

Installation | Connection

Connection information	Plug contact
------------------------	--------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

Mechanical data | Mounting data

Height	37 mm
Width	38 mm
Depth	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C