

TELEMECANIQUE CONTACTOR SUPPRESSOR

Varistor, 250VAC/DC

Art.No.: 26187

Weight: 0.003

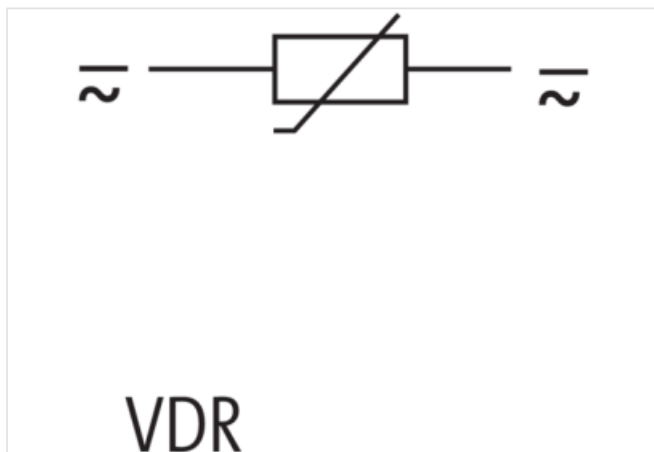
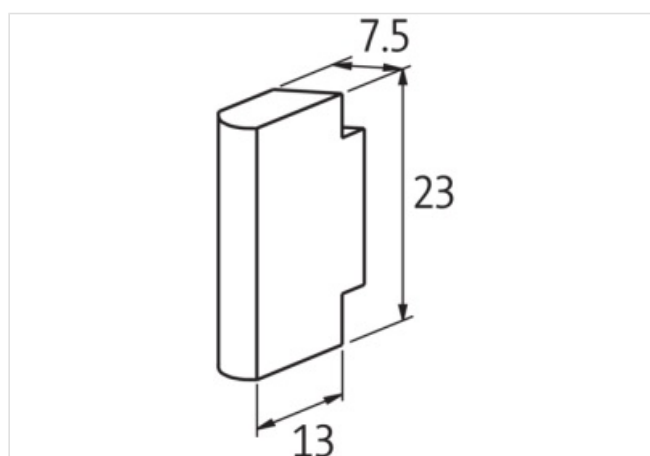
Country of origin: CZ

Model designation: PZV 250

230 V AC/DC

VDR

For other configurations and voltages, please inquire.

Link to Product**Illustration**

Product may differ from Image

**Header**

Material short text

PZV 250

Commercial data

URL Webshop

<https://shop.murrelektronik.com/26187>

GTIN	4048879018104
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879018104
Packaging unit	1

Electrical data

Damping factor	1.5× UN
----------------	---------

Electrical data | Input

Input voltage AC	250 V
------------------	-------

Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

Mechanical data | Mounting data

Height	13 mm
Width	23 mm
Depth	7.5 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C