

VALVE PLUG SUPPRESSOR FORM BI - 11MM

With LED, 24VAC/DC/50VA/W

Art.No.: 3124215

Weight: 0.014

Country of origin: CZ

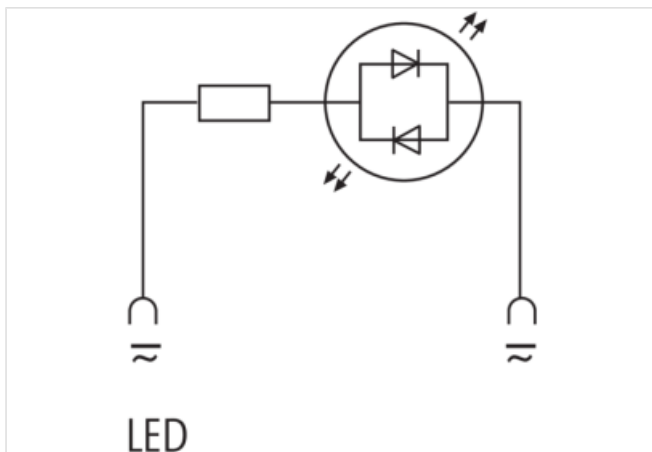
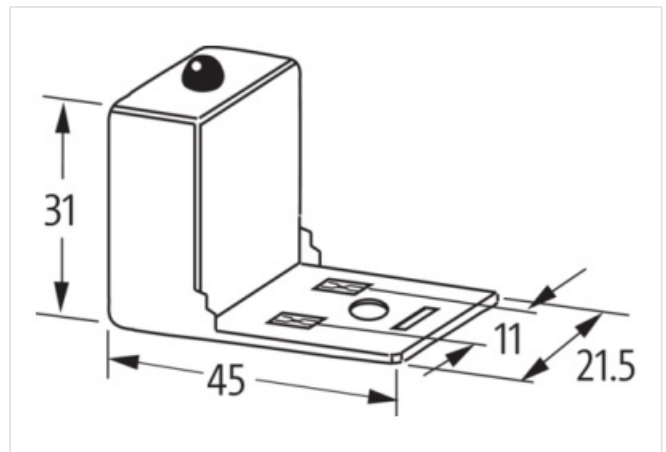
Model designation: LBS-LED 24 U

24 V AC/DC

LED

Remove plug gasket when fitting adapter. Other LED colors on request.

Note PIN arrangement (PE at cable outlet of connector). 180° turned version on request.

Link to Product**Illustration**

Product may differ from Image

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/3124215>

GTIN

4048879011983

ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
EAN	4048879011983

Electrical data

Holding power max.	50 W
--------------------	------

Electrical data | Input

Input voltage AC min.	12 V
Input voltage AC max.	24 V
Input voltage DC min.	12 V
Input voltage DC max.	24 V

Diagnostics

Status indication LED	yellow
-----------------------	--------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated

Mechanical data | Mounting data

Height	31 mm
Width	45 mm
Depth	21.5 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C