

MSDD pass-through RJ45 CAT5e femal/femal, design silver

Art.No.: 4000-73000-0010000

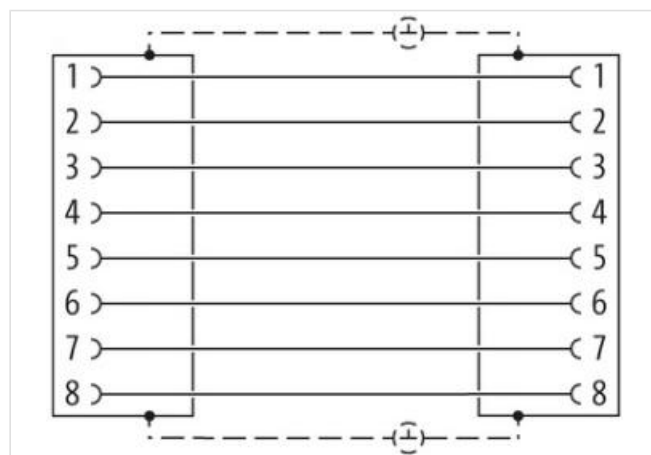
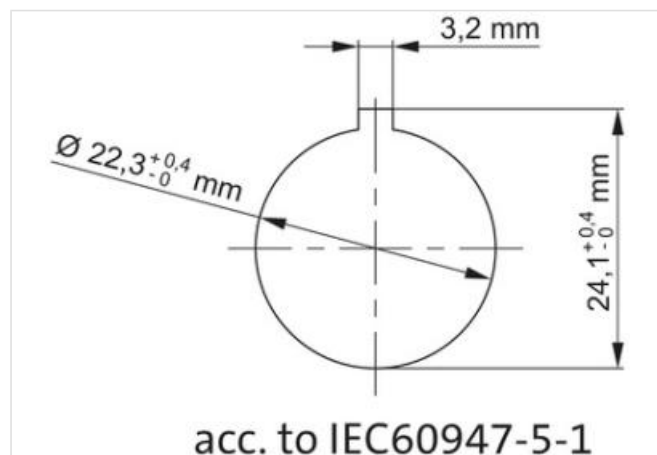
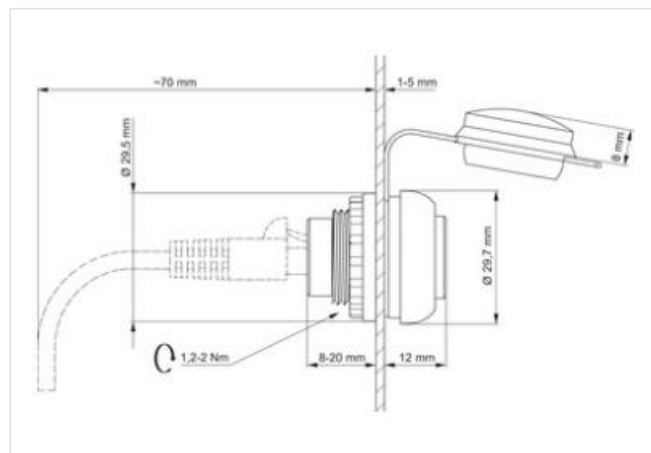
Weight: 0.018

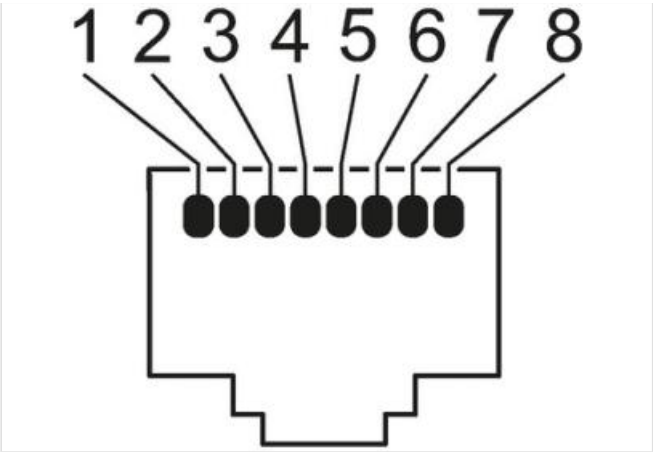
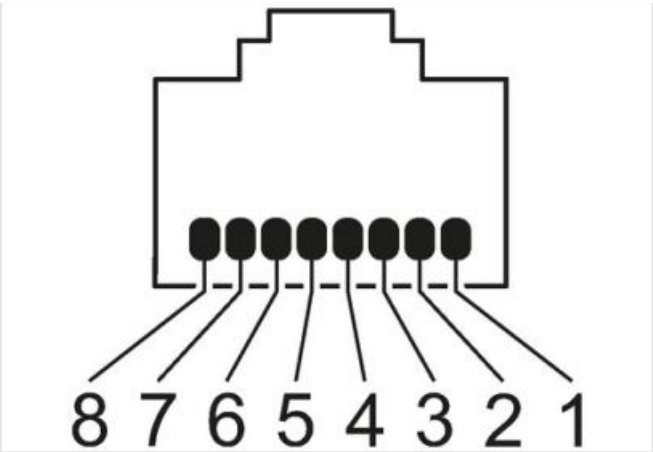
Country of origin: CZ

Model designation: MSDD PT22-S RJ45 CAT5e F/F

Pass-through

1 × RJ45, 8-pole CAT5e (female/female)

[Link to Product](#)**Illustration**



Product may differ from Image



Commercial data	
ECLASS-6.0	27143423
ECLASS-6.1	27143419
ECLASS-7.0	27440515
ECLASS-8.0	27440515
ECLASS-9.0	27440515
ECLASS-10.1	27440515
ECLASS-11.1	27440515
ECLASS-12.0	27440515
ETIM-5.0	EC002625
ETIM-6.0	EC002625
ETIM-7.0	EC002625
ETIM-8.0	EC002625
customs tariff number	85366990
customs tariff number	85366990
GTIN	4048879031189
GTIN	4048879031189
Packaging unit	1
Packaging unit	1
Electrical data Supply	
Operating voltage AC	24 V
Operating voltage DC	24 V
Operating current max.	1,5 A
Installation Connection	
Family construction form	RJ47
Gender	female
Gender Rear	female
Cable category min.	Cat5e
Device protection	
Shielded	yes
Device protection Electrical	
Degree of protection (EN IEC 60529)	IP20, IP65
Protection NEMA	2, 3R, 4, 12, 13, 4x

Additional condition protection degree inserted, in closed state

Device protection | Mechanical

Mechanical endurance 750 Cycles

Mechanical data | Mounting data

Diameter cutout 22,5 mm

Diameter 29,5 mm

Mounting depth 70 mm

Depth 20 mm

Approvals

UL 50E yes